


**SAI-M23-BE-12-F****Weidmüller Interface GmbH & Co. KG**

Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

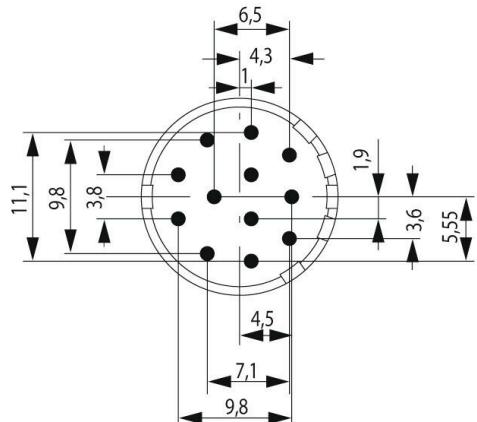

The M23 circular connector has a high number of pluggable contacts, strong current carrying capacity, high contact density and small size.  
The connection box, plug pins and pressure contact points must be ordered separately.

**通用订货数据**

版本	Sensor/Actuator plug-in connector
订货号	<a href="#">1224150000</a>
类型	SAI-M23-BE-12-F
GTIN (EAN)	4050118007688
数量	1 items

**SAI-M23-BE-12-F**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

**技术数据****审批**

MAMID 认证



ROHS	一致
UL File Number Search	<a href="#">UL 网站</a>
UR 证书号	E344862

**尺寸和重量**

净重	10 g
----	------

**环保产品合规**

RoHS 合规状态	合规, 有例外
RoHS 豁免 (如适用/已知)	7a, 7cl
REACH SVHC	Lead 7439-92-1
SCIP	1c533b66-fcff-4da5-b89f-fd55fbf5cb55

**技术资料 可定制接插件**

回路数	12	编码	无
插针镀层	镀金的	联接类型	焊接
外壳基本材料	热塑聚酰胺 PA 6, PBT	触点材料	铜锌合金
额定电压	200 V	额定电流	8 A
插拔次数	> 1000	污染等级	3
端头类型	插座	连接点截面积, 最大值	1.5 mm <sup>2</sup>
连接点截面积, 最小值	0.08 mm <sup>2</sup>		

**分类**

ETIM 8.0	EC003557	ETIM 9.0	EC003557
ETIM 10.0	EC003557	ECLASS 14.0	27-44-02-23
ECLASS 15.0	27-44-02-23		

**SAI-M23-BE-12-F**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

**图纸**

[www.weidmueller.com](http://www.weidmueller.com)

