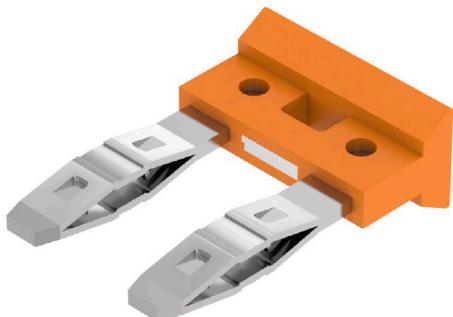


## SCM/SDI P CC



横联件，用于D-SERIES DRM中的插座

### 通用订货数据

版本	D-SERIES, 横联
订货号	<a href="#">7760056366</a>
类型	SCM/SDI P CC
GTIN (EAN)	6944169773327
数量	10 items

**SCM/SDI P CC**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**技术数据****审批**

ROHS	一致
------	----

**尺寸和重量**

深	18.2 mm	深度 (英寸)	0.7165 inch
高度	5.7 mm	高度 (英寸)	0.2244 inch
宽度	12.1 mm	宽度 (英寸)	0.4764 inch
净重	1 g		

**温度**

存储温度	工作温度
------	------

**环保产品合规**

RoHS 合规状态	合规, 无例外
REACH SVHC	不超过 0.1 wt% 的高度关注物质 (SVHC)

**横截面数据**

额定电压	250 V	额定电流	2 A
绝缘	是	触摸安全保护	是
颜色编码	橙色	横联端子数量	2
回路数	2	间距 P (单位 : mm)	8.00 mm
安装方式	插入的	类型	用于带 PUSH IN 直插式联接的 D 系列插座

**基本信息**

类型	用于带 PUSH IN 直插式联接的 D 系列插座	颜色编码	橙色
----	---------------------------	------	----

**绝缘设计**

额定电压	250 V
------	-------

**联接参数**

间距 P (单位 : mm)	8.00 mm
----------------	---------

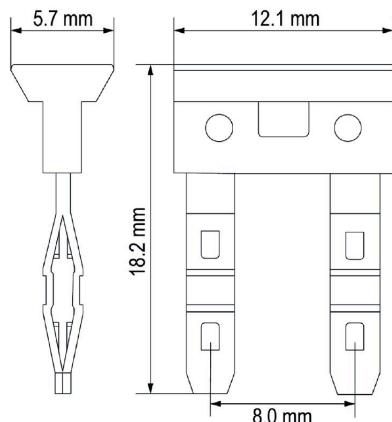
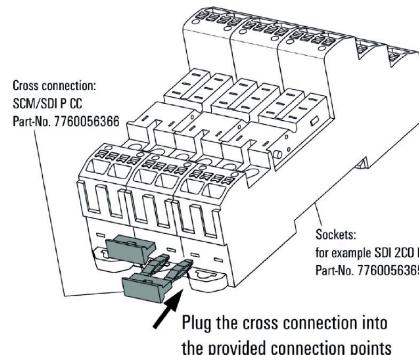
**分类**

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

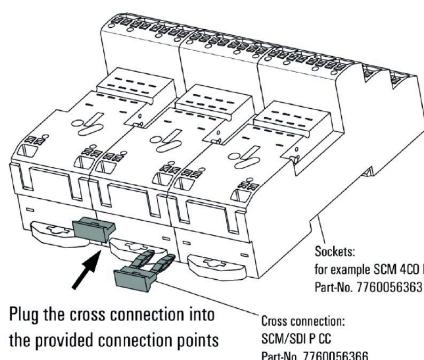
**SCM/SDI P CC**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**图纸****Dimensional drawing****应用举例****How to install cross connection**  
to cross connect A2 contacts of SDI... PUSH IN sockets

怎样安装横联件至 SDI 的横联 A2触点上... PUSH IN 插座

**应用举例****How to install cross connection**  
to cross connect A2 contacts of SCM... PUSH IN sockets

怎样安装横联件至 SCM 的横联 A2触点上... PUSH IN 插座

**应用举例****Cross connection**  
between SDI... and SCM... PUSH IN sockets is possible