

**TS 15X5/LL 2M/ST/ZN****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

**General ordering data**

Version	Terminal rail, Accessories, Steel, galvanic zinc plated and passivated, Width: 2000 mm, Height: 15 mm, Depth: 5.5 mm
Order No.	<a href="#">0117500000</a>
Type	TS 15X5/LL 2M/ST/ZN
GTIN (EAN)	4008190150662
Qty.	10 M

**TS 15X5/LL 2M/ST/ZN**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	5.5 mm	Depth (inches)	0.2165 inch
Height	15 mm	Height (inches)	0.5906 inch
Width	2000 mm	Width (inches)	78.74 inch
Net weight	140 g		

**Temperatures**

Ambient temperature -5 °C...40 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Mounting rail**

Solder eyelet hole diameter (D)	4.2 mm	
Standards	DIN EN 60715	
Surface finish	galvanic zinc plated and passivated	
Thickness	1.00 mm	
Basic material	Steel	
Length of the terminal rail	min.	0 mm
	nominal	2000 mm
	max.	2000 mm
Slotted drill holes	Yes	
Slit length	12.20 mm	
Slit gap	8.00 mm	
Short-time withstand current per second according to IEC 60947-7-2	1.2 kA	
Slit width	4.20 mm	
Pre-punched mounting rail	Yes	
Slit width		
Short circuit strength corresponds to E-Cu wire	10.00 mm <sup>2</sup>	
Drill-hole diameter	4.20 mm	
Spacing of holes, centre-to-centre	20 mm	
Slit gap		
Slit length		

**Classifications**



ETIM 8.0	EC001285	ETIM 9.0	EC001285
ETIM 10.0	EC001285	ECLASS 14.0	27-40-06-02
ECLASS 15.0	27-40-06-02		

**TS 15X5/LL 2M/ST/ZN**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

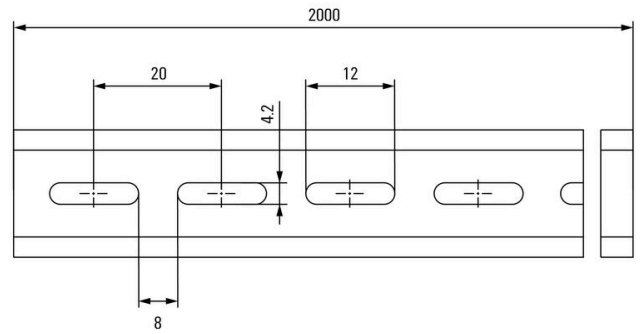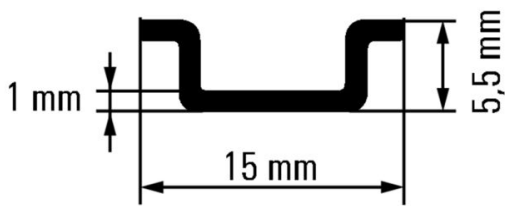

## TS 15X5/LL 2M/ST/ZN

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## End bracket




Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

Type	EW 15	Version	
Order No.	<a href="#">0382860000</a>	End bracket, beige, TS 15, V-2, Polyamide 66, Width: 10 mm, 100 °C	
GTIN (EAN)	4008190187804		
Qty.	50 ST		

## Accessories

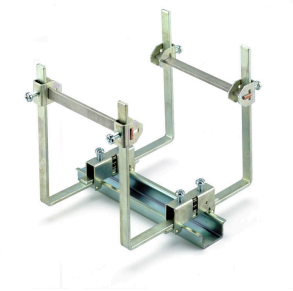


The comprehensive accessories of the Klippon® Connect portfolio are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms

## General ordering data

Type	SO SH1	Version	
Order No.	<a href="#">0401460000</a>	Busbar support, grey, 100 °C, Width: 24.5 mm, V-2, Polyamide 66, when screwed in	
GTIN (EAN)	4008190188092		
Qty.	20 ST		

## End bracket

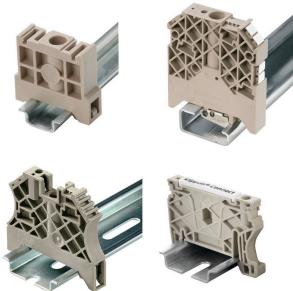

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

Type	EW 15/2	Version	
Order No.	<a href="#">1071900000</a>	End bracket, dark beige, TS 15, HB, Plastic, Width: 8 mm, 100 °C	
GTIN (EAN)	4008190462949		
Qty.	50 ST		

## TS 15X5/LL 2M/ST/ZN

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

Type	ZEW 15	Version	
Order No.	<a href="#">7920340000</a>	End bracket, beige, TS 15, V-2, Plastic, Width: 5 mm, 120 °C	
GTIN (EAN)	4032248238910		
Qty.	20 ST		

## Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

## General ordering data

Type	BFSC M4X6 MS	Version	
Order No.	<a href="#">0136300000</a>	Mounting screw (Terminal), 4.00 mm, Brass, Depth: 7 mm, Width: 7 mm, Height: 6 mm	
GTIN (EAN)	4008190177713		
Qty.	50 ST		
Type	BFSC M4X6	Version	
Order No.	<a href="#">0149700000</a>	Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 mm, Height: 6 mm	
GTIN (EAN)	4008190016098		
Qty.	100 ST		