

QL 3 SAK4


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

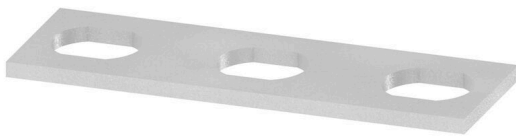

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | |
|------------|---|
| Version | Cross-connector (terminal), when screwed in, grey, 41 A, Number of poles: 3, Pitch in mm (P): 6.00, Insulated: No, Width: 18 mm |
| Order No. | 0130700000 |
| Type | QL 3 SAK4 |
| GTIN (EAN) | 4008 190085 117 |
| Qty. | 100 items |

QL 3 SAK4

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 0.6 mm | Depth (inches) | 0.0236 inch |
| Height | 6 mm | Height (inches) | 0.2362 inch |
| Width | 18 mm | Width (inches) | 0.7087 inch |
| Net weight | 0.43 g | | |

Temperatures

Storage temperature -25 °C...55 °C Ambient temperature -5 °C...40 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
REACH SVHC No SVHC above 0.1 wt%

Material data

Basic material Copper Colour grey

System specifications

Version for cross-connection link

Additional technical data

Type of fixing when screwed in Installation advice Direct mounting
Explosion-tested version No

Dimensions

Pitch in mm (P) 6.00 mm

General

Number of poles 3 Installation advice Direct mounting

Rating data

Nominal current 41 A

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000489 | ETIM 9.0 | EC000489 |
| ETIM 10.0 | EC000489 | ECLASS 14.0 | 27-25-03-03 |
| ECLASS 15.0 | 27-25-03-03 | | |