


ESO/SCHS1 500X12,5X0,3

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

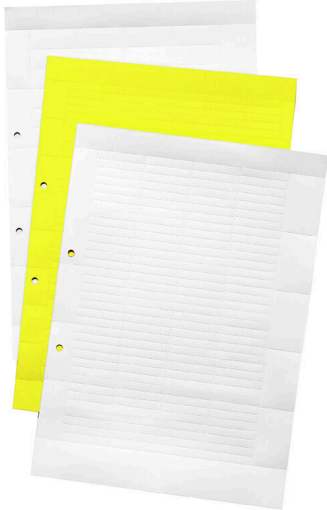

Similar to illustration

General ordering data

Version	Terminal markers, Insert markers, 500 x 12.5 mm, white
Order No.	0139000000
Type	ESO/SCHS1 500X12,5X0,3
GTIN (EAN)	4008190047252
Qty.	100 items
Delivery status	This article will no longer be available in the future.
Available until	2026-01-30T00:00:00+01:00

ESO/SCHS1 500X12,5X0,3

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	1 mm	Depth (inches)	0.0394 inch
Height	500 mm	Height (inches)	19.685 inch
Width	12.5 mm	Width (inches)	0.4921 inch
Net weight	2.46 g		

Temperatures

Operating temperature range -40...80 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Material colour according to resistance code	9		
Orientation of print	horizontal and vertical		
Number per sheet	1		
Width	12.5 mm		
UL 94 flammability rating	HB		
Operating temperature range, max.	80 °C		
Operating temperature range, min.	-40 °C		
Colour	white		
Basic material	Paper		
Printed characters	without		
Number of markers per packaging unit	Form of supply	Label sheet	
Number of markers per combination	1 Label sheet = Insert markers		
Operating temperature range	-40...80 °C		

Classifications

ETIM 8.0	EC000761	ETIM 9.0	EC000761
ETIM 10.0	EC000761	ECLASS 14.0	27-28-11-01
ECLASS 15.0	27-28-11-01		