


## ESO/SCHS1 500X12,5X0,3

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

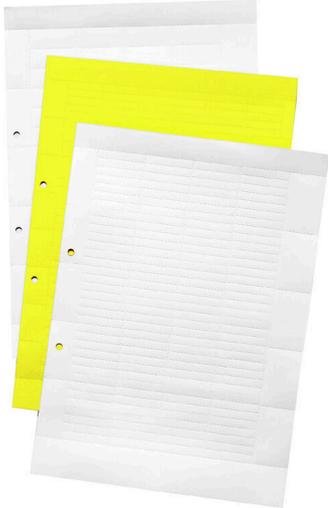

Similar to illustration

### General ordering data

|                 |   |
|-----------------|---|
| Version         | Terminal markers, Insert markers, 500 x 12.5 mm, white  |
| Order No.       | <a href="#">0139000000</a>                              |
| Type            | ESO/SCHS1 500X12,5X0,3                                  |
| GTIN (EAN)      | 4008190047252   |
| Qty.            | 100 items   |
| Delivery status | This article will no longer be available in the future. |
| Available until | 2026-01-30T00:00:00+01:00                               |

**ESO/SCHS1 500X12,5X0,3**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 1 mm    | Depth (inches)  | 0.0394 inch |
| Height     | 500 mm  | Height (inches) | 19.685 inch |
| Width      | 12.5 mm | Width (inches)  | 0.4921 inch |
| Net weight | 2.46 g  |                 |             |

**Temperatures**

Operating temperature range -40...80 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

|  |                                |             |  |
|--|--------------------------------|-------------|--|
| Material colour according to resistance code | 9                              |             |  |
| Orientation of print                         | horizontal and vertical        |             |  |
| Number per sheet                             | 1                              |             |  |
| Width  | 12.5 mm                        |             |  |
| UL 94 flammability rating                    | HB                             |             |  |
| Operating temperature range, max.            | 80 °C                          |             |  |
| Operating temperature range, min.            | -40 °C                         |             |  |
| Colour                                       | white                          |             |  |
| Basic material                               | Paper                          |             |  |
| Printed characters                           | without                        |             |  |
| Number of markers per packaging unit         | Form of supply                 | Label sheet |  |
| Number of markers per combination            | 1 Label sheet = Insert markers |             |  |
| Operating temperature range                  | -40...80 °C                    |             |  |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000761    | ETIM 9.0    | EC000761    |
| ETIM 10.0   | EC000761    | ECLASS 14.0 | 27-28-11-01 |
| ECLASS 15.0 | 27-28-11-01 |             |             |

## ESO/SCHS1 500X12,5X0,3

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Accessories

[www.weidmueller.com](http://www.weidmueller.com)

### WKM for inlay tags



The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking. Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

### General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | WKM 18/43                  | Version  |  |
| Order No.  | <a href="#">1610700000</a> | WKM, Conductor and cable markers, 7 - 115 mm, 43 x 18 mm, Wire |  |
| GTIN (EAN) | 4008190204488              | and cable markers, Transparent                                 |  |
| Qty.       | 50 ST                      |  |  |