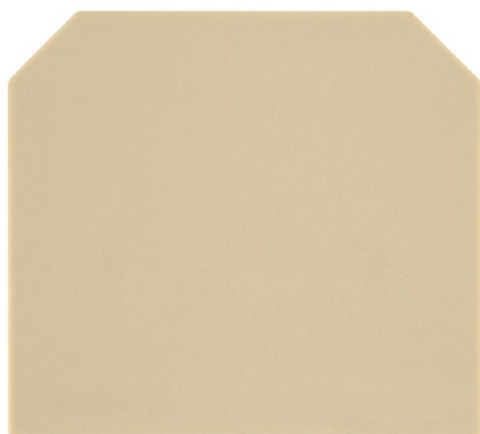


TW SAKG28 HP/TF/GE/2**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Similar to illustration

End plates are fitted to the open side of the last modular terminal before the end bracket. The use of an end plate ensures the function of the modular terminal and the specified rated voltage. It guarantees protection against contact with live parts and makes the final terminal finger-proof.

General ordering data

Version	Partition plate (terminal), yellow, Height: 120 mm, Width: 2 mm, V-2, PA 66
Order No.	0164600000
Type	TW SAKG28 HP/TF/GE/2
GTIN (EAN)	4008190141998
Qty.	10 items

TW SAKG28 HP/TF/GE/2

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	55 mm	Depth (inches)	2.1654 inch
Height	120 mm	Height (inches)	4.7244 inch
Width	2 mm	Width (inches)	0.0787 inch
Net weight	15.5 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	PA 66	Colour	yellow
UL 94 flammability rating	V-2		

System specifications

Version	Intermediate plate
---------	--------------------

Additional technical data

Snap-on	No	Installation advice	Direct mounting
---------	----	---------------------	-----------------

General

Installation advice	Direct mounting
---------------------	-----------------

Classifications

ETIM 6.0	EC000886	ETIM 7.0	EC000886
ETIM 8.0	EC000886	ETIM 9.0	EC000886
ETIM 10.0	EC000886	ECLASS 9.0	27-14-11-92
ECLASS 9.1	27-14-11-33	ECLASS 10.0	27-14-11-92
ECLASS 11.0	27-14-11-92	ECLASS 12.0	27-14-11-92
ECLASS 13.0	27-25-03-01	ECLASS 14.0	27-25-03-01
ECLASS 15.0	27-25-03-01		