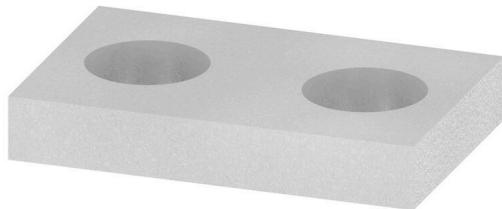


**QL 2 SAKD2.5N****Weidmüller Interface GmbH & Co. KG**Klingenbergsstraße 26  
D-32758 Detmold  
Germany[www.weidmueller.com](http://www.weidmueller.com)

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

**General ordering data**

Version	Cross-connector (terminal), when screwed in, grey, 24 A, Number of poles: 2, Pitch in mm (P): 5.00, Insulated: No, Width: 9.5 mm
Order No.	<a href="#">0215800000</a>
Type	QL 2 SAKD2.5N
GTIN (EAN)	4008190058661
Qty.	100 items
Delivery status	This article will no longer be available in the future.
Available until	2026-06-30T00:00:00+02:00

## QL 2 SAKD2.5N

Weidmüller Interface GmbH & Co. KG  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

## Approvals

RoHS	Conform
------	---------

## Dimensions and weights

Depth	1.5 mm	Depth (inches)	0.0591 inch
Height	6 mm	Height (inches)	0.2362 inch
Width	9.5 mm	Width (inches)	0.374 inch
Net weight	0.47 g		

## Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
---------------------	----------------	---------------------	---------------

## Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	86596b21-b817-43a9-8e4c-ac00e41b9a24

## Material data

Basic material	Cu Zn	Colour	grey
----------------	-------	--------	------

## System specifications

Version	Cross-connector
---------	-----------------

## Additional technical data

Type of fixing	when screwed in	Installation advice	Direct mounting
Explosion-tested version	No	Type of mounting	when screwed in

## Dimensions

Pitch in mm (P)	5.00 mm
-----------------	---------

## General

Number of poles	2	Installation advice	Direct mounting
-----------------	---	---------------------	-----------------

## Rating data

Rated voltage	400 V	Nominal current	24 A
---------------	-------	-----------------	------

## Classifications

ETIM 8.0	EC000489	ETIM 9.0	EC000489
ETIM 10.0	EC000489	ECLASS 14.0	27-25-03-03
ECLASS 15.0	27-25-03-03		

**QL 2 SAKD2.5N**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Accessories****Mounting support**

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

**General ordering data**

Type	KISC M2.5X15/5.5 SAKD	Version
Order No.	<a href="#">0367700000</a>	Mounting screw (Terminal), 2.50 mm, Steel, Depth: 3.8 mm, Width:
GTIN (EAN)	4008190170844	4.5 mm, Height: 15 mm
Qty.	100 ST	