


DKSUE NSCH/ESCH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

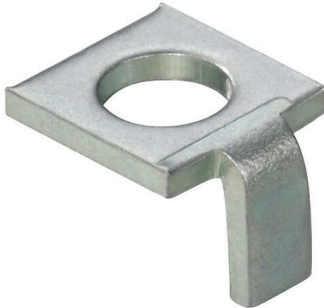

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

Version	Fastening element (Terminal), silver, Height: 12.5 mm, Width: 10 mm, Steel, 180 °C
Order No.	028010000
Type	DKSUE NSCH/ESCH
GTIN (EAN)	4008190036348
Qty.	100 items

DKSUE NSCH/ESCH

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	7.7 mm	Depth (inches)	0.3031 inch
Height	12.5 mm	Height (inches)	0.4921 inch
Width	10 mm	Width (inches)	0.3937 inch
Net weight	1.31 g		

Temperatures

Ambient temperature	-5 °C...40 °C	Continuous operating temp., min.	-60 °C
Continuous operating temp., max.	180 °C		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	Steel	Colour	silver
----------------	-------	--------	--------

System specifications

Version	Miscellaneous
---------	---------------

Additional technical data

Type of fixing	when screwed in	Explosion-tested version	No
----------------	-----------------	--------------------------	----

Dimensions

Pitch in mm (P)	13.50 mm
-----------------	----------

Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		