

H25,0/36 BR


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

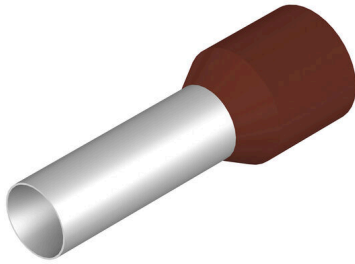

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 24 mm, 22 mm, brown
Order No.	0317100000
Type	H25,0/36 BR
GTIN (EAN)	4008190049751
Qty.	50 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 1.2 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, brown	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	7.3 mm	Contact surface length (L2)	22 mm
Collar diameter (D2)	11.2 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	36.00 mm	Wire connection cross section AWG, max.	AWG 3
Metal sleeve thickness (S1)	0.2 mm	Stripping length	24 mm
Conductor cross-section	25 mm ²	Colour code	Weidmueller

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

