

H35,0/30 BE


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

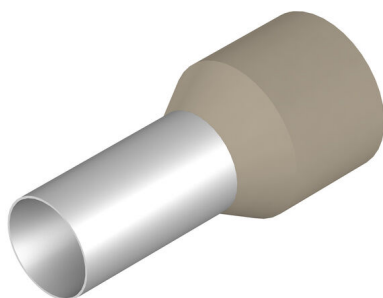

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 19 mm, 16 mm, beige
Order No.	0317200000
Type	H35,0/30 BE
GTIN (EAN)	4008190023904
Qty.	50 items
Packaging	loose

Technical data

Approvals

Approvals



ROHS	Conform
------	---------

UL File Number Search	UL Website
-----------------------	----------------------------

Certificate no. (cULus)	E499744
-------------------------	---------

Dimensions and weights

Net weight	1.18 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
------------------------	-----------------------------

REACH SVHC	No SVHC above 0.1 wt%
------------	-----------------------

Technical data

Description of article	Wire end ferrule with plastic collar, beige	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	8.3 mm	Contact surface length (L2)	16 mm
Collar diameter (D2)	12.7 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	30.00 mm	Wire connection cross section AWG, max.	AWG 2
Metal sleeve thickness (S1)	0.2 mm	Stripping length	19 mm
Conductor cross-section	35 mm ²	Colour code	Weidmueller

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

