

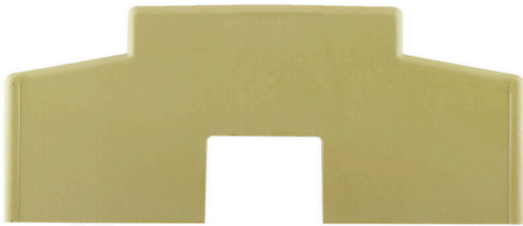
**AH 40 SAKG40****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

**General ordering data**

Version	Terminal cover, beige, PA 66, Height: 186 mm, Width: 38 mm, Depth: 78 mm, V-2
Order No.	<a href="#">0326860000</a>
Type	AH 40 SAKG40
GTIN (EAN)	4008190061258
Qty.	5 items

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	78 mm	Depth (inches)	3.0709 inch
Height	186 mm	Height (inches)	7.3228 inch
Width	38 mm	Width (inches)	1.4961 inch
Net weight	85.6 g		

**Temperatures**

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...55 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Material data**

Basic material	PA 66	Colour	beige
UL 94 flammability rating	V-2		

**System specifications**

Version	Hood
---------	------

**Additional technical data**

Snap-on	Yes	Installation advice	Direct mounting
---------	-----	---------------------	-----------------

**General**

Installation advice	Direct mounting
---------------------	-----------------

**Classifications**

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		