

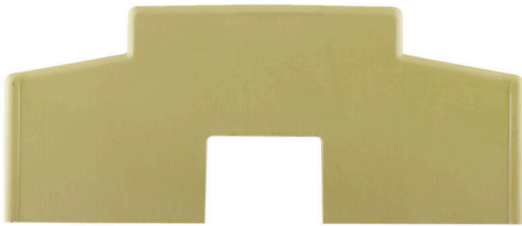
AH 40 SAKG40**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

| | |
|------------|---|
| Version | Terminal cover, beige, PA 66, Height: 186 mm, Width: 38 mm, Depth: 78 mm, V-2 |
| Order No. | 0326860000 |
| Type | AH 40 SAKG40 |
| GTIN (EAN) | 4008190061258 |
| Qty. | 5 items |

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 78 mm | Depth (inches) | 3.0709 inch |
| Height | 186 mm | Height (inches) | 7.3228 inch |
| Width | 38 mm | Width (inches) | 1.4961 inch |
| Net weight | 85.6 g | | |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|----------------|
| Storage temperature | -25 °C...55 °C | Ambient temperature | -50 °C...55 °C |
| Continuous operating temp., min. | -50 °C | Continuous operating temp., max. | 100 °C |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Material data

| | | | |
|---------------------------|-------|--------|-------|
| Basic material | PA 66 | Colour | beige |
| UL 94 flammability rating | V-2 | | |

System specifications

| | |
|---------|------|
| Version | Hood |
|---------|------|

Additional technical data

| | | | |
|---------|-----|---------------------|-----------------|
| Snap-on | Yes | Installation advice | Direct mounting |
|---------|-----|---------------------|-----------------|

General

| | |
|---------------------|-----------------|
| Installation advice | Direct mounting |
|---------------------|-----------------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC002848 | ETIM 9.0 | EC002848 |
| ETIM 10.0 | EC002848 | ECLASS 14.0 | 27-25-03-90 |
| ECLASS 15.0 | 27-25-03-90 | | |