


RSX LOETST. LP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

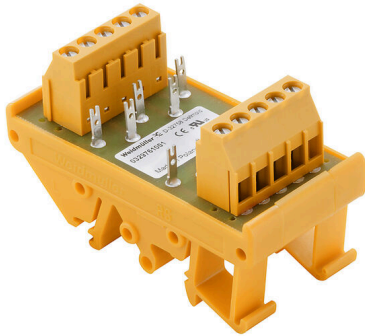

Axial components such as resistors, diodes and capacitors, can be soldered into the RSX component modules. Depending on the version, up to eight components can be soldered into our RSX modules.

General ordering data

Version	Assembly modul, Number of signals: 5
Order No.	0329761001
Type	RSX LOETST. LP
GTIN (EAN)	4032248043729
Qty.	5 items

RSX LOETST. LP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (UR) E141197

Dimensions and weights

Depth	42 mm	Depth (inches)	1.6535 inch
Height	70 mm	Height (inches)	2.7559 inch
Width	35 mm	Width (inches)	1.378 inch
Net weight	36.35 g		

Temperatures

Storage temperature	-40...60 °C	Ambient temperature	-25 °C...50 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	d577b8f5-26ef-4f66-a4a2-3b0818823974

Rated data UL

Rated current I _N	4 A	Operating temperature UL, min.	-25 °C
Operating temperature UL, max.	50 °C	Rated current I _{max}	4 A
Rated voltage U _N	250 V		

Insulation coordination (EN50178)

According to	DIN EN 50178	Rated insulation voltage	<250 V AC
Surge voltage category	II		

Connection field

Clamping range, max.	6 mm ²	Clamping range, min.	0.5 mm ²
----------------------	-------------------	----------------------	---------------------

Classifications

ETIM 8.0	EC002780	ETIM 9.0	EC002780
ETIM 10.0	EC002780	ECLASS 14.0	27-14-11-52
ECLASS 15.0	27-14-11-52		

RSX LOETST. LP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

