

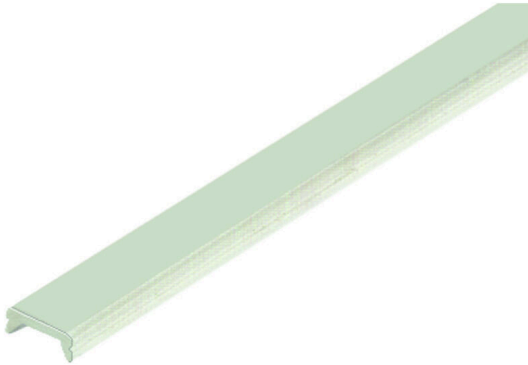
**ADP 2/HP2 1M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**Similar to illustration *Abbildung ähnlich*

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

**General ordering data**

Version	SAK Series, Cover profile, Transparent, 1000 mm
Order No.	<a href="#">0485300000</a>
Type	ADP 2/HP2 1M
GTIN (EAN)	4008190051716
Qty.	20 M

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	61.5 mm	Depth (inches)	2.4213 inch
Height	30 mm	Height (inches)	1.1811 inch
Width	1000 mm	Width (inches)	39.37 inch
Net weight	218 g		

### Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...55 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Material data

Basic material	PVC	Colour	Transparent
UL 94 flammability rating	V-2		

### System specifications

Version	cover plate
---------	-------------

### Additional technical data

Snap-on	Yes	Installation advice	Direct mounting
---------	-----	---------------------	-----------------

### General

Installation advice	Direct mounting
---------------------	-----------------

### Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		

**Drawings**

