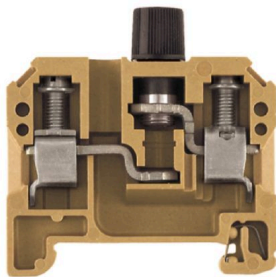


SAKS 1/35/G20**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image

Fuse terminal blocks and component terminal blocks allow protective and functional elements to be integrated directly into the terminal strip. Fuse terminal blocks include built-in fuse holders to reliably protect electrical circuits against overload —ideal for control and distribution systems. Component terminal blocks make it possible to incorporate electronic components such as diodes, resistors, or LEDs directly into the wiring. This enables space-saving and clearly arranged implementation of switching functions and signal separation. Both types of terminal blocks ensure higher safety, easy maintenance, and a compact, function-oriented installation.

General ordering data

| | |
|------------|--|
| Version | Fuse terminal, Screw connection, medium yellow, 10 mm ² , 10 A, 500 V, Number of connections: 2, Number of levels: 1, TS 35 |
| Order No. | 0501620000 |
| Type | SAKS 1/35/G20 |
| GTIN (EAN) | 4008190111229 |
| Qty. | 20 items |

Technical data

Approvals

Approvals



| | |
|------|---------|
| ROHS | Conform |
|------|---------|

| | |
|-----------------------|----------------------------|
| UL File Number Search | UL Website |
|-----------------------|----------------------------|

| | |
|----------------------|--------|
| Certificate No. (UR) | E60693 |
|----------------------|--------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 53 mm | Depth (inches) | 2.0866 inch |
| Height | 54 mm | Height (inches) | 2.126 inch |
| Width | 13 mm | Width (inches) | 0.5118 inch |
| Net weight | 36.5 g | | |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|---------------|
| Storage temperature | -25 °C...55 °C | Ambient temperature | -5 °C...40 °C |
| Continuous operating temp., min. | -60 °C | Continuous operating temp., max. | 130 °C |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Material data

| | | | |
|---------------------------|----------|--------|---------------|
| Basic material | KrG | Colour | medium yellow |
| UL 94 flammability rating | V-0, 5VA | | |

System specifications

| | | | |
|-------------------------------------|---|-------------------------------|-----|
| Version | Screw connection, Fuse cartridge, One end without connector | End cover plate required | Yes |
| Number of potentials | 1 | Number of levels | 1 |
| Number of clamping points per level | 2 | Number of potentials per tier | 1 |
| Levels cross-connected internally | No | PE connection | No |
| Mounting rail | TS 35 | N-function | No |
| PE function | No | PEN function | No |

Additional technical data

| | | | |
|---------------------|-----------------|-----------------------------|----|
| Open sides | right | Number of similar terminals | 1 |
| Installation advice | Direct mounting | Explosion-tested version | No |
| Type of mounting | Snap-on | | |

CSA rating data

| | | | |
|-------------------------------|--------|-----------------------|-----------|
| Wire cross section max. (CSA) | 10 AWG | Voltage size C (CSA) | 600 V |
| Current size C (CSA) | 10 A | Certificate No. (CSA) | 12400-198 |
| Wire cross section min. (CSA) | 26 AWG | | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Conductors for clamping (additional connection)

| | | | |
|---|--------------------|--|------------------|
| Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max. | 10 mm ² | Connection type, additional connection | Screw connection |
|---|--------------------|--|------------------|

Conductors for clamping (rated connection)

| | | | |
|---|----------------------|---|----------------------|
| Gauge to IEC 60947-1 | B6 | Wire connection cross section AWG, max. | AWG 10 |
| Connection direction | on side | Tightening torque, max. | 2.4 Nm |
| Tightening torque, min. | 1.2 Nm | Stripping length | 12 mm |
| Type of connection 2 | Screw connection | Type of connection | Screw connection |
| Number of connections | 2 | Clamping range, max. | 16 mm ² |
| Clamping range, min. | 0.13 mm ² | Clamping screw | M 4 |
| Blade size | 1.0 x 5.5 mm | Wire connection cross section AWG, min. | AWG 26 |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.13 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 10 mm ² |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 0.13 mm ² | Wire connection cross section, finely stranded, max. | 10 mm ² |
| Wire connection cross section, finely stranded, min. | 0.13 mm ² | Connection cross-section, stranded, max. | 10 mm ² |
| Connection cross-section, stranded, min. | 0.13 mm ² | Torque level with DMS electric screwdriver | 4 |
| Wire connection cross-section, solid core, max. | 16 mm ² | Wire connection cross-section, solid core, min. | 0.13 mm ² |
| Connection cross-section, finely stranded, min. | 0.13 mm ² | | |

General

| | | | |
|---|--------|---------------------|-----------------|
| Wire connection cross section AWG, max. | AWG 10 | Installation advice | Direct mounting |
| Wire connection cross section AWG, min. | AWG 26 | Standards | IEC 60947-7-3 |
| Mounting rail | TS 35 | | |

Rating data

| | | | |
|--|--------------------|---------------------------------|---------------|
| Rated cross-section | 10 mm ² | Rated voltage | 500 V |
| Rated DC voltage | 500 V | Nominal current | 10 A |
| Current at maximum wires | 10 A | Standards | IEC 60947-7-3 |
| Volume resistance according to IEC 60947-7-x | 0.56 mΩ | Rated impulse withstand voltage | 6 kV |
| Power loss in accordance with IEC 60947-7-x | 1.82 W | Pollution severity | 3 |

UL rating data

| | | | |
|---|--------|---|--------|
| Conductor size Factory wiring max. (UR) | 8 AWG | Current size C (UR) | 6.3 A |
| Voltage size C (UR) | 600 V | Conductor size Factory wiring min. (UR) | 26 AWG |
| Certificate No. (UR) | E60693 | Conductor size Field wiring min. (UR) | 22 AWG |
| Conductor size Field wiring max. (UR) | 10 AWG | | |

Important note

| | |
|---------------------|--|
| Product information | The voltage depends on the selected fuse element or the selected indicator light |
|---------------------|--|

Technical data**Classifications**

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000899 | ETIM 9.0 | EC000899 |
| ETIM 10.0 | EC000899 | ECLASS 14.0 | 27-25-01-13 |
| ECLASS 15.0 | 27-25-01-13 | | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKS1 | Version |
| Order No. | 0191400000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190123130 | poles: 2, Pitch in mm (P): 13.00, Insulated: No, Width: 18.9 mm |
| Qty. | 50 ST | |
| Type | QL 3 SAKS1 | Version |
| Order No. | 0191500000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190036881 | poles: 3, Pitch in mm (P): 13.00, Insulated: No, Width: 31.9 mm |
| Qty. | 50 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 4 SAKS1 | Version |
| Order No. | 0191600000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190105518 | poles: 4, Pitch in mm (P): 13.00, Insulated: No, Width: 44.7 mm |
| Qty. | 20 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 10 SAKS1 | Version |
| Order No. | 0338800000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190127039 | poles: 10, Pitch in mm (P): 13.00, Insulated: No, Width: 122.1 mm |
| Qty. | 20 ST | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | AP SAKS1+3 KRG | Version |
| Order No. | 0191320000 | End plate for terminals, dark beige, yellow, Height: 54 mm, Width: 3 |
| GTIN (EAN) | 4008190031688 | mm, V-0, KrG, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | AP SAKS1+3 KRG/DB | Version |
| Order No. | 0191300000 | End plate for terminals, dark beige, Height: 54 mm, Width: 3 mm, V-0, |
| GTIN (EAN) | 4008190099763 | KrG, Snap-on: Yes |
| Qty. | 20 ST | |

Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|--------------------------------------|
| Type | KISC M3X6 SAKS1 | Version |
| Order No. | 0346200000 | Clamping yoke, Mounting screw, Steel |
| GTIN (EAN) | 4008190175658 | |
| Qty. | 100 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | G 20/0.10A/F | Version |
| Order No. | 0430300000 | Miniature fuse, quick-acting, 0.1 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190077174 | |
| Qty. | 10 ST | |
| Type | G 20/0.20A/F | Version |
| Order No. | 0430400000 | Miniature fuse, quick-acting, 0.2 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190152383 | |
| Qty. | 10 ST | |
| Type | G 20/0.25A/F | Version |
| Order No. | 0430500000 | Miniature fuse, quick-acting, 0.25 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190153991 | |
| Qty. | 10 ST | |
| Type | G 20/0.50A/F | Version |
| Order No. | 0430600000 | Miniature fuse, quick-acting, 0.5 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190046835 | |
| Qty. | 10 ST | |
| Type | G 20/0.63A/F | Version |
| Order No. | 0439000000 | Miniature fuse, quick-acting, 0.63 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190131210 | |
| Qty. | 10 ST | |
| Type | G 20/1.00A/F | Version |
| Order No. | 0430700000 | Miniature fuse, quick-acting, 1 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190093877 | |
| Qty. | 10 ST | |
| Type | G 20/1.60A/F | Version |
| Order No. | 0430800000 | Miniature fuse, quick-acting, 1.6 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190031503 | |
| Qty. | 10 ST | |
| Type | G 20/2.00A/F | Version |
| Order No. | 0430900000 | Miniature fuse, quick-acting, 2 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190123567 | |
| Qty. | 10 ST | |
| Type | G 20/2.50A/F | Version |
| Order No. | 0431000000 | Miniature fuse, quick-acting, 2.5 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190085513 | |
| Qty. | 10 ST | |
| Type | G 20/3.15A/F | Version |
| Order No. | 0431100000 | Miniature fuse, quick-acting, 3.15 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190012977 | |
| Qty. | 10 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | G 20/4.00A/F | Version |
| Order No. | 0431200000 | Miniature fuse, quick-acting, 4 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190022983 | |
| Qty. | 10 ST | |
| Type | G 20/5.00A/F | Version |
| Order No. | 0431300000 | Miniature fuse, quick-acting, 5 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190185381 | |
| Qty. | 10 ST | |
| Type | G 20/6.30A/F | Version |
| Order No. | 0431400000 | Miniature fuse, quick-acting, 6.3 A, G-Si. 5 x 20 |
| GTIN (EAN) | 4008190086053 | |
| Qty. | 10 ST | |

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.


Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/5 MC NE WS | Version |
| Order No. | 1609801044 | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397111 | Weidmueller, white |
| Qty. | 1000 ST | |

End bracket

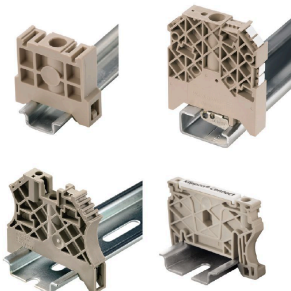

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | EW 35 | Version |
| Order No. | 0383560000 | End bracket, beige, TS 35, V-2, Wemid, Width: 8.5 mm, 100 °C |
| GTIN (EAN) | 4008190181314 | |
| Qty. | 50 ST | |
| Type | EWK 1 | Version |
| Order No. | 0206160000 | End bracket, beige, TS 32, V-0, Wemid, Width: 9 mm, 100 °C |
| GTIN (EAN) | 4008190080020 | |
| Qty. | 50 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | Q 2 SAK10 | Version |
| Order No. | 0457100000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190103545 | poles: 2, Pitch in mm (P): 9.90, Insulated: No, Width: 16.9 mm |
| Qty. | 50 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | Q 3 SAK10 | Version |
| Order No. | 0457200000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190135379 | poles: 3, Pitch in mm (P): 9.90, Insulated: No, Width: 26.8 mm |
| Qty. | 50 ST | |
| Type | Q 4 SAK10 | Version |
| Order No. | 0457300000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190129750 | poles: 4, Pitch in mm (P): 9.90, Insulated: No, Width: 36.7 mm |
| Qty. | 50 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | Q 10 SAK10 | Version |
| Order No. | 0457400000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190016166 | poles: 10, Pitch in mm (P): 9.90, Insulated: No, Width: 96.1 mm |
| Qty. | 20 ST | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | AP SAK4-10 DB | Version |
| Order No. | 0105100000 | End plate for terminals, dark beige, Height: 40 mm, Width: 1.5 mm, |
| GTIN (EAN) | 4008190394875 | V-0, Wemid, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | AP SAK4-10 RT | Version |
| Order No. | 0117900000 | End plate for terminals, red, Height: 40 mm, Width: 1.5 mm, V-2, PA |
| GTIN (EAN) | 4008190125059 | 66, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | AP SAK4-10 I | Version |
| Order No. | 0117910000 | End plate for terminals, black, Height: 40 mm, Width: 1.5 mm, V-2, PA |
| GTIN (EAN) | 4008190183707 | 66, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | AP SAK4-10 KRG | Version |
| Order No. | 0117920000 | End plate for terminals, dark beige, yellow, Height: 40 mm, Width: 1.5 |
| GTIN (EAN) | 4008190135904 | mm, V-0, KrG, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | AP SAK4-10 | Version |
| Order No. | 0117960000 | End plate for terminals, beige, Height: 40 mm, Width: 1.5 mm, V-2, |
| GTIN (EAN) | 4008190081485 | PA 66, Snap-on: Yes |
| Qty. | 20 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | AP SAK4-10 KRG/BL | Version |
| Order No. | 0117970000 | End plate for terminals, blue, Height: 40 mm, Width: 1.5 mm, V-0, |
| GTIN (EAN) | 4008190049607 | KrG, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | AP SAK4-10 BL | Version |
| Order No. | 0117980000 | End plate for terminals, blue, Height: 40 mm, Width: 1.5 mm, V-2, PA |
| GTIN (EAN) | 4008190171087 | 66, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | TW SAK4-10 KRG | Version |
| Order No. | 0130120000 | Partition plate (terminal), dark beige, yellow, Height: 50 mm, Width: |
| GTIN (EAN) | 4008190139117 | 2.25 mm, V-0, KrG |
| Qty. | 20 ST | |
| Type | TW 4 SAK4-10 | Version |
| Order No. | 0130160000 | Partition plate (terminal), beige, Height: 50 mm, Width: 1.5 mm, V-2, |
| GTIN (EAN) | 4008190096335 | PA 66 |
| Qty. | 20 ST | |
| Type | TW SAK4-10 KRG/BL | Version |
| Order No. | 0130170000 | Partition plate (terminal), blue, Height: 50 mm, Width: 2.25 mm, V-0, |
| GTIN (EAN) | 4008190063757 | KrG |
| Qty. | 20 ST | |
| Type | TW 4 SAK4-10 BL | Version |
| Order No. | 0130180000 | Partition plate (terminal), blue, Height: 50 mm, Width: 1.5 mm, V-2, |
| GTIN (EAN) | 4008190114138 | PA 66 |
| Qty. | 20 ST | |
| Type | TW SAK4-10 HP/DBR/0.5 | Version |
| Order No. | 0197100000 | Partition plate (terminal), brown, dark beige, Height: 40 mm, Width: |
| GTIN (EAN) | 4008190146627 | 0.5 mm, V-2, PA 66 |
| Qty. | 20 ST | |
| Type | TSCH 1 | Version |
| Order No. | 0319160000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190097219 | max.: 100 °C |
| Qty. | 100 ST | |
| Type | TSCH 2 | Version |
| Order No. | 0353660000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190128432 | max.: 100 °C |
| Qty. | 100 ST | |
| Type | TSCH 3 SAKD2.5 N | Version |
| Order No. | 0366860000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190010928 | max.: 100 °C |
| Qty. | 100 ST | |
| Type | TSCH 4 AKZ4 | Version |
| Order No. | 0363360000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190136680 | max.: 100 °C |
| Qty. | 100 ST | |
| Type | TSCH 6 DKI S4 | Version |
| Order No. | 0190260000 | Small partition (terminal), PA 66, beige, Continuous operating temp., |
| GTIN (EAN) | 4008190051075 | max.: 100 °C |
| Qty. | 100 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|--------------------------------|
| Type | PS 4 F.STB 4 | Version |
| Order No. | 0299600000 | Test adapter (terminal), 230 V |
| GTIN (EAN) | 4008190074043 | |
| Qty. | 20 ST | |

Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | BFSC M3X22 PA/RT | Version |
| Order No. | 0128900000 | Mounting screw (Terminal), 3.00 mm, Polyamide 66, Depth: 4.8 mm, |
| GTIN (EAN) | 4008190084158 | Width: 4.8 mm, Height: 22 mm |
| Qty. | 100 ST | |
| Type | BFSC M3X25 | Version |
| Order No. | 0292500000 | Mounting screw (Terminal), 3.00 mm, Steel, Depth: 4.8 mm, Width: |
| GTIN (EAN) | 4008190177027 | 4.8 mm, Height: 25 mm |
| Qty. | 100 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany


www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | VH 19/5/3.4 | Version |
| Order No. | 0285100000 | Connecting sleeve (terminal), when screwed in, Width: 5 mm, Height: 5 mm, Depth: 17.5, Number of poles: 1, Cu Zn |
| GTIN (EAN) | 4008190189297 | |
| Qty. | 50 ST | |
| Type | VL 2 SAK6/10/SAKB | Version |
| Order No. | 0135900000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of poles: 2, Pitch in mm (P): 6.50, Insulated: No, Width: 1.5 mm |
| GTIN (EAN) | 4008190036409 | |
| Qty. | 50 ST | |

 Warning cover



Warning covers with a flash symbol provide more safety for man and machine. They are used where external voltage must be indicated within the application.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | AD 4 SAK10 | Version |
| Order No. | 0178600000 | Terminal cover, yellow, PVC, Height: 39.6 mm, Width: 25 mm, Depth: 1 mm, HB |
| GTIN (EAN) | 4008190068288 | |
| Qty. | 50 ST | |

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/5 MC SDR | Version |
| Order No. | 1609810000 | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190456597 | Weidmueller, To customer specification |
| Qty. | 200 ST | |

Accessories

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKB10 | Version |
| Order No. | 0114100000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190056605 | poles: 2, Pitch in mm (P): 10.00, Insulated: No, Width: 17 mm |
| Qty. | 100 ST | |
| Type | QL 10 SAKB10 | Version |
| Order No. | 0338400000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190139452 | poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 97 mm |
| Qty. | 20 ST | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | AP SAKB/C/T KRG | Version |
| Order No. | 0146720000 | End plate for terminals, dark beige, yellow, Height: 65 mm, Width: 3 |
| GTIN (EAN) | 4008190027995 | mm, V-O, KrG, Snap-on: Yes |
| Qty. | 20 ST | |
| Type | TW SAKB/C/T | Version |
| Order No. | 0242920000 | Partition plate (terminal), beige, Height: 75 mm, Width: 3 mm, V-2, |
| GTIN (EAN) | 4008190069933 | KrG |
| Qty. | 20 ST | |

Accessories

Mounting support




We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SS M4 D 128-A 4 | Version |
| Order No. | 0136400000 | Lock washer, Copper |
| GTIN (EAN) | 4008190118143 | |
| Qty. | 100 ST | |
| Type | BFSC M4X9T | Version |
| Order No. | 0103300000 | Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 mm, Height: 9 mm |
| GTIN (EAN) | 4008190023348 | |
| Qty. | 100 ST | |

SchT group marker carrier

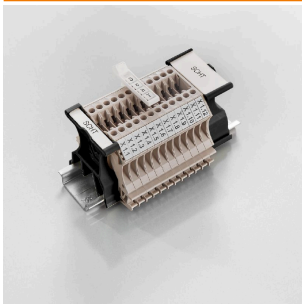

The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw. The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

Inlay tags and protective strips can be found under "Accessories".

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SCHT 7 | Version |
| Order No. | 0517960000 | SCHT, Terminal marker, 39.3 x 8 mm, Pitch in mm (P): 7.00 |
| GTIN (EAN) | 4008190001742 | Weidmueller, white |
| Qty. | 20 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKH10 | Version |
| Order No. | 0131400000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190114237 | poles: 2, Pitch in mm (P): 14.00, Insulated: No, Width: 16.9 mm |
| Qty. | 50 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 3 SAKH10 | Version |
| Order No. | 0131500000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190056490 | poles: 3, Pitch in mm (P): 14.00, Insulated: No, Width: 26.8 mm |
| Qty. | 50 ST | |
| Type | QL 10 SAKH10 | Version |
| Order No. | 0338700000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190039424 | poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 96.1 mm |
| Qty. | 20 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|---|
| Type | VH 12/4.9/3.3 | Version |
| Order No. | 0249000000 | Connecting sleeve (terminal), when screwed in, Width: 4.9 mm, |
| GTIN (EAN) | 4008190129507 | Height: 4.9 mm, Depth: 12 mm, Number of poles: 1, Copper |
| Qty. | 100 ST | |

Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|------------------------------------|
| Type | KISC M3X20 SAK10 CU5 | Version |
| Order No. | 0377100000 | SAK Series, Mounting screw, Copper |
| GTIN (EAN) | 4008190060350 | |
| Qty. | 100 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKA10 | Version |
| Order No. | 0135500000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of |
| GTIN (EAN) | 4008190099404 | poles: 2, Pitch in mm (P): 12.00, Insulated: No, Width: 19.9 mm |
| Qty. | 50 ST | |
| Type | QL 3 SAKA10 | Version |
| Order No. | 0135600000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190032081 | poles: 3, Pitch in mm (P): 12.00, Insulated: No, Width: 31.8 mm |
| Qty. | 50 ST | |
| Type | QL 4 SAKA10 | Version |
| Order No. | 0135700000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190118822 | poles: 4, Pitch in mm (P): 12.00, Insulated: No, Width: 43.7 mm |
| Qty. | 50 ST | |
| Type | QL 10 SAKA10 | Version |
| Order No. | 0338500000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190063313 | poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 115.1 mm |
| Qty. | 20 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | AP SAKA KRG | Version |
| Order No. | 0134220000 | End plate for terminals, dark beige, yellow, Height: 82 mm, Width: 3 |
| GTIN (EAN) | 4008190167943 | mm, V-O, KrG, Snap-on: Yes |
| Qty. | 20 ST | |

Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|--------------------|
| Type | STB 13.5/D6/4/M4 SAKA10 | Version |
| Order No. | 0135200000 | SAK Series, Socket |
| GTIN (EAN) | 4008190172862 | |
| Qty. | 50 ST | |

Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | BFSC M4X30 | Version |
| Order No. | 0267100000 | Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 |
| GTIN (EAN) | 4008190187897 | mm, Height: 30 mm |
| Qty. | 50 ST | |


SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cross-connections

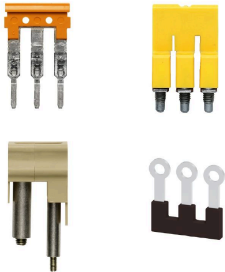

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | VL 2 SAK 16/SAKA | Version |
| Order No. | 0135800000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190132088 | poles: 2, Pitch in mm (P): 12.00, Insulated: No, Width: 8 mm |
| Qty. | 50 ST | |

Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|---------------------------------------|
| Type | PS 2.3 RT | Version |
| Order No. | 0180400000 | Test adapter (terminal), 230 V, 20 mA |
| GTIN (EAN) | 4008190060121 | |
| Qty. | 20 ST | |

Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | BFSC M4X20 | Version |
| Order No. | 0362800000 | Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 |
| GTIN (EAN) | 4008190114053 | mm, Height: 20 mm |
| Qty. | 100 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | VH 13.6/6.3/4.3 | Version |
| Order No. | 0299700000 | Connecting sleeve (terminal), when screwed in, Width: 7 mm, Height: 7 mm, Depth: 13.6 mm, Number of poles: 1, Cu Zn |
| GTIN (EAN) | 4008190018313 | |
| Qty. | 50 ST | |

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6.5 MC SDR | Version |
| Order No. | 1609850000 | Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50 |
| GTIN (EAN) | 4008190456610 | Weidmueller, To customer specification |
| Qty. | 180 ST | |

Accessories

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6.5 MC NE WS | Version |
| Order No. | 1609840000 | Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50 |
| GTIN (EAN) | 4008190203429 | Weidmueller, white |
| Qty. | 900 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 RSF 1+2 | Version |
| Order No. | 0267400000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 2, Pitch in mm (P): 11.00, Insulated: No, Width: 18 mm |
| GTIN (EAN) | 4008190139988 | |
| Qty. | 50 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 3 RSF1+2 | Version |
| Order No. | 0267500000 | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |
| GTIN (EAN) | 4008190116835 | poles: 3, Pitch in mm (P): 11.00, Insulated: No, Width: 29 mm |
| Qty. | 50 ST | |
| Type | QL 4 RSF1+2 | Version |
| Order No. | 0267600000 | Cross-connector (terminal), when screwed in, grey, 41 A, Number of |
| GTIN (EAN) | 4008190174859 | poles: 4, Pitch in mm (P): 11.00, Insulated: No, Width: 40 mm |
| Qty. | 50 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 10 RSF1+2 | Version |
| Order No. | 0341700000 | Cross-connector (terminal), when screwed in, grey, 20 A, Number of |
| GTIN (EAN) | 4008190003173 | poles: 10, Pitch in mm (P): 8.00, Insulated: No, Width: 106 mm |
| Qty. | 20 ST | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | AP RSF1 KRG | Version |
| Order No. | 0270420000 | End plate for terminals, medium yellow, Height: 50 mm, Width: 3 mm, |
| GTIN (EAN) | 4008190099107 | V-0, KrG, Snap-on: Yes |
| Qty. | 10 ST | |
| Type | TW AST1/PA HP/DBR/0.5 | Version |
| Order No. | 0474700000 | Partition plate (terminal), dark brown, Height: 65 mm, Width: 0.5 mm, |
| GTIN (EAN) | 4008190078508 | V-2 |
| Qty. | 20 ST | |
| Type | TW DK4 HP/DBR/2 | Version |
| Order No. | 3833500000 | Partition plate (terminal), dark brown, Height: 65 mm, Width: 2 mm, |
| GTIN (EAN) | 4008190009052 | V-2, PA 66 |
| Qty. | 20 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | STB 18/RSF1 | Version |
| Order No. | 0286500000 | Socket (terminal), Plug-in depth: 15 mm, Depth: 23 mm |
| GTIN (EAN) | 4008190515591 | |
| Qty. | 20 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

General ordering data

| | | |
|------------|----------------------------|---------------------|
| Type | SS M3 D 128-A 3 | Version |
| Order No. | 0164400000 | Lock washer, Copper |
| GTIN (EAN) | 4008190035914 | |
| Qty. | 50 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | VH 17.5/5/3.4 | Version |
| Order No. | 0285200000 | Connecting sleeve (terminal), when screwed in, Width: 5 mm, Height: 5 mm, Depth: 17.5 mm, Number of poles: 1, Copper |
| GTIN (EAN) | 4008190054717 | |
| Qty. | 50 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Protection against contact



Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | ADP 2/HP2 1M | Version |
| Order No. | 0485300000 | SAK Series, Cover profile, Transparent, 1000 mm |
| GTIN (EAN) | 4008190051716 | |
| Qty. | 20 M | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKS2 | Version |
| Order No. | 0207800000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190144364 | poles: 2, Pitch in mm (P): 27.60, Insulated: No, Width: 40.6 mm |
| Qty. | 20 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 4 SAKS2 | Version |
| Order No. | 0208000000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190069100 | poles: 4, Pitch in mm (P): 27.60, Insulated: No, Width: 95.8 mm |
| Qty. | 20 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 10 SAKS2 | Version |
| Order No. | 0338900000 | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190105723 | poles: 10, Pitch in mm (P): 10.00, Insulated: No, Width: 261.4 mm |
| Qty. | 20 ST | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | AP SAK35/TW SAK16 | Version |
| Order No. | 0303660000 | End plate for terminals, beige, Height: 58 mm, Width: 1.5 mm, V-2, |
| GTIN (EAN) | 4008190110765 | PA 66, Snap-on: Yes |
| Qty. | 10 ST | |
| Type | AP SAK35/TW SAK16 BL | Version |
| Order No. | 0303680000 | End plate for terminals, blue, Height: 58 mm, Width: 1.5 mm, V-2, PA |
| GTIN (EAN) | 4008190025199 | 66, Snap-on: Yes |
| Qty. | 10 ST | |
| Type | TW SAK16 KRG | Version |
| Order No. | 0281120000 | Partition plate (terminal), dark beige, yellow, Height: 60 mm, Width: 3 |
| GTIN (EAN) | 4008190072360 | mm, V-0, KrG |
| Qty. | 20 ST | |
| Type | TW SAKS2 HP/DBR/2 | Version |
| Order No. | 0607000000 | Partition plate (terminal), dark brown, Height: 80 mm, Width: 2 mm, |
| GTIN (EAN) | 4008190002732 | V-2, PA 66 |
| Qty. | 20 ST | |
| Type | WTW EN | Version |
| Order No. | 1058800000 | Partition plate (terminal), dark beige, Height: 86 mm, Width: 3 mm, |
| GTIN (EAN) | 4008190140175 | V-0, Wemid |
| Qty. | 20 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Slotted screwdriver



Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

General ordering data

| | | | |
|------------|----------------------------|--------------------------|--|
| Type | SDS 1.0X5.5X150 | Version | |
| Order No. | 9008350000 | Screwdriver, Screwdriver | |
| GTIN (EAN) | 4032248056316 | | |
| Qty. | 1 ST | | |

Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

General ordering data

| | | | |
|------------|----------------------------|-----------------------------------|--|
| Type | E 16/10A RT TNDZ | Version | |
| Order No. | 0208500000 | Active components, Cartridge fuse | |
| GTIN (EAN) | 4008190067120 | | |
| Qty. | 25 ST | | |
| Type | E 16/16A GR TNDZ | Version | |
| Order No. | 0208600000 | Active components, Cartridge fuse | |
| GTIN (EAN) | 4008190015121 | | |
| Qty. | 25 ST | | |
| Type | E 16/20A BL TNDZ | Version | |
| Order No. | 0208700000 | Active components, Cartridge fuse | |
| GTIN (EAN) | 4008190044886 | | |
| Qty. | 25 ST | | |
| Type | E 16/25A GE TNDZ | Version | |
| Order No. | 0208800000 | Active components, Cartridge fuse | |
| GTIN (EAN) | 4008190037314 | | |
| Qty. | 25 ST | | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Fuse holder



The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

General ordering data

| | | |
|------------|----------------------------|----------------------------|
| Type | SK E14 SAKS4 | Version |
| Order No. | 0339410000 | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190032104 | |
| Qty. | 20 ST | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 2 SAKS4 | Version |
| Order No. | 0328000000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 2, Pitch in mm (P): 24.00, Insulated: No, Width: 34 mm |
| GTIN (EAN) | 4008190071165 | |
| Qty. | 20 ST | |
| Type | QL 3 SAKS4 | Version |
| Order No. | 0328100000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 3, Pitch in mm (P): 24.00, Insulated: No, Width: 58 mm |
| GTIN (EAN) | 4008190097639 | |
| Qty. | 20 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | QL 10 SAKS4 | Version |
| Order No. | 0339000000 | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190025335 | poles: 10, Pitch in mm (P): 10.00, Insulated: No, Width: 226 mm |
| Qty. | 20 ST | |

Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | E 14/2A RS | Version |
| Order No. | 0137400000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190069094 | |
| Qty. | 10 ST | |
| Type | E 14/4A BR | Version |
| Order No. | 0137500000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190142629 | |
| Qty. | 10 ST | |
| Type | E 14/6A GN | Version |
| Order No. | 0328300000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190002190 | |
| Qty. | 10 ST | |
| Type | E 14/10A RT | Version |
| Order No. | 0328400000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190000288 | |
| Qty. | 10 ST | |
| Type | E 14/16A GR | Version |
| Order No. | 0328500000 | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190152161 | |
| Qty. | 10 ST | |
| Type | P 14/2 D01 RS SAKS4 | Version |
| Order No. | 0138000000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190114664 | Aluminium, pink |
| Qty. | 50 ST | |
| Type | P 14/6 D01 GN SAKS4 | Version |
| Order No. | 0328600000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190004248 | Aluminium, green |
| Qty. | 50 ST | |
| Type | P 14/10 D01 RT SAKS4 | Version |
| Order No. | 0328700000 | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190010294 | Aluminium, red |
| Qty. | 50 ST | |


SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

End bracket

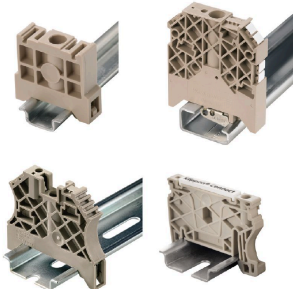

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | EWK 1 ALT | Version |
| Order No. | 0495160000 | End bracket, beige, TS 32, V-2, Polyamide 66, Width: 8 mm, 100 °C |
| GTIN (EAN) | 4008190160777 | |
| Qty. | 50 ST | |
| Type | EWK 2 | Version |
| Order No. | 0199360000 | End bracket, beige, TS 32, V-0, Wemid, Width: 15 mm, 100 °C |
| GTIN (EAN) | 4008190023546 | |
| Qty. | 50 ST | |
| Type | WEW 32/1 | Version |
| Order No. | 1067600000 | End bracket, dark beige, TS 32, V-2, PA 66 GF 30, Width: 12 mm, |
| GTIN (EAN) | 4008190099657 | 100 °C |
| Qty. | 50 ST | |

Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | G 25/0.25A/M GE | Version |
| Order No. | 0546900000 | Miniature fuse, medium time-lag, 0.25 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190097370 | |
| Qty. | 10 ST | |
| Type | G 25/0.50A/M WS | Version |
| Order No. | 0510300000 | Miniature fuse, medium time-lag, 0.5 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190018368 | |
| Qty. | 10 ST | |
| Type | G 25/0.80A/M GR | Version |
| Order No. | 0646400000 | Miniature fuse, medium time-lag, 0.8 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190060794 | |
| Qty. | 10 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | G 25/1.00A/M RT | Version |
| Order No. | 0265800000 | Miniature fuse, medium time-lag, 1 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190141660 | |
| Qty. | 10 ST | |
| Type | G 25/2.00A/F BL | Version |
| Order No. | 0192700000 | Miniature fuse, quick-acting, 2 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190176402 | |
| Qty. | 10 ST | |
| Type | G 25/4.00A/F BR | Version |
| Order No. | 0192800000 | Miniature fuse, quick-acting, 4 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190115319 | |
| Qty. | 10 ST | |
| Type | G 25/6.30A/F GN | Version |
| Order No. | 0192900000 | Miniature fuse, quick-acting, 6.3 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190135461 | |
| Qty. | 10 ST | |
| Type | G 25/10.0A/M RT | Version |
| Order No. | 0193100000 | Miniature fuse, medium time-lag, 10 A, G-Si. 5 x 25 |
| GTIN (EAN) | 4008190023799 | |
| Qty. | 10 ST | |

Mounting rail support

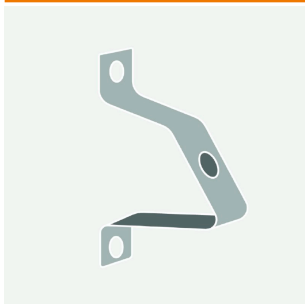

General ordering data

| | | |
|------------|----------------------------|--|
| Type | SH 2 | Version |
| Order No. | 0494920000 | Busbar support, medium yellow, 130 °C, Width: 40 mm, V-0, KrG, |
| GTIN (EAN) | 4008190007584 | when screwed in |
| Qty. | 10 ST | |

Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | VL 2 SAK6N/SAKT | Version |
| Order No. | 0194700000 | Cross-connector (terminal), when screwed in, grey, 32 A, Number of |
| GTIN (EAN) | 4008190148027 | poles: 2, Pitch in mm (P): 8.00, Insulated: No, Width: 7 mm |
| Qty. | 50 ST | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | HP NT6/10 BL | Version |
| Order No. | 0352880000 | End and partition plate for terminals, blue, Height: 40 mm, Width: 2 |
| GTIN (EAN) | 4008190135126 | mm, V-2, PA 66 |
| Qty. | 20 ST | |

Busbars



With our bus bars in various materials and the associated accessories, you can connect cables in the smallest installation space. Depending on the application, potentials can be collected, distributed or dissipated.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | ESCH 1 M | Version |
| Order No. | 0280300000 | Busbar (terminal), silver, Height: 12 mm, Depth: 2 mm, Steel |
| GTIN (EAN) | 4008190143053 | |
| Qty. | 10 M | |
| Type | NSCH 1M | Version |
| Order No. | 0280200000 | Busbar (terminal), Natural, Height: 15 mm, Depth: 2 mm, Copper |
| GTIN (EAN) | 4008190012953 | |
| Qty. | 10 M | |
| Type | SSCH 6X6X1000 CU/SN | Version |
| Order No. | 0571300000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 6 mm, Copper |
| GTIN (EAN) | 4008190015039 | |
| Qty. | 1 M | |
| Type | SSCH 7.3X1.2X1000 | Version |
| Order No. | 1071200000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 1.2 mm, Copper |
| GTIN (EAN) | 4008190279172 | |
| Qty. | 1 M | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | SSCH 10X3X1000 CU/SN | Version |
| Order No. | 0348900000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Copper |
| GTIN (EAN) | 4008190024802 | |
| Qty. | 25 M | |
| Type | SA 3.00X10.00X1000 CUZN... | Version |
| Order No. | 0259800000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Brass |
| GTIN (EAN) | 4008190049300 | |
| Qty. | 1 M | |
| Type | SSCH 15X6X1000 CU/SN | Version |
| Order No. | 0357400000 | Busbar (terminal), silver, Height: 1000 mm, Depth: 6 mm, Copper |
| GTIN (EAN) | 4008190169572 | |
| Qty. | 1 M | |

Testadapter and testsockets




Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|---------------------------------------|
| Type | PS 2.0 OR | Version |
| Order No. | 0293800000 | Test adapter (terminal), 230 V, 20 mA |
| GTIN (EAN) | 4008190042356 | |
| Qty. | 20 ST | |

Busbar connections

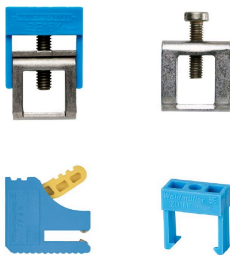

Weidmueller offers tapping terminals for various types of bus bar systems. Depending on the application, a distinction can be made here between insulated and non-insulated tap-off terminals.

General ordering data

| | | |
|------------|----------------------------|------------------------------|
| Type | ZB 4 | Version |
| Order No. | 0316500000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190061999 | |
| Qty. | 50 ST | |
| Type | ZB 4K BL | Version |
| Order No. | 0475380000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190010942 | |
| Qty. | 50 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|------------------------------|
| Type | ZB 4K GE/GN | Version |
| Order No. | 0475360000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190188047 | |
| Qty. | 50 ST | |
| Type | ZB 4K GG HENSEL | Version |
| Order No. | 1824560000 | Terminal (busbar connection) |
| GTIN (EAN) | 4032248330973 | |
| Qty. | 50 ST | |
| Type | ZB 4K SW | Version |
| Order No. | 0475310000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190008406 | |
| Qty. | 50 ST | |
| Type | ZB 4G BL | Version |
| Order No. | 0322180000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190050504 | |
| Qty. | 50 ST | |
| Type | ZB 4G GN/GE | Version |
| Order No. | 0322160000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190014278 | |
| Qty. | 50 ST | |
| Type | ZB 4G SW | Version |
| Order No. | 0322110000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190189310 | |
| Qty. | 50 ST | |
| Type | ZB 4/6 | Version |
| Order No. | 0556700000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190188412 | |
| Qty. | 50 ST | |
| Type | ZB 4/6K BL | Version |
| Order No. | 0565480000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190086831 | |
| Qty. | 50 ST | |
| Type | ZB 4/6K GE/GN | Version |
| Order No. | 0565460000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190032609 | |
| Qty. | 50 ST | |
| Type | ZB 16K BL | Version |
| Order No. | 0502880000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190014186 | |
| Qty. | 50 ST | |
| Type | ZB 16K GE/GN | Version |
| Order No. | 0502860000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190188795 | |
| Qty. | 50 ST | |
| Type | ZB 16K SW | Version |
| Order No. | 0502810000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190332563 | |
| Qty. | 50 ST | |
| Type | ZB 16 ZKSC | Version |
| Order No. | 0316600000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190145989 | |
| Qty. | 50 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|------------------------------|
| Type | ZB 35/M6X16 | Version |
| Order No. | 0266500000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190102814 | |
| Qty. | 20 ST | |
| Type | ZB 35K BL M6X16 | Version |
| Order No. | 0502680000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190004385 | |
| Qty. | 20 ST | |
| Type | ZB 35K GE/GN M6X16 | Version |
| Order No. | 0502660000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190052294 | |
| Qty. | 20 ST | |
| Type | ZB 35K SW M6X16 | Version |
| Order No. | 0502610000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190332587 | |
| Qty. | 20 ST | |

Testadapter and testsockets




Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | ZS 2.3/4 | Version |
| Order No. | 0249600000 | Plug (terminal), Plug-in connection, 4 mm ² , Number of connections: 1, |
| GTIN (EAN) | 4008190022785 | Number of poles: 4, Width: 6.5 mm |
| Qty. | 20 ST | |
| Type | FZS 2/4 RT/80 SAKT4 | Version |
| Order No. | 1276300000 | Plug (terminal), Plug-in connection, 2 mm ² , Number of connections: 2, |
| GTIN (EAN) | 4008190026080 | Number of poles: 1, Width: 9 mm |
| Qty. | 20 ST | |

Busbar connections

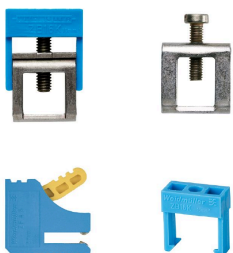

Weidmueller offers tapping terminals for various types of bus bar systems. Depending on the application, a distinction can be made here between insulated and non-insulated tap-off terminals.

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|------------------------------|
| Type | ZBE 6 | Version |
| Order No. | 0459500000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190032692 | |
| Qty. | 50 ST | |
| Type | ZBE 6K BL | Version |
| Order No. | 0525980000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190060886 | |
| Qty. | 50 ST | |
| Type | ZBE 6K GE/GN | Version |
| Order No. | 0525960000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190145026 | |
| Qty. | 50 ST | |
| Type | ZBE 6K SW | Version |
| Order No. | 0525910000 | Terminal (busbar connection) |
| GTIN (EAN) | 4008190977054 | |
| Qty. | 50 ST | |

Protection against contact



Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | IK 4 BL ZB4 | Version |
| Order No. | 0475480000 | Terminal cover, silver, Height: 19 mm, Width: 6 mm, Depth: 14.5 mm, V-2 |
| GTIN (EAN) | 4008190145668 | |
| Qty. | 50 ST | |
| Type | IK 4 GG ZB4 | Version |
| Order No. | 0475460000 | Cover hood (terminal), Polyamide 66 |
| GTIN (EAN) | 4008190065348 | |
| Qty. | 50 ST | |
| Type | IK 6 GG ZBE6K | Version |
| Order No. | 0526060000 | Cover hood (terminal), Steel |
| GTIN (EAN) | 4008190128647 | |
| Qty. | 50 ST | |
| Type | IK 16/ZB16 BL | Version |
| Order No. | 0502980000 | Cover hood (terminal) |
| GTIN (EAN) | 4008190159696 | |
| Qty. | 50 ST | |
| Type | IK 16/ZB16 GG | Version |
| Order No. | 0502960000 | Cover hood (terminal), Polyamide 66 |
| GTIN (EAN) | 4008190113438 | |
| Qty. | 50 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|-----------------------|
| Type | IK 35/ZB35 BL | Version |
| Order No. | 0502780000 | Cover hood (terminal) |
| GTIN (EAN) | 4008190141455 | |
| Qty. | 50 ST | |

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6 MC SDR | Version |
| Order No. | 1609830000 | Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 |
| GTIN (EAN) | 4008190456603 | Weidmueller, To customer specification |
| Qty. | 200 ST | |

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/6 MC NE WS | Version |
| Order No. | 1609820000 | Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 |
| GTIN (EAN) | 4008190203436 | Weidmueller, white |
| Qty. | 1000 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | TS 32X15/LL 2M/ST/ZN | Version | |
| Order No. | 0514400000 | Terminal rail, Accessories, Steel, galvanic zinc plated and passivated, | |
| GTIN (EAN) | 4008190086152 | Width: 2000 mm, Height: 33 mm, Depth: 15 mm | |
| Qty. | 20 M | | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | AP KSKM | Version | |
| Order No. | 9509630000 | SAK Series, End plate, 1.5 mm, beige, Direct mounting | |
| GTIN (EAN) | 4008190456771 | | |
| Qty. | 20 ST | | |

Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | VH 20/5/3.4 | Version | |
| Order No. | 0446100000 | Dummy fuse | |
| GTIN (EAN) | 4008190519742 | | |
| Qty. | 10 ST | | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | VH 25.4/6.3/4.3 | Version | |
| Order No. | 0446200000 | Dummy fuse | |
| GTIN (EAN) | 4008190519759 | | |
| Qty. | 10 ST | | |

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | DEK 5/8 MC NE WS | Version | |
| Order No. | 1856740000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 | |
| GTIN (EAN) | 4032248400850 | Weidmueller, white | |
| Qty. | 800 ST | | |

Accessories

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 MC SDR | Version |
| Order No. | 1856750000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248400867 | Weidmueller, To customer specification |
| Qty. | 160 ST | |

Plus



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 PLUS MC NE WS | Version |
| Order No. | 1046350000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248782055 | Weidmueller, white |
| Qty. | 800 ST | |

Accessories

Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/8 PLUS MC SDR | Version |
| Order No. | 1046370000 | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248782079 | Weidmueller, To customer specification |
| Qty. | 160 ST | |

DEK 5/8



WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

| | | |
|------------|----------------------------|--|
| Type | DEK 5/8 MM WS | Version |
| Order No. | 2007130000 | Dekafix, Terminal marker, 5 x 8 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392012 | |
| Qty. | 500 ST | |

SAKS 1/35/G20

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Marker holder

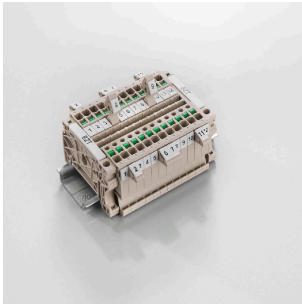

The marker holder offer the possibility of additional mounting of standard markers with a pitch of 5 or 5.1 mm. The angled holders can be optionally snapped together and could be mounted in all standard marking channels of the Klippon® Connect modular terminal blocks. Fitting marker types could be found under the respective accessories of the designation marking holder.

General ordering data

| | | |
|------------|----------------------------|----------------------------|
| Type | BZT 1 WS 10/5 | Version |
| Order No. | 1805490000 | Accessories, Marker holder |
| GTIN (EAN) | 4032248270231 | |
| Qty. | 100 ST | |
| Type | BZT 1 ZA WS 10/5 | Version |
| Order No. | 1805520000 | Accessories, Marker holder |
| GTIN (EAN) | 4032248270248 | |
| Qty. | 100 ST | |

DEK 5/6



WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

| | | |
|------------|----------------------------|--|
| Type | DEK 5/6 MM WS | Version |
| Order No. | 2007120000 | Dekafix, Terminal marker, 5 x 6 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392104 | |
| Qty. | 600 ST | |