

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Product image

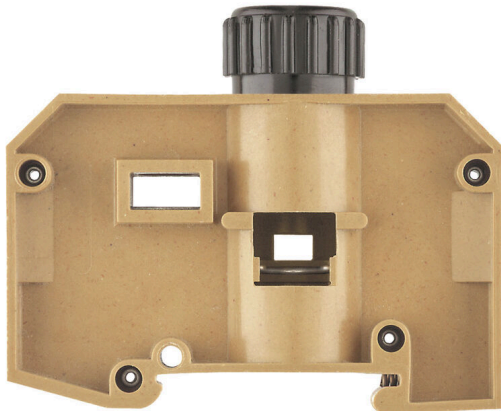

Fuse terminal blocks and component terminal blocks allow protective and functional elements to be integrated directly into the terminal strip. Fuse terminal blocks include built-in fuse holders to reliably protect electrical circuits against overload –ideal for control and distribution systems. Component terminal blocks make it possible to incorporate electronic components such as diodes, resistors, or LEDs directly into the wiring. This enables space-saving and clearly arranged implementation of switching functions and signal separation. Both types of terminal blocks ensure higher safety, easy maintenance, and a compact, function-oriented installation.

## General ordering data

|                     |  |
|---------------------|--|
| Version             | Fuse terminal, Screw connection, medium yellow, 10 mm <sup>2</sup> , 16 A, 400 V, Number of connections: 2, Number of levels: 1, TS 35 |
| Order No.           | <a href="#">0501820000</a>   |
| Type                | SAKS 4/35  |
| GTIN (EAN)          | 4008190090166  |
| Qty.                | 20 items   |
| Delivery status     | This article will no longer be available in the future.  |
| Last order date     | 2026-06-30T00:00:00+02:00  |
| Alternative product | <a href="#">SAKS 4/35 DB</a>   |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



|                       |                            |
|-----------------------|----------------------------|
| ROHS                  | Conform                    |
| UL File Number Search | <a href="#">UL Website</a> |
| Certificate No. (UR)  | E60693                     |

### Dimensions and weights

|                          |             |                |             |
|--------------------------|-------------|----------------|-------------|
| Depth                    | 65 mm       | Depth (inches) | 2.5591 inch |
| Depth including DIN rail | 66 mm       | Height         | 75 mm       |
| Height (inches)          | 2.9527 inch | Width          | 24 mm       |
| Width (inches)           | 0.9449 inch | Net weight     | 77.2 g      |

### Temperatures

|                                  |                |                                  |               |
|----------------------------------|----------------|----------------------------------|---------------|
| Storage temperature              | -25 °C...55 °C | Ambient temperature              | -5 °C...40 °C |
| Continuous operating temp., min. | -60 °C         | Continuous operating temp., max. | 130 °C        |

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### Material data

|                           |          |        |               |
|---------------------------|----------|--------|---------------|
| Basic material            | KrG      | Colour | medium yellow |
| UL 94 flammability rating | V-0, 5VA |        |               |

### System specifications

|                                     |   |                               |    |
|-------------------------------------|---|-------------------------------|----|
| Version                             | Screw connection, Fuse cartridge, for screwable cross-connection, One end without connector | End cover plate required      | No |
| Number of potentials                | 1   | Number of levels              | 1  |
| Number of clamping points per level | 2   | Number of potentials per tier | 1  |
| Levels cross-connected internally   | No  | PE connection                 | No |
| Mounting rail                       | TS 35   | N-function                    | No |
| PE function                         | No  | PEN function                  | No |

### Additional technical data

|                     |                 |                             |    |
|---------------------|-----------------|-----------------------------|----|
| Open sides          | closed          | Number of similar terminals | 1  |
| Installation advice | Direct mounting | Explosion-tested version    | No |
| Type of mounting    | Snap-on         |                             |    |

### CSA rating data

|                               |        |                       |           |
|-------------------------------|--------|-----------------------|-----------|
| Wire cross section max. (CSA) | 8 AWG  | Voltage size C (CSA)  | 600 V     |
| Current size C (CSA)          | 30 A   | Certificate No. (CSA) | 12400-188 |
| Voltage size B (CSA)          | 600 V  | Current size B (CSA)  | 30 A      |
| Voltage size D (CSA)          | 600 V  | Current size D (CSA)  | 5 A       |
| Wire cross section min. (CSA) | 22 AWG |                       |           |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Conductors for clamping (additional connection)

|  |                  |   |                    |
|--|------------------|---|--------------------|
| Connection direction additional connection | on side          | Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max. | 10 mm <sup>2</sup> |
| Connection type, additional connection     | Screw connection |   |                    |

## Conductors for clamping (rated connection)

|   |                      |   |                      |
|---|----------------------|---|----------------------|
| Gauge to IEC 60947-1  | B6                   | Wire connection cross section AWG, max.   | AWG 8                |
| Connection direction  | on side              | Tightening torque, max.   | 2.4 Nm               |
| Tightening torque, min.   | 1.2 Nm               | Stripping length  | 14 mm                |
| Type of connection 2  | Screw connection     | Type of connection  | Screw connection     |
| Number of connections   | 2                    | Clamping range, max.  | 16 mm <sup>2</sup>   |
| Clamping range, min.  | 0.33 mm <sup>2</sup> | Clamping screw  | M 4                  |
| Blade size  | 1.0 x 5.5 mm         | Wire connection cross section AWG, min.   | AWG 22               |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.33 mm <sup>2</sup> | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 10 mm <sup>2</sup>   |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 0.33 mm <sup>2</sup> | Wire connection cross section, finely stranded, max.                                    | 10 mm <sup>2</sup>   |
| Wire connection cross section, finely stranded, min.                                    | 0.33 mm <sup>2</sup> | Connection cross-section, stranded, max.  | 10 mm <sup>2</sup>   |
| Connection cross-section, stranded, min. 0.33 mm <sup>2</sup>                           |                      | Torque level with DMS electric screwdriver  | 4                    |
| Wire connection cross-section, solid core, max.   | 16 mm <sup>2</sup>   | Wire connection cross-section, solid core, min.   | 0.33 mm <sup>2</sup> |
| Connection cross-section, finely stranded, min.   | 0.33 mm <sup>2</sup> |   |                      |

## Fuse terminals

|                               |       |                                |                  |
|-------------------------------|-------|--------------------------------|------------------|
| Cartridge fuse                | E14   | Fuse holder (cartridge holder) | for screw fixing |
| Type of voltage for indicator | AC/DC | Display                        | Without LED      |
| Operating voltage, max.       | 400 V |                                |                  |

## General

|   |        |                     |                 |
|---|--------|---------------------|-----------------|
| Wire connection cross section AWG, max. | AWG 8  | Installation advice | Direct mounting |
| Wire connection cross section AWG, min. | AWG 22 | Standards           | IEC 60947-7-3   |
| Mounting rail                           | TS 35  |                     |                 |

## Rating data

|  |                    |                                 |               |
|--|--------------------|---------------------------------|---------------|
| Rated cross-section                          | 10 mm <sup>2</sup> | Rated voltage                   | 400 V         |
| Rated DC voltage                             | 400 V              | Nominal current                 | 16 A          |
| Current at maximum wires                     | 16 A               | Standards                       | IEC 60947-7-3 |
| Volume resistance according to IEC 60947-7-x | 0.56 mΩ            | Rated impulse withstand voltage | 6 kV          |
| Power loss in accordance with IEC 60947-7-x  | 1.82 W             | Pollution severity              | 3             |

**Technical data****UL rating data**

|   |        |   |        |
|---|--------|---|--------|
| Conductor size Factory wiring max. (UR) | 8 AWG  | Current size C (UR)                     | 30 A   |
| Voltage size C (UR)                     | 600 V  | Conductor size Factory wiring min. (UR) | 26 AWG |
| Certificate No. (UR)                    | E60693 | Conductor size Field wiring min. (UR)   | 22 AWG |
| Conductor size Field wiring max. (UR)   | 8 AWG  |   |        |

**Important note**

Product information                      The voltage depends on the selected fuse element or the selected indicator light

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000899    | ETIM 9.0    | EC000899    |
| ETIM 10.0   | EC000899    | ECLASS 14.0 | 27-25-01-13 |
| ECLASS 15.0 | 27-25-01-13 |             |             |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Disconnect plugs




In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 2 SAKS4                 | Version  |
| Order No.  | <a href="#">0328000000</a> | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 2, Pitch in mm (P): 24.00, Insulated: No, Width: 34 mm |
| GTIN (EAN) | 4008190071165              |  |
| Qty.       | 20 ST                      |  |
| Type       | QL 3 SAKS4                 | Version  |
| Order No.  | <a href="#">0328100000</a> | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 3, Pitch in mm (P): 24.00, Insulated: No, Width: 58 mm |
| GTIN (EAN) | 4008190097639              |  |
| Qty.       | 20 ST                      |  |

## Cross-connections

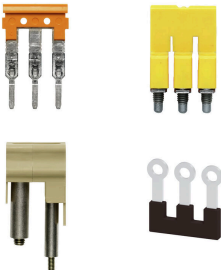

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 10 SAKS4                | Version  |
| Order No.  | <a href="#">0339000000</a> | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 10, Pitch in mm (P): 10.00, Insulated: No, Width: 226 mm |
| GTIN (EAN) | 4008190025335              |  |
| Qty.       | 20 ST                      |  |

## Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | BFSC M4X9T                 | Version   |
| Order No.  | <a href="#">0103300000</a> | Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 mm, Height: 9 mm |
| GTIN (EAN) | 4008190023348              |   |
| Qty.       | 100 ST                     |   |
| Type       | SS M4 D 128-A 4            | Version   |
| Order No.  | <a href="#">0136400000</a> | Lock washer, Copper   |
| GTIN (EAN) | 4008190118143              |   |
| Qty.       | 100 ST                     |   |

## Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | E 14/2A RS                 | Version   |
| Order No.  | <a href="#">0137400000</a> | Active components, Cartridge fuse   |
| GTIN (EAN) | 4008190069094              |   |
| Qty.       | 10 ST                      |   |
| Type       | E 14/4A BR                 | Version   |
| Order No.  | <a href="#">0137500000</a> | Active components, Cartridge fuse   |
| GTIN (EAN) | 4008190142629              |   |
| Qty.       | 10 ST                      |   |
| Type       | E 14/6A GN                 | Version   |
| Order No.  | <a href="#">0328300000</a> | Active components, Cartridge fuse   |
| GTIN (EAN) | 4008190002190              |   |
| Qty.       | 10 ST                      |   |
| Type       | E 14/10A RT                | Version   |
| Order No.  | <a href="#">0328400000</a> | Active components, Cartridge fuse   |
| GTIN (EAN) | 4008190000288              |   |
| Qty.       | 10 ST                      |   |
| Type       | E 14/16A GR                | Version   |
| Order No.  | <a href="#">0328500000</a> | Active components, Cartridge fuse   |
| GTIN (EAN) | 4008190152161              |   |
| Qty.       | 10 ST                      |   |
| Type       | P 14/2 D01 RS SAKS4        | Version   |
| Order No.  | <a href="#">0138000000</a> | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, Aluminium, pink  |
| GTIN (EAN) | 4008190114664              |   |
| Qty.       | 50 ST                      |   |
| Type       | P 14/6 D01 GN SAKS4        | Version   |
| Order No.  | <a href="#">0328600000</a> | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, Aluminium, green |
| GTIN (EAN) | 4008190004248              |   |
| Qty.       | 50 ST                      |   |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | P 14/10 D01 RT SAKS4       | Version  |
| Order No.  | <a href="#">0328700000</a> | Fuse gauge ring (terminal), Height: 11 mm, Depth: 10.5 mm, |
| GTIN (EAN) | 4008190010294              | Aluminium, red   |
| Qty.       | 50 ST                      |  |

## Fuse holder



The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

## General ordering data

|            |                            |                            |
|------------|----------------------------|----------------------------|
| Type       | SK E14 SAKS4               | Version                    |
| Order No.  | <a href="#">0339410000</a> | Screw cover cap (terminal) |
| GTIN (EAN) | 4008190032104              |                            |
| Qty.       | 20 ST                      |                            |

## Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | DEK 5/5 MC SDR             | Version   |
| Order No.  | <a href="#">1609810000</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190456597              | Weidmueller, To customer specification                    |
| Qty.       | 200 ST                     |   |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

## Accessories

www.weidmueller.com

## Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.


Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | DEK 5/5 MC NE WS           | Version   |
| Order No.  | <a href="#">1609801044</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397111              | Weidmueller, white  |
| Qty.       | 1000 ST                    |   |

## SchT group marker carrier

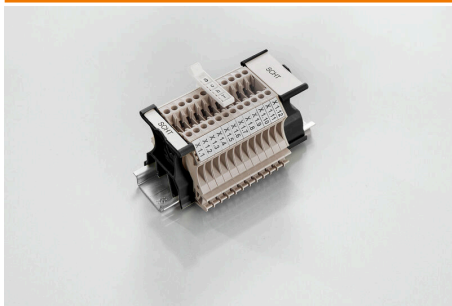

The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw. The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

Inlay tags and protective strips can be found under "Accessories".

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | SCHT 7                     | Version   |
| Order No.  | <a href="#">0517960000</a> | SCHT, Terminal marker, 39.3 x 8 mm, Pitch in mm (P): 7.00 |
| GTIN (EAN) | 4008190001742              | Weidmueller, white  |
| Qty.       | 20 ST                      |   |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

## Accessories

www.weidmueller.com

## End bracket



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | EW 35                      | Version  |  |
| Order No.  | <a href="#">0383560000</a> | End bracket, beige, TS 35, V-2, Wemid, Width: 8.5 mm, 100 °C |  |
| GTIN (EAN) | 4008190181314              |  |  |
| Qty.       | 50 ST                      |  |  |
| Type       | EWK 1                      | Version  |  |
| Order No.  | <a href="#">0206160000</a> | End bracket, beige, TS 32, V-0, Wemid, Width: 9 mm, 100 °C   |  |
| GTIN (EAN) | 4008190080020              |  |  |
| Qty.       | 50 ST                      |  |  |

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | Q 2 SAK10                  | Version  |  |
| Order No.  | <a href="#">0457100000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 2, Pitch in mm (P): 9.90, Insulated: No, Width: 16.9 mm  |  |
| GTIN (EAN) | 4008190103545              |  |  |
| Qty.       | 50 ST                      |  |  |
| Type       | Q 3 SAK10                  | Version  |  |
| Order No.  | <a href="#">0457200000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 3, Pitch in mm (P): 9.90, Insulated: No, Width: 26.8 mm  |  |
| GTIN (EAN) | 4008190135379              |  |  |
| Qty.       | 50 ST                      |  |  |
| Type       | Q 4 SAK10                  | Version  |  |
| Order No.  | <a href="#">0457300000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 4, Pitch in mm (P): 9.90, Insulated: No, Width: 36.7 mm  |  |
| GTIN (EAN) | 4008190129750              |  |  |
| Qty.       | 50 ST                      |  |  |
| Type       | Q 10 SAK10                 | Version  |  |
| Order No.  | <a href="#">0457400000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 10, Pitch in mm (P): 9.90, Insulated: No, Width: 96.1 mm |  |
| GTIN (EAN) | 4008190016166              |  |  |
| Qty.       | 20 ST                      |  |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

#### General ordering data

|            |                            |                                |  |
|------------|----------------------------|--------------------------------|--|
| Type       | PS 4 F.STB 4               | Version                        |  |
| Order No.  | <a href="#">0299600000</a> | Test adapter (terminal), 230 V |  |
| GTIN (EAN) | 4008190074043              |                                |  |
| Qty.       | 20 ST                      |                                |  |

### Mounting support




We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

#### General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | BFSC M3X22 PA/RT           | Version   |  |
| Order No.  | <a href="#">0128900000</a> | Mounting screw (Terminal), 3.00 mm, Polyamide 66, Depth: 4.8 mm, Width: 4.8 mm, Height: 22 mm |  |
| GTIN (EAN) | 4008190084158              |   |  |
| Qty.       | 100 ST                     |   |  |
| Type       | BFSC M3X25                 | Version   |  |
| Order No.  | <a href="#">0292500000</a> | Mounting screw (Terminal), 3.00 mm, Steel, Depth: 4.8 mm, Width: 4.8 mm, Height: 25 mm        |  |
| GTIN (EAN) | 4008190177027              |   |  |
| Qty.       | 100 ST                     |   |  |

### Cross-connections

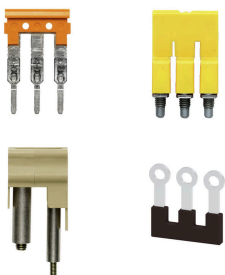

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany


www.weidmueller.com

## Accessories

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | VH 19/5/3.4                | Version  |
| Order No.  | <a href="#">0285100000</a> | Connecting sleeve (terminal), when screwed in, Width: 5 mm, Height: 5 mm, Depth: 17.5, Number of poles: 1, Cu Zn                 |
| GTIN (EAN) | 4008190189297              |  |
| Qty.       | 50 ST                      |  |
| Type       | VL 2 SAK6/10/SAKB          | Version  |
| Order No.  | <a href="#">0135900000</a> | Cross-connector (terminal), when screwed in, grey, 32 A, Number of poles: 2, Pitch in mm (P): 6.50, Insulated: No, Width: 1.5 mm |
| GTIN (EAN) | 4008190036409              |  |
| Qty.       | 50 ST                      |  |

## Warning cover

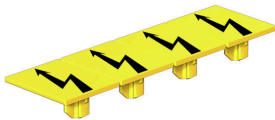

Warning covers with a flash symbol provide more safety for man and machine. They are used where external voltage must be indicated within the application.

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | AD 4 SAK10                 | Version   |
| Order No.  | <a href="#">0178600000</a> | Terminal cover, yellow, PVC, Height: 39.6 mm, Width: 25 mm, Depth: 1 mm, HB |
| GTIN (EAN) | 4008190068288              |   |
| Qty.       | 50 ST                      |   |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 2 SAKB 10               | Version  |
| Order No.  | <a href="#">0114100000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 2, Pitch in mm (P): 10.00, Insulated: No, Width: 17 mm |
| GTIN (EAN) | 4008190056605              |  |
| Qty.       | 100 ST                     |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | QL 10 SAKB10               | Version  |  |
| Order No.  | <a href="#">0338400000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |  |
| GTIN (EAN) | 4008190139452              | poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 97 mm      |  |
| Qty.       | 20 ST                      |  |  |

## End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | AP SAKB/C/T KR             | Version  |  |
| Order No.  | <a href="#">0146720000</a> | End plate for terminals, dark beige, yellow, Height: 65 mm, Width: 3 |  |
| GTIN (EAN) | 4008190027995              | mm, V-0, KrG, Snap-on: Yes   |  |
| Qty.       | 20 ST                      |  |  |

## Accessorie



**Current and voltage transformer wiring**  
 Our test disconnect terminal blocks featuring spring and screw connection technology allow you to create all the important converter circuits for measuring current, voltage and power in a safe and sophisticated way.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | TW SAKB/C/T                | Version   |  |
| Order No.  | <a href="#">0242920000</a> | Partition plate (terminal), beige, Height: 75 mm, Width: 3 mm, V-2, |  |
| GTIN (EAN) | 4008190069933              | KrG   |  |
| Qty.       | 20 ST                      |   |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 2 SAKH10                | Version  |
| Order No.  | <a href="#">0131400000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 2, Pitch in mm (P): 14.00, Insulated: No, Width: 16.9 mm |
| GTIN (EAN) | 4008190114237              |  |
| Qty.       | 50 ST                      |  |
| Type       | QL 3 SAKH10                | Version  |
| Order No.  | <a href="#">0131500000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 3, Pitch in mm (P): 14.00, Insulated: No, Width: 26.8 mm |
| GTIN (EAN) | 4008190056490              |  |
| Qty.       | 50 ST                      |  |
| Type       | QL 10 SAKH10               | Version  |
| Order No.  | <a href="#">0338700000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 96.1 mm |
| GTIN (EAN) | 4008190039424              |  |
| Qty.       | 20 ST                      |  |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | VH 12/4.9/3.3              | Version  |
| Order No.  | <a href="#">0249000000</a> | Connecting sleeve (terminal), when screwed in, Width: 4.9 mm, Height: 4.9 mm, Depth: 12 mm, Number of poles: 1, Copper |
| GTIN (EAN) | 4008190129507              |  |
| Qty.       | 100 ST                     |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

### General ordering data

|            |                            |         |                                    |
|------------|----------------------------|---------|------------------------------------|
| Type       | KISC M3X20 SAK10 CU5       | Version |                                    |
| Order No.  | <a href="#">0377100000</a> | Version | SAK Series, Mounting screw, Copper |
| GTIN (EAN) | 4008190060350              |         |                                    |
| Qty.       | 100 ST                     |         |                                    |

### Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

### General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | QL 2 SAKA10                | Version |  |
| Order No.  | <a href="#">0135500000</a> | Version | Cross-connector (terminal), when screwed in, grey, 32 A, Number of poles: 2, Pitch in mm (P): 12.00, Insulated: No, Width: 19.9 mm |
| GTIN (EAN) | 4008190099404              |         |  |
| Qty.       | 50 ST                      |         |  |
| Type       | QL 3 SAKA10                | Version |  |
| Order No.  | <a href="#">0135600000</a> | Version | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 3, Pitch in mm (P): 12.00, Insulated: No, Width: 31.8 mm |
| GTIN (EAN) | 4008190032081              |         |  |
| Qty.       | 50 ST                      |         |  |
| Type       | QL 4 SAKA10                | Version |  |
| Order No.  | <a href="#">0135700000</a> | Version | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 4, Pitch in mm (P): 12.00, Insulated: No, Width: 43.7 mm |
| GTIN (EAN) | 4008190118822              |         |  |
| Qty.       | 50 ST                      |         |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | QL 10 SAKA10               | Version  |  |
| Order No.  | <a href="#">0338500000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of |  |
| GTIN (EAN) | 4008190063313              | poles: 10, Pitch in mm (P): 6.00, Insulated: No, Width: 115.1 mm   |  |
| Qty.       | 20 ST                      |  |  |

## End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | AP SAKA KRG                | Version  |  |
| Order No.  | <a href="#">0134220000</a> | End plate for terminals, dark beige, yellow, Height: 82 mm, Width: 3 |  |
| GTIN (EAN) | 4008190167943              | mm, V-0, KrG, Snap-on: Yes   |  |
| Qty.       | 20 ST                      |  |  |

## Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

## General ordering data

|            |                            |                    |  |
|------------|----------------------------|--------------------|--|
| Type       | STB 13.5/D6/4/M4 SAKA10    | Version            |  |
| Order No.  | <a href="#">0135200000</a> | SAK Series, Socket |  |
| GTIN (EAN) | 4008190172862              |                    |  |
| Qty.       | 50 ST                      |                    |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | BFSC M4X30                 | Version  |  |
| Order No.  | <a href="#">0267100000</a> | Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 mm, Height: 30 mm |  |
| GTIN (EAN) | 4008190187897              |  |  |
| Qty.       | 50 ST                      |  |  |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | VL 2 SAK 16/SAKA           | Version   |  |
| Order No.  | <a href="#">0135800000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 2, Pitch in mm (P): 12.00, Insulated: No, Width: 8 mm |  |
| GTIN (EAN) | 4008190132088              |   |  |
| Qty.       | 50 ST                      |   |  |

## Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

## General ordering data

|            |                            |                                       |  |
|------------|----------------------------|---------------------------------------|--|
| Type       | PS 2.3 RT                  | Version                               |  |
| Order No.  | <a href="#">0180400000</a> | Test adapter (terminal), 230 V, 20 mA |  |
| GTIN (EAN) | 4008190060121              |                                       |  |
| Qty.       | 20 ST                      |                                       |  |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | BFSC M4X20                 | Version  |  |
| Order No.  | <a href="#">0362800000</a> | Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 mm, Height: 20 mm |  |
| GTIN (EAN) | 4008190114053              |  |  |
| Qty.       | 100 ST                     |  |  |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | VH 13.6/6.3/4.3            | Version   |  |
| Order No.  | <a href="#">0299700000</a> | Connecting sleeve (terminal), when screwed in, Width: 7 mm, Height: 7 mm, Depth: 13.6 mm, Number of poles: 1, Cu Zn |  |
| GTIN (EAN) | 4008190018313              |   |  |
| Qty.       | 50 ST                      |   |  |

## Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | DEK 5/6.5 MC SDR           | Version   |
| Order No.  | <a href="#">1609850000</a> | Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50 |
| GTIN (EAN) | 4008190456610              | Weidmueller, To customer specification                      |
| Qty.       | 180 ST                     |   |

## Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.


Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | DEK 5/6.5 MC NE WS         | Version   |
| Order No.  | <a href="#">1609840000</a> | Dekafix, Terminal marker, 5 x 6.5 mm, Pitch in mm (P): 6.50 |
| GTIN (EAN) | 4008190203429              | Weidmueller, white  |
| Qty.       | 900 ST                     |   |

## Cross-connections

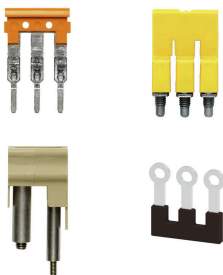

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 2 RSF 1+2               | Version  |
| Order No.  | <a href="#">0267400000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 2, Pitch in mm (P): 11.00, Insulated: No, Width: 18 mm |
| GTIN (EAN) | 4008190139988              |  |
| Qty.       | 50 ST                      |  |
| Type       | QL 3 RSF 1+2               | Version  |
| Order No.  | <a href="#">0267500000</a> | Cross-connector (terminal), when screwed in, grey, 57 A, Number of poles: 3, Pitch in mm (P): 11.00, Insulated: No, Width: 29 mm |
| GTIN (EAN) | 4008190116835              |  |
| Qty.       | 50 ST                      |  |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 4 RSF1+2                | Version  |
| Order No.  | <a href="#">0267600000</a> | Cross-connector (terminal), when screwed in, grey, 41 A, Number of |
| GTIN (EAN) | 4008190174859              | poles: 4, Pitch in mm (P): 11.00, Insulated: No, Width: 40 mm      |
| Qty.       | 50 ST                      |  |

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 10 RSF1+2               | Version  |
| Order No.  | <a href="#">0341700000</a> | Cross-connector (terminal), when screwed in, grey, 20 A, Number of |
| GTIN (EAN) | 4008190003173              | poles: 10, Pitch in mm (P): 8.00, Insulated: No, Width: 106 mm     |
| Qty.       | 20 ST                      |  |

## End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | AP RSF1 KR                 | Version   |
| Order No.  | <a href="#">0270420000</a> | End plate for terminals, medium yellow, Height: 50 mm, Width: 3 mm,   |
| GTIN (EAN) | 4008190099107              | V-0, KrG, Snap-on: Yes  |
| Qty.       | 10 ST                      |   |
| Type       | TW AST1/PA HP/DBR/0.5      | Version   |
| Order No.  | <a href="#">0474700000</a> | Partition plate (terminal), dark brown, Height: 65 mm, Width: 0.5 mm, |
| GTIN (EAN) | 4008190078508              | V-2   |
| Qty.       | 20 ST                      |   |
| Type       | TW DK4 HP/DBR/2            | Version   |
| Order No.  | <a href="#">3833500000</a> | Partition plate (terminal), dark brown, Height: 65 mm, Width: 2 mm,   |
| GTIN (EAN) | 4008190009052              | V-2, PA 66  |
| Qty.       | 20 ST                      |   |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | STB 18/RSF1                | Version   |  |
| Order No.  | <a href="#">0286500000</a> | Socket (terminal), Plug-in depth: 15 mm, Depth: 23 mm |  |
| GTIN (EAN) | 4008190515591              |   |  |
| Qty.       | 20 ST                      |   |  |

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |                     |  |
|------------|----------------------------|---------------------|--|
| Type       | SS M3 D 128-A 3            | Version             |  |
| Order No.  | <a href="#">0164400000</a> | Lock washer, Copper |  |
| GTIN (EAN) | 4008190035914              |                     |  |
| Qty.       | 50 ST                      |                     |  |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | VH 17.5/5/3.4              | Version  |  |
| Order No.  | <a href="#">0285200000</a> | Connecting sleeve (terminal), when screwed in, Width: 5 mm, Height: 5 mm, Depth: 17.5 mm, Number of poles: 1, Copper |  |
| GTIN (EAN) | 4008190054717              |  |  |
| Qty.       | 50 ST                      |  |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Protection against contact



Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | ADP 2/HP2 1M               | Version   |  |
| Order No.  | <a href="#">0485300000</a> | SAK Series, Cover profile, Transparent, 1000 mm |  |
| GTIN (EAN) | 4008190051716              |   |  |
| Qty.       | 1 M                        |   |  |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | QL 2 SAKS2                 | Version  |  |
| Order No.  | <a href="#">0207800000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 2, Pitch in mm (P): 27.60, Insulated: No, Width: 40.6 mm   |  |
| GTIN (EAN) | 4008190144364              |  |  |
| Qty.       | 20 ST                      |  |  |
| Type       | QL 4 SAKS2                 | Version  |  |
| Order No.  | <a href="#">0208000000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 4, Pitch in mm (P): 27.60, Insulated: No, Width: 95.8 mm   |  |
| GTIN (EAN) | 4008190069100              |  |  |
| Qty.       | 20 ST                      |  |  |
| Type       | QL 10 SAKS2                | Version  |  |
| Order No.  | <a href="#">0338900000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of poles: 10, Pitch in mm (P): 10.00, Insulated: No, Width: 261.4 mm |  |
| GTIN (EAN) | 4008190105723              |  |  |
| Qty.       | 20 ST                      |  |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## End plates and partition plates




Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | WTW EN                     | Version   |  |
| Order No.  | <a href="#">1058800000</a> | Partition plate (terminal), dark beige, Height: 86 mm, Width: 3 mm, |  |
| GTIN (EAN) | 4008190140175              | V-0, Wemid  |  |
| Qty.       | 20 ST                      |   |  |

## Slotted screwdriver

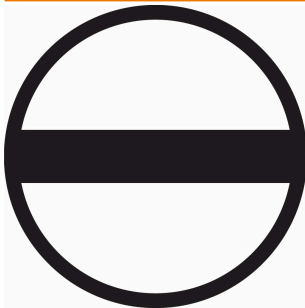

Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

## General ordering data

|            |                            |                          |  |
|------------|----------------------------|--------------------------|--|
| Type       | SDS 1.0X5.5X150            | Version                  |  |
| Order No.  | <a href="#">9008350000</a> | Screwdriver, Screwdriver |  |
| GTIN (EAN) | 4032248056316              |                          |  |
| Qty.       | 1 ST                       |                          |  |

## Fuse



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

## General ordering data

|            |                            |                                   |  |
|------------|----------------------------|-----------------------------------|--|
| Type       | E 16/10A RT TNDZ           | Version                           |  |
| Order No.  | <a href="#">0208500000</a> | Active components, Cartridge fuse |  |
| GTIN (EAN) | 4008190067120              |                                   |  |
| Qty.       | 25 ST                      |                                   |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |                                   |
|------------|----------------------------|-----------------------------------|
| Type       | E 16/16A GR TNDZ           | Version                           |
| Order No.  | <a href="#">0208600000</a> | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190015121              |                                   |
| Qty.       | 25 ST                      |                                   |
| Type       | E 16/20A BL TNDZ           | Version                           |
| Order No.  | <a href="#">0208700000</a> | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190044886              |                                   |
| Qty.       | 25 ST                      |                                   |
| Type       | E 16/25A GE TNDZ           | Version                           |
| Order No.  | <a href="#">0208800000</a> | Active components, Cartridge fuse |
| GTIN (EAN) | 4008190037314              |                                   |
| Qty.       | 25 ST                      |                                   |

## Disconnect plugs




In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 2 SAKS1                 | Version  |
| Order No.  | <a href="#">0191400000</a> | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 2, Pitch in mm (P): 13.00, Insulated: No, Width: 18.9 mm |
| GTIN (EAN) | 4008190123130              |  |
| Qty.       | 50 ST                      |  |

## Cross-connections

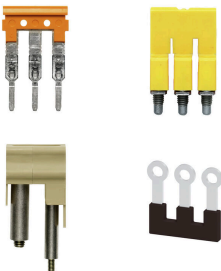

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 3 SAKS1                 | Version  |
| Order No.  | <a href="#">0191500000</a> | Cross-connector (terminal), when screwed in, grey, 47 A, Number of poles: 3, Pitch in mm (P): 13.00, Insulated: No, Width: 31.9 mm |
| GTIN (EAN) | 4008190036881              |  |
| Qty.       | 50 ST                      |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 4 SAKS1                 | Version  |
| Order No.  | <a href="#">0191600000</a> | Cross-connector (terminal), when screwed in, grey, 47 A, Number of |
| GTIN (EAN) | 4008190105518              | poles: 4, Pitch in mm (P): 13.00, Insulated: No, Width: 44.7 mm    |
| Qty.       | 20 ST                      |  |

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | QL 10 SAKS1                | Version  |
| Order No.  | <a href="#">0338800000</a> | Cross-connector (terminal), when screwed in, grey, 36 A, Number of |
| GTIN (EAN) | 4008190127039              | poles: 10, Pitch in mm (P): 13.00, Insulated: No, Width: 122.1 mm  |
| Qty.       | 20 ST                      |  |

## End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | AP SAKS1+3 KR              | Version  |
| Order No.  | <a href="#">0191320000</a> | End plate for terminals, dark beige, yellow, Height: 54 mm, Width: 3 |
| GTIN (EAN) | 4008190031688              | mm, V-O, KrG, Snap-on: Yes   |
| Qty.       | 20 ST                      |  |

## SAKS 4/35


**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |   |
|------------|----------------------------|---|
| Type       | AP SAKS1+3 KRG/DB          | Version   |
| Order No.  | <a href="#">0191300000</a> | End plate for terminals, dark beige, Height: 54 mm, Width: 3 mm, V-0, KrG, Snap-on: Yes |
| GTIN (EAN) | 4008190099763              |   |
| Qty.       | 20 ST                      |   |

### End bracket

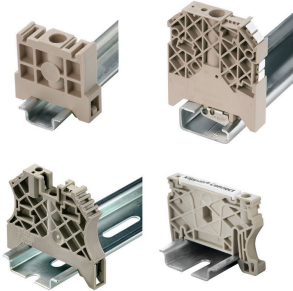

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

### General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | EWK 1 ALT                  | Version  |
| Order No.  | <a href="#">0495160000</a> | End bracket, beige, TS 32, V-2, Polyamide 66, Width: 8 mm, 100 °C      |
| GTIN (EAN) | 4008190160777              |  |
| Qty.       | 50 ST                      |  |
| Type       | EWK 2                      | Version  |
| Order No.  | <a href="#">0199360000</a> | End bracket, beige, TS 32, V-0, Wemid, Width: 15 mm, 100 °C            |
| GTIN (EAN) | 4008190023546              |  |
| Qty.       | 50 ST                      |  |
| Type       | WEW 32/1                   | Version  |
| Order No.  | <a href="#">1067600000</a> | End bracket, dark beige, TS 32, V-2, PA 66 GF 30, Width: 12 mm, 100 °C |
| GTIN (EAN) | 4008190099657              |  |
| Qty.       | 50 ST                      |  |

### Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

### General ordering data

|            |                            |                                      |
|------------|----------------------------|--------------------------------------|
| Type       | KISC M3X6 SAKS1            | Version                              |
| Order No.  | <a href="#">0346200000</a> | Clamping yoke, Mounting screw, Steel |
| GTIN (EAN) | 4008190175658              |                                      |
| Qty.       | 100 ST                     |                                      |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Mounting rail support



## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | SH 2                       | Version  |  |
| Order No.  | <a href="#">0494920000</a> | Busbar support, medium yellow, 130 °C, Width: 40 mm, V-0, KrG, |  |
| GTIN (EAN) | 4008190007584              | when screwed in  |  |
| Qty.       | 10 ST                      |  |  |

## Disconnect plugs



In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | VL 2 SAK6N/SAKT            | Version  |  |
| Order No.  | <a href="#">0194700000</a> | Cross-connector (terminal), when screwed in, grey, 32 A, Number of |  |
| GTIN (EAN) | 4008190148027              | poles: 2, Pitch in mm (P): 8.00, Insulated: No, Width: 7 mm        |  |
| Qty.       | 50 ST                      |  |  |

## End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | HP NT6/10 BL               | Version  |  |
| Order No.  | <a href="#">0352880000</a> | End and partition plate for terminals, blue, Height: 40 mm, Width: 2 |  |
| GTIN (EAN) | 4008190135126              | mm, V-2, PA 66   |  |
| Qty.       | 20 ST                      |  |  |

## Accessories

### Busbars



With our bus bars in various materials and the associated accessories, you can connect cables in the smallest installation space. Depending on the application, potentials can be collected, distributed or dissipated.

### General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | ESCH 1 M                   | Version   |
| Order No.  | <a href="#">0280300000</a> | Busbar (terminal), silver, Height: 12 mm, Depth: 2 mm, Steel      |
| GTIN (EAN) | 4008190143053              |   |
| Qty.       | 10 M                       |   |
| Type       | NSCH 1M                    | Version   |
| Order No.  | <a href="#">0280200000</a> | Busbar (terminal), Natural, Height: 15 mm, Depth: 2 mm, Copper    |
| GTIN (EAN) | 4008190012953              |   |
| Qty.       | 10 M                       |   |
| Type       | SSCH 6X6X1000 CU/SN        | Version   |
| Order No.  | <a href="#">0571300000</a> | Busbar (terminal), silver, Height: 1000 mm, Depth: 6 mm, Copper   |
| GTIN (EAN) | 4008190015039              |   |
| Qty.       | 1 M                        |   |
| Type       | SSCH 7.3X1.2X1000          | Version   |
| Order No.  | <a href="#">1071200000</a> | Busbar (terminal), silver, Height: 1000 mm, Depth: 1.2 mm, Copper |
| GTIN (EAN) | 4008190279172              |   |
| Qty.       | 1 M                        |   |
| Type       | SSCH 10X3X1000 CU/SN       | Version   |
| Order No.  | <a href="#">0348900000</a> | Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Copper   |
| GTIN (EAN) | 4008190024802              |   |
| Qty.       | 25 M                       |   |
| Type       | SA 3.00X10.00X1000 CUZN... | Version   |
| Order No.  | <a href="#">0259800000</a> | Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Brass    |
| GTIN (EAN) | 4008190049300              |   |
| Qty.       | 1 M                        |   |

 
## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

### General ordering data

|            |                            |         |   |
|------------|----------------------------|---------|---|
| Type       | DEK 5/6 MC SDR             | Version |   |
| Order No.  | <a href="#">1609830000</a> | Version | Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 |
| GTIN (EAN) | 4008190456603              | Version | Weidmueller, To customer specification                    |
| Qty.       | 200 ST                     |         |   |

### Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

### General ordering data

|            |                            |         |   |
|------------|----------------------------|---------|---|
| Type       | DEK 5/6 MC NE WS           | Version |   |
| Order No.  | <a href="#">1609820000</a> | Version | Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 |
| GTIN (EAN) | 4008190203436              | Version | Weidmueller, white  |
| Qty.       | 1000 ST                    |         |   |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | TS 32X15/LL 2M/ST/ZN       | Version   |  |
| Order No.  | <a href="#">0514400000</a> | Terminal rail, Accessories, Steel, galvanic zinc plated and passivated, |  |
| GTIN (EAN) | 4008190086152              | Width: 2000 mm, Height: 33 mm, Depth: 15 mm                             |  |
| Qty.       | 20 M                       |   |  |

## End plates and partition plates




Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | AP KSKM                    | Version   |  |
| Order No.  | <a href="#">9509630000</a> | SAK Series, End plate, 1.5 mm, beige, Direct mounting |  |
| GTIN (EAN) | 4008190456771              |   |  |
| Qty.       | 20 ST                      |   |  |

## Cross-connections

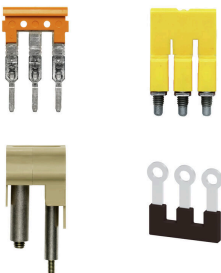

The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |            |  |
|------------|----------------------------|------------|--|
| Type       | VH 20/5/3.4                | Version    |  |
| Order No.  | <a href="#">0446100000</a> | Dummy fuse |  |
| GTIN (EAN) | 4008190519742              |            |  |
| Qty.       | 10 ST                      |            |  |

**SAKS 4/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**Fuse**



As accessories for our wide product portfolio of fuse terminal blocks, we also offer the appropriate fuse links. The portfolio includes device protection fuses (miniature fuses) from 5x20 mm up to 10x38 mm, E 14 to E 18 fuse links, as well as automotive fuses and automatic circuit breakers. Gauge rings for the fuse holders round off the overall portfolio.

**General ordering data**

|            |                            |            |  |
|------------|----------------------------|------------|--|
| Type       | VH 25.4/6.3/4.3            | Version    |  |
| Order No.  | <a href="#">0446200000</a> | Dummy fuse |  |
| GTIN (EAN) | 4008190519759              |            |  |
| Qty.       | 10 ST                      |            |  |

**Blank**



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

**General ordering data**

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | DEK 5/8 MC NE WS           | Version   |  |
| Order No.  | <a href="#">1856740000</a> | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |  |
| GTIN (EAN) | 4032248400850              | Weidmueller, white  |  |
| Qty.       | 800 ST                     |   |  |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

## Accessories

www.weidmueller.com

## Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |         |   |
|------------|----------------------------|---------|---|
| Type       | DEK 5/8 MC SDR             | Version |   |
| Order No.  | <a href="#">1856750000</a> |         | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248400867              |         | Weidmueller, To customer specification                    |
| Qty.       | 160 ST                     |         |   |

## Plus



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |         |   |
|------------|----------------------------|---------|---|
| Type       | DEK 5/8 PLUS MC NE WS      | Version |   |
| Order No.  | <a href="#">1046350000</a> |         | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248782055              |         | Weidmueller, white  |
| Qty.       | 800 ST                     |         |   |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |         |   |
|------------|----------------------------|---------|---|
| Type       | DEK 5/8 PLUS MC SDR        | Version |   |
| Order No.  | <a href="#">1046370000</a> |         | Dekafix, Terminal marker, 5 x 8 mm, Pitch in mm (P): 8.00 |
| GTIN (EAN) | 4032248782079              |         | Weidmueller, To customer specification                    |
| Qty.       | 160 ST                     |         |   |

## DEK 5/8



## WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

## General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | DEK 5/8 MM WS              | Version |  |
| Order No.  | <a href="#">2007130000</a> |         | Dekafix, Terminal marker, 5 x 8 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392012              |         |  |
| Qty.       | 500 ST                     |         |  |

## SAKS 4/35

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Marker holder

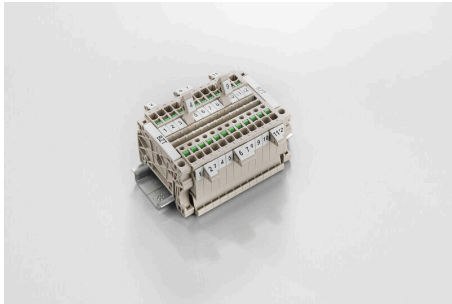

The marker holder offer the possibility of additional mounting of standard markers with a pitch of 5 or 5.1 mm. The angled holders can be optionally snapped together and could be mounted in all standard marking channels of the Klippon® Connect modular terminal blocks. Fitting marker types could be found under the respective accessories of the designation marking holder.

## General ordering data

|            |                            |                            |  |
|------------|----------------------------|----------------------------|--|
| Type       | BZT 1 WS 10/5              | Version                    |  |
| Order No.  | <a href="#">1805490000</a> | Accessories, Marker holder |  |
| GTIN (EAN) | 4032248270231              |                            |  |
| Qty.       | 100 ST                     |                            |  |
| Type       | BZT 1 ZA WS 10/5           | Version                    |  |
| Order No.  | <a href="#">1805520000</a> | Accessories, Marker holder |  |
| GTIN (EAN) | 4032248270248              |                            |  |
| Qty.       | 100 ST                     |                            |  |

## DEK 5/6



## WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

## Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | DEK 5/6 MM WS              | Version  |  |
| Order No.  | <a href="#">2007120000</a> | Dekafix, Terminal marker, 5 x 6 mm, Weidmueller, white |  |
| GTIN (EAN) | 4050118392104              |  |  |
| Qty.       | 600 ST                     |  |  |

## SAKS 4/35

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Accessories

[www.weidmueller.com](http://www.weidmueller.com)

### Fuse holder



The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

### General ordering data

|            |                            |                            |  |
|------------|----------------------------|----------------------------|--|
| Type       | SK E16/SAKS2               | Version                    |  |
| Order No.  | <a href="#">0284110000</a> | Screw cover cap (terminal) |  |
| GTIN (EAN) | 4008190006204              |                            |  |
| Qty.       | 25 ST                      |                            |  |