

**TS 15X5 2M/ST/ZN****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

**General ordering data**

Version	Terminal rail, Accessories, Steel, galvanic zinc plated and passivated, Width: 2000 mm, Height: 15 mm, Depth: 5.5 mm
Order No.	<a href="#">0514200000</a>
Type	TS 15X5 2M/ST/ZN
GTIN (EAN)	4008190172428
Qty.	10 M

## TS 15X5 2M/ST/ZN

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	5.5 mm	Depth (inches)	0.2165 inch
Height	15 mm	Height (inches)	0.5906 inch
Width	2000 mm	Width (inches)	78.74 inch
Net weight	155.5 g		

## Temperatures

Ambient temperature	-5 °C...40 °C
---------------------	---------------

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%


## Mounting rail

Installation advice	Direct mounting	
Standards	DIN EN 60715	
Surface finish	galvanic zinc plated and passivated	
Thickness	1.00 mm	
Basic material	Steel	
Length of the terminal rail	min.	0 mm
	nominal	2000 mm
	max.	2000 mm
Short-time withstand current per second 1.2 kA according to IEC 60947-7-2		
Pre-punched mounting rail	No	
Slit width		
Short circuit strength corresponds to E-Cu wire	10.00 mm <sup>2</sup>	
Spacing of holes, centre-to-centre	0 mm	
Slit gap		
Slit length		

## Classifications

ETIM 6.0	EC001285	ETIM 7.0	EC001285
ETIM 8.0	EC001285	ETIM 9.0	EC001285
ETIM 10.0	EC001285	ECLASS 9.0	27-40-06-02
ECLASS 9.1	27-40-06-02	ECLASS 10.0	27-40-06-02
ECLASS 11.0	27-40-06-02	ECLASS 12.0	27-40-06-02
ECLASS 13.0	27-40-06-02	ECLASS 14.0	27-40-06-02
ECLASS 15.0	27-40-06-02		

**Drawings**

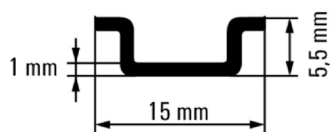

## TS 15X5 2M/ST/ZN

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## End bracket

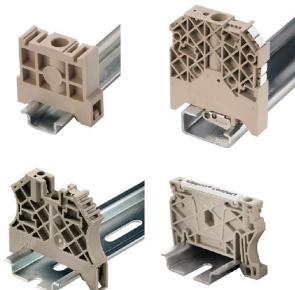


Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

Type	EW 15	Version
Order No.	<a href="#">0382860000</a>	End bracket, beige, TS 15, V-2, Polyamide 66, Width: 10 mm, 100 °C
GTIN (EAN)	4008190187804	
Qty.	50 ST	

## Accessories

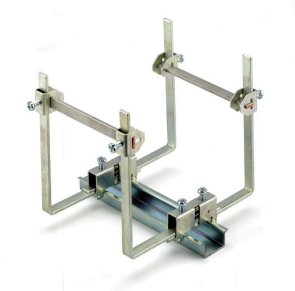


The comprehensive accessories of the Klippon® Connect portfolio are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms

## General ordering data

Type	SO SH1	Version
Order No.	<a href="#">0401460000</a>	Busbar support, grey, 100 °C, Width: 24.5 mm, V-2, Polyamide 66,
GTIN (EAN)	4008190188092	when screwed in
Qty.	20 ST	

## End bracket

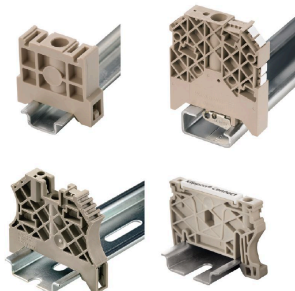

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

Type	EW 15/2	Version
Order No.	<a href="#">1071900000</a>	End bracket, dark beige, TS 15, HB, Plastic, Width: 8 mm, 100 °C
GTIN (EAN)	4008190462949	
Qty.	50 ST	

**TS 15X5 2M/ST/ZN**
**Weidmüller Interface GmbH & Co. KG**

 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)
**Accessories**

Type	ZEW 15	Version
Order No.	<a href="#">7920340000</a>	End bracket, beige, TS 15, V-2, Plastic, Width: 5 mm, 120 °C
GTIN (EAN)	4032248238910	
Qty.	20 ST	

**Mounting support**


We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

**General ordering data**

Type	BFSC M4X6 MS	Version
Order No.	<a href="#">0136300000</a>	Mounting screw (Terminal), 4.00 mm, Brass, Depth: 7 mm, Width: 7 mm, Height: 6 mm
GTIN (EAN)	4008190177713	
Qty.	50 ST	
Type	BFSC M4X6	Version
Order No.	<a href="#">0149700000</a>	Mounting screw (Terminal), 4.00 mm, Steel, Depth: 7 mm, Width: 7 mm, Height: 6 mm
GTIN (EAN)	4008190016098	
Qty.	100 ST	