


## H6,0/20 SW

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

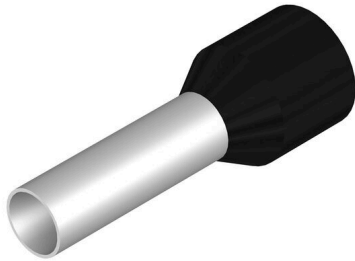

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 14 mm, 12 mm, black
Order No.	<a href="#">0533500000</a>
Type	H6,0/20 SW
GTIN (EAN)	4008 190183905
Qty.	100 items
Packaging	loose

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.36 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, black	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	3.5 mm	Contact surface length (L2)	12 mm
Collar diameter (D2)	6.3 mm	Plastic collar thickness (S2)	0.3 mm
L1 in mm	20.00 mm	Wire connection cross section AWG, max.	AWG 10
Metal sleeve thickness (S1)	0.2 mm	Stripping length	14 mm
Conductor cross-section	6 mm <sup>2</sup>	Colour code	Weidmueller

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

