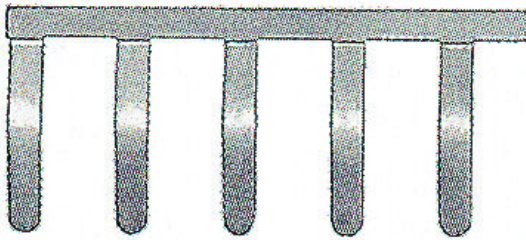


**Product image**

In contrast to the terminal blocks with integrated disconnect lever, our disconnect plugs can be completely detached or removed from the terminal block and the respective application and offer a flexible alternative solution to our standard disconnectors.

**General ordering data**

Version	Cross-connector (terminal), when screwed in, grey, 27 A, Number of poles: 58, Pitch in mm (P): 8.00, Insulated: No, Width: 0.8 mm
Order No.	<a href="#">0545400000</a>
Type	QB 58/8/15
GTIN (EAN)	4008190028794
Qty.	10 items

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	17.5 mm	Depth (inches)	0.689 inch
Height	458.5 mm	Height (inches)	18.0511 inch
Width	0.8 mm	Width (inches)	0.0315 inch
Net weight	21.96 g		

**Temperatures**

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Operating temperature	-60 °C...130 °C		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Material data**

Basic material	Copper	Colour	grey
----------------	--------	--------	------

**System specifications**

Version	for cross-connection link
---------	---------------------------

**Additional technical data**

Type of fixing	when screwed in	Installation advice	Direct mounting
Explosion-tested version	No		

**Dimensions**

Pitch in mm (P)	8.00 mm
-----------------	---------

**General**

Number of poles	58	Installation advice	Direct mounting
-----------------	----	---------------------	-----------------

**Rating data**

Nominal current	27 A
-----------------	------

**Classifications**

ETIM 8.0	EC000489	ETIM 9.0	EC000489
ETIM 10.0	EC000489	ECLASS 14.0	27-25-03-03
ECLASS 15.0	27-25-03-03		