

SH 3


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

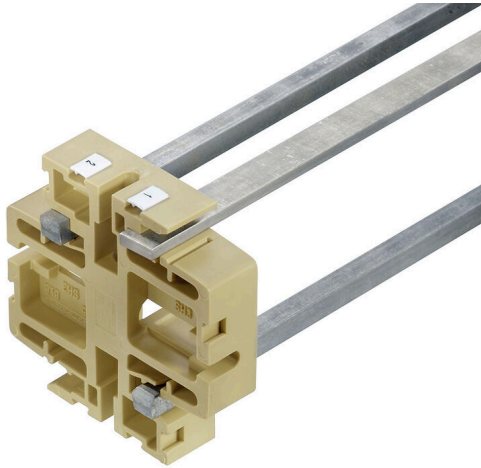

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

Version	Busbar support, silver, 100 °C, Width: 65 mm, V-2, Polyamide 66
Order No.	0556660000
Type	SH 3
GTIN (EAN)	4008 1901 23086
Qty.	10 items

SH 3

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	65 mm	Depth (inches)	2.5591 inch
Height	15 mm	Height (inches)	0.5906 inch
Width	65 mm	Width (inches)	2.5591 inch
Net weight	26.4 g		

Temperatures

Ambient temperature	-5 °C...40 °C	Continuous operating temp., min.	-50 °C
Continuous operating temp., max.	100 °C		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	Polyamide 66	Surface finish	all others
Colour	silver	UL 94 flammability rating	V-2

System specifications

Version	15 x 6 mm busbar connection
---------	-----------------------------

Conductors for clamping (rated connection)

Type of connection	Miscellaneous
--------------------	---------------

General

Number of poles	3	Operating temperature range, max.	100 °C
Surface finish	all others		

Classifications

ETIM 8.0	EC001166	ETIM 9.0	EC001166
ETIM 10.0	EC001166	ECLASS 14.0	27-40-06-07
ECLASS 15.0	27-40-06-07		