


## CLI R 02 F. CLI C 02-3

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

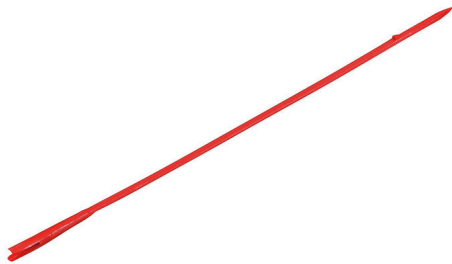

The CableLine range of wire and cable marker products provides users with solutions for the most diverse applications. The range of applications extends from narrow wires right up to cables with large outside diameters.

### General ordering data

Version	CableLine, Mounting mandrel
Order No.	<a href="#">0559900000</a>
Type	CLI R 02 F. CLI C 02-3
GTIN (EAN)	4008 19008 1645
Qty.	20 items

## CLI R 02 F. CLI C 02-3

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

## Technical data

www.weidmueller.com

## Dimensions and weights

Depth	1.5 mm	Depth (inches)	0.0591 inch
Height	150 mm	Height (inches)	5.9055 inch
Width	2 mm	Width (inches)	0.0787 inch
Net weight	0.47 g		

## Temperatures

Operating temperature range	-40...100 °C
-----------------------------	--------------

## Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	No SVHC above 0.1 wt%

## General data

Material colour according to resistance code	2	Type of printing	Standard
Version	MultiPack	Width	2 mm
UL 94 flammability rating	V-0	Operating temperature range, max.	100 °C
Operating temperature range, min.	-40 °C	Colour	red
Halogen	Yes	Basic material	POM
Printed characters	Numbers	Recommended industries	Process, Machinery
Number per mandrel	25	Operating temperature range	-40...100 °C

## Conductor and cable markers

Halogen	Yes	Conductor cross-section, max.	1.5 mm <sup>2</sup>
Conductor cross-section, min.	0.2 mm <sup>2</sup>	Conductor O.D., max.	3 mm
Conductor O.D., min.	1.3 mm	Conductor O.D.	1.3 - 3 mm
Cross-section for connected wire	0.2 - 1.5 mm <sup>2</sup>		

## Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		