


## H10,0/28 EB

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

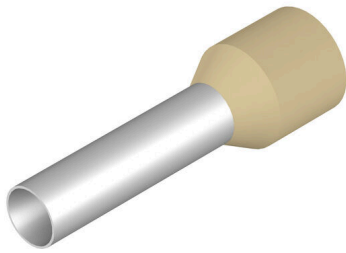

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

|            |   |
|------------|---|
| Version    | Wire-end ferrule, Standard, 21 mm, 18 mm, Ivory |
| Order No.  | <a href="#">0565800000</a>                      |
| Type       | H10,0/28 EB                                     |
| GTIN (EAN) | 4008 190138646                                  |
| Qty.       | 100 items                                       |
| Packaging  | loose   |

**H10,0/28 EB**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



|                         |                            |
|-------------------------|----------------------------|
| ROHS                    | Conform                    |
| UL File Number Search   | <a href="#">UL Website</a> |
| Certificate no. (cULus) | E499744                    |

**Dimensions and weights**

|            |       |
|------------|-------|
| Net weight | 0.6 g |
|------------|-------|

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

**Technical data**

|                        |   |         |          |
|------------------------|---|---------|----------|
| Description of article | Wire end ferrule with plastic collar, ivory | Version | Standard |
|------------------------|---|---------|----------|

**Wire-end ferrules**

|                               |                    |   |             |
|-------------------------------|--------------------|---|-------------|
| Contact surface diameter (D1) | 4.5 mm             | Contact surface length (L2)             | 18 mm       |
| Collar diameter (D2)          | 7.6 mm             | Plastic collar thickness (S2)           | 0.4 mm      |
| L1 in mm                      | 28.00 mm           | Wire connection cross section AWG, max. | AWG 8       |
| Metal sleeve thickness (S1)   | 0.2 mm             | Stripping length                        | 21 mm       |
| Conductor cross-section       | 10 mm <sup>2</sup> | Colour code                             | Weidmueller |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000005    | ETIM 9.0    | EC000005    |
| ETIM 10.0   | EC000005    | ECLASS 14.0 | 27-40-02-01 |
| ECLASS 15.0 | 27-40-02-01 |             |             |

Drawing

