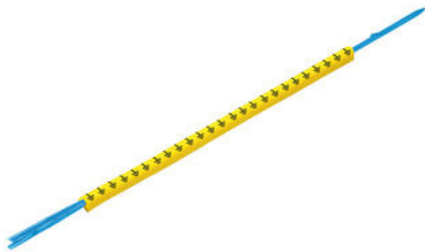


**CLI R 1-3 GE/SW N****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration

The CableLine range of wire and cable marker products provides users with solutions for the most diverse applications. The range of applications extends from narrow wires right up to cables with large outside diameters.

**General ordering data**

|            |                             |
|------------|-----------------------------|
| Version    | CableLine, Mounting mandrel |
| Order No.  | <a href="#">0572901664</a>  |
| Type       | CLI R 1-3 GE/SW N           |
| GTIN (EAN) | 4008190163884               |
| Qty.       | 10 items                    |

## CLI R 1-3 GE/SW N

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Dimensions and weights

|            |        |                 |             |
|------------|--------|-----------------|-------------|
| Depth      | 5 mm   | Depth (inches)  | 0.1968 inch |
| Height     | 3 mm   | Height (inches) | 0.1181 inch |
| Width      | 4.2 mm | Width (inches)  | 0.1654 inch |
| Net weight | 2.3 g  |                 |             |

## Temperatures

|                             |             |
|-----------------------------|-------------|
| Operating temperature range | -30...80 °C |
|-----------------------------|-------------|

## Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

## General data

|                                              |                    |                                   |                            |
|----------------------------------------------|--------------------|-----------------------------------|----------------------------|
| Material colour according to resistance code | 4                  | Orientation of print              | horizontal                 |
| Type of printing                             | Standard           | Printing method                   | hot-embossing              |
| Version                                      | MultiPack          | Width                             | 4.2 mm                     |
| UL 94 flammability rating                    | V-0                | Operating temperature range, max. | 80 °C                      |
| Operating temperature range, min.            | -30 °C             | Colour                            | yellow                     |
| Halogen                                      | Yes                | Basic material                    | PVC, soft, without Cadmium |
| Colour of printing                           | black              | Printed characters                | Upper-case letters         |
| Recommended industries                       | Process, Machinery | Number per mandrel                | 25                         |
| Operating temperature range                  | -30...80 °C        | Imprint                           | N                          |

## Conductor and cable markers

|                                  |                         |                               |                   |
|----------------------------------|-------------------------|-------------------------------|-------------------|
| Halogen                          | Yes                     | Conductor cross-section, max. | 4 mm <sup>2</sup> |
| Conductor cross-section, min.    | 1.5 mm <sup>2</sup>     | Conductor O.D., max.          | 5 mm              |
| Conductor O.D., min.             | 2.5 mm                  | Conductor O.D.                | 2.5 - 5 mm        |
| Cross-section for connected wire | 1.5 - 4 mm <sup>2</sup> |                               |                   |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ETIM 10.0   | EC001530    | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 |             |             |