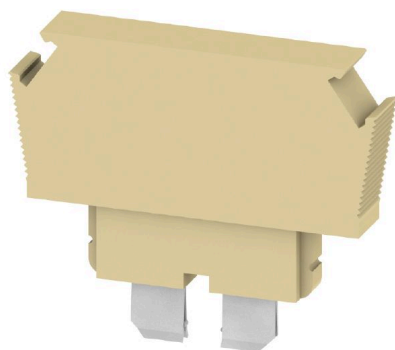


**DLS 2 SAKRD -/+****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The component plug is used to integrate an electrical component in a disconnect terminal block. After soldering the electronic component, the plug can be integrated into the disconnection area of our disconnect terminal blocks and thus changes the disconnect terminal block into a modular terminal block with integrated electronic component.

**General ordering data**

|                 |                                                                                          |
|-----------------|------------------------------------------------------------------------------------------|
| Version         | Plug (terminal), 1 A, 250 V, Number of connections: 1, Number of poles: 1, Width: 5.8 mm |
| Order No.       | <a href="#">0630160000</a>                                                               |
| Type            | DLS 2 SAKRD -/+                                                                          |
| GTIN (EAN)      | 4008190091194                                                                            |
| Qty.            | 50 items                                                                                 |
| Delivery status | This article will no longer be available in the future.                                  |
| Available until | 2026-06-30T00:00:00+02:00                                                                |

## DLS 2 SAKRD -/+

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Dimensions and weights

|            |        |                 |             |
|------------|--------|-----------------|-------------|
| Height     | 36 mm  | Height (inches) | 1.4173 inch |
| Width      | 5.8 mm | Width (inches)  | 0.2283 inch |
| Net weight | 3.84 g |                 |             |

## Temperatures

|                                  |               |                                  |        |
|----------------------------------|---------------|----------------------------------|--------|
| Ambient temperature              | -5 °C...40 °C | Continuous operating temp., min. | -50 °C |
| Continuous operating temp., max. | 100 °C        |                                  |        |

## Environmental Product Compliance

|                                      |                                      |
|--------------------------------------|--------------------------------------|
| RoHS Compliance Status               | Compliant with exemption             |
| RoHS Exemption (if applicable/known) | 7a                                   |
| REACH SVHC                           | Lead 7439-92-1                       |
| SCIP                                 | e1c310ef-6b67-4efa-80a6-d307472f4de9 |

## Material data

|                           |              |        |       |
|---------------------------|--------------|--------|-------|
| Basic material            | Polyamide 66 | Colour | beige |
| UL 94 flammability rating | V-2          |        |       |

## System specifications

|         |      |
|---------|------|
| Version | Plug |
|---------|------|

## Additional technical data

|                          |         |                     |                 |
|--------------------------|---------|---------------------|-----------------|
| Type of fixing           | Plugged | Installation advice | Direct mounting |
| Explosion-tested version | No      | Type of mounting    | Plugged         |

## Conductors for clamping (rated connection)

|                       |   |
|-----------------------|---|
| Number of connections | 1 |
|-----------------------|---|

## Dimensions

|                 |         |
|-----------------|---------|
| Pitch in mm (P) | 6.00 mm |
|-----------------|---------|

## General

|                 |   |                     |                 |
|-----------------|---|---------------------|-----------------|
| Number of poles | 1 | Installation advice | Direct mounting |
|-----------------|---|---------------------|-----------------|

## Rating data

|               |       |                 |     |
|---------------|-------|-----------------|-----|
| Rated voltage | 250 V | Nominal current | 1 A |
|---------------|-------|-----------------|-----|

## Classifications

|           |          |             |             |
|-----------|----------|-------------|-------------|
| ETIM 8.0  | EC002848 | ETIM 9.0    | EC002848    |
| ETIM 10.0 | EC002848 | ECLASS 14.0 | 27-25-03-90 |

## Technical data

ECLASS 15.0

27-25-03-90

## Drawings

