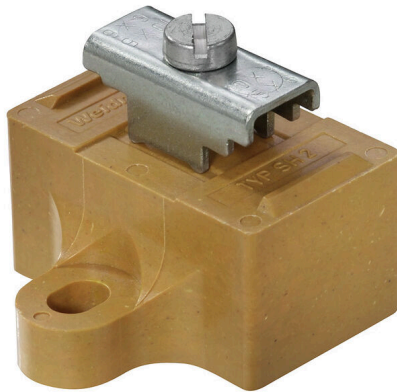


**SH 2 S**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Product image**

The comprehensive accessories of the Klippon® Connect portfolio are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms

**General ordering data**

Version	Busbar support, medium yellow, 130 °C, Width: 40 mm, V-0, KrG, when screwed in
Order No.	<a href="#">0641720000</a>
Type	SH 2 S
GTIN (EAN)	4008190166304
Qty.	10 items

## SH 2 S

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	35.5 mm	Depth (inches)	1.3976 inch
Height	40 mm	Height (inches)	1.5748 inch
Width	40 mm	Width (inches)	1.5748 inch
Net weight	26.9 g		

### Temperatures

Ambient temperature	-5 °C...40 °C	Continuous operating temp., min.	-60 °C
Continuous operating temp., max.	130 °C		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Material data

Basic material	KrG	Surface finish	all others
Colour	medium yellow	UL 94 flammability rating	V-0

### System specifications

Version	For the mounting rails
---------	------------------------

### Additional technical data

Type of mounting	when screwed in
------------------	-----------------

### Conductors for clamping (rated connection)

Type of connection	Miscellaneous
--------------------	---------------

### General

Number of poles	1	Surface finish	all others
-----------------	---	----------------	------------

### Classifications

ETIM 8.0	EC001166	ETIM 9.0	EC001166
ETIM 10.0	EC001166	ECLASS 14.0	27-40-06-07
ECLASS 15.0	27-40-06-07		