


AP DKT4 PA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

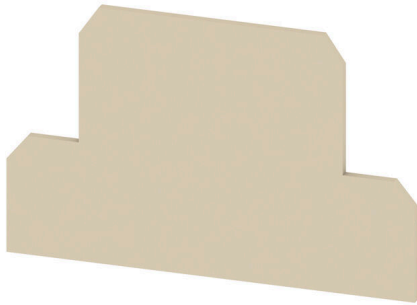

Logic functions AND, NAND, OR and NOR in modular terminal format with a rated cross-section of 4 mm². They each have five inputs which are fed – with logic gating – via a 24 V/20 mA PNP output. The logic components can be used for many applications involving the coupling of digital sensor/actuator signals with automation devices.

General ordering data

Version	End plate for terminals, beige, Height: 65 mm, Width: 1.5 mm, V-2, PA 66, Snap-on: Yes
Order No.	0687560000
Type	AP DKT4 PA
GTIN (EAN)	4008 190009465
Qty.	20 items

AP DKT4 PA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	65 mm	Depth (inches)	2.5591 inch
Height	65 mm	Height (inches)	2.5591 inch
Width	1.5 mm	Width (inches)	0.0591 inch
Net weight	3.26 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...55 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate	0.084 kg CO2eq.	

General data

Installation advice	Direct mounting	Protection degree	IP20
---------------------	-----------------	-------------------	------

Material data

Basic material	PA 66	Colour	beige
UL 94 flammability rating	V-2		

System specifications

Version	End plate
---------	-----------

Additional technical data

Snap-on	Yes	Installation advice	Direct mounting
---------	-----	---------------------	-----------------

General

Installation advice	Direct mounting
---------------------	-----------------

Classifications

ETIM 8.0	EC000886	ETIM 9.0	EC000886
ETIM 10.0	EC000886	ECLASS 14.0	27-25-03-01
ECLASS 15.0	27-25-03-01		