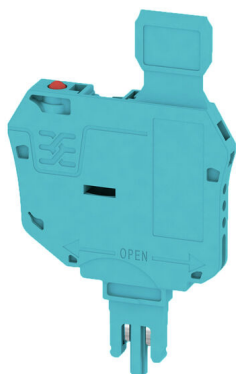


**SIHA 3/G20/LD 10-36V BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

**General ordering data**

|            |                                                                                    |
|------------|------------------------------------------------------------------------------------|
| Version    | Fuse holder for feed-through modular terminal, blue, 2.31 A, pluggable, V-O, Wemid |
| Order No.  | <a href="#">1005250000</a>                                                         |
| Type       | SIHA 3/G20/LD 10-36V BL                                                            |
| GTIN (EAN) | 4032248712038                                                                      |
| Qty.       | 25 items                                                                           |

## SIHA 3/G20/LD 10-36V BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Dimensions and weights

|            |          |                 |             |
|------------|----------|-----------------|-------------|
| Depth      | 63.1 mm  | Depth (inches)  | 2.4842 inch |
| Height     | 39.38 mm | Height (inches) | 1.5504 inch |
| Width      | 6 mm     | Width (inches)  | 0.2362 inch |
| Net weight | 8.56 g   |                 |             |

## Temperatures

|                                  |               |                                  |        |
|----------------------------------|---------------|----------------------------------|--------|
| Ambient temperature              | -5 °C...40 °C | Continuous operating temp., min. | -50 °C |
| Continuous operating temp., max. | 120 °C        |                                  |        |

## Environmental Product Compliance

|                                      |                          |
|--------------------------------------|--------------------------|
| RoHS Compliance Status               | Compliant with exemption |
| RoHS Exemption (if applicable/known) | 7cl                      |
| REACH SVHC                           | No SVHC above 0.1 wt%    |

## Material data

|                           |       |        |      |
|---------------------------|-------|--------|------|
| Basic material            | Wemid | Colour | blue |
| UL 94 flammability rating | V-0   |        |      |

## System specifications

|         |                |
|---------|----------------|
| Version | Fuse cartridge |
|---------|----------------|

## Additional technical data

|                     |                                      |                  |         |
|---------------------|--------------------------------------|------------------|---------|
| Installation advice | Operating instructions/<br>catalogue | Type of mounting | Plugged |
|---------------------|--------------------------------------|------------------|---------|

## General

|                     |                                      |                                   |        |
|---------------------|--------------------------------------|-----------------------------------|--------|
| Installation advice | Operating instructions/<br>catalogue | Operating temperature range, max. | 120 °C |
|---------------------|--------------------------------------|-----------------------------------|--------|

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC002848    | ETIM 9.0    | EC002848    |
| ETIM 10.0   | EC002848    | ECLASS 14.0 | 27-25-03-90 |
| ECLASS 15.0 | 27-25-03-90 |             |             |

## Drawings

