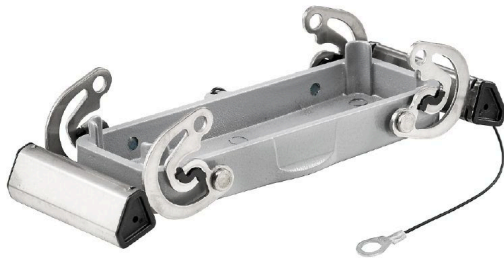


HDC 24B DODQ 2QB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**IP65**

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | |
|------------|--|
| Version | HDC enclosures, Installation size: 8, Protection degree: IP65, in plugged condition, Cover for lower part of housing, Side-locking clamp on upper side, Standard |
| Order No. | 1009100000 |
| Type | HDC 24B DODQ 2QB |
| GTIN (EAN) | 4032248713844 |
| Qty. | 1 items |

HDC 24B DODQ 2QB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS

Conform

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Height | 17 mm | Height (inches) | 0.6693 inch |
| Width | 55 mm | Width (inches) | 2.1654 inch |
| Net weight | 144.32 g | | |

Temperatures

Limit temperature -40 °C ... 125 °C

Environmental Product Compliance

| | |
|------------------------|--|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | Potassium perfluorobutane sulfonate 29420-49-3 |
| SCIP | e98b2b24-ba23-41bf-8d19-0dda3647412f |

| | | |
|---------------------|---------------------|-------------------------|
| Chemical resistance | Substance | Acetone |
| | Chemical resistance | Conditionally resistant |
| | Substance | Drilling oil |
| | Chemical resistance | Resistant |
| | Substance | Diesel |
| | Chemical resistance | Resistant |
| | Substance | Ethyl alcohol |
| | Chemical resistance | Resistant |
| | Substance | Transmission oil |
| | Chemical resistance | Resistant |
| | Substance | Hydraulic oil |
| | Chemical resistance | Resistant |
| | Substance | Coolant |
| | Chemical resistance | Resistant |
| | Substance | Petroleum benzine |
| | Chemical resistance | Resistant |
| | Substance | Sweat |
| | Chemical resistance | Resistant |
| | Substance | Premium gasoline |
| | Chemical resistance | Conditionally resistant |
| | Substance | Water |
| | Chemical resistance | Resistant |
| | Substance | UV |
| | Chemical resistance | Unstable |
| | Substance | Ozone |
| | Chemical resistance | Unstable |

Dimensions

| | | | |
|----------------------|-----------|---------------------|-------|
| Cable entry | For bases | Width housing C | 43 mm |
| Total length housing | 120 mm | Height of housing B | 17 mm |

HDC 24B DODQ 2QB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com
Technical data**General data**

| | | | |
|-----------------------------|-----------------------------|----------------|----------------|
| Housing main material | diecast aluminium | Surface finish | Powder coating |
| Protection degree | IP65, in plugged condition | EMC housings | No |
| Material of locking element | Stainless steel, rust-proof | | |


Version

| | | | |
|--------------------------|----------------------------------|-------------------|---------------------------------|
| Top part/bottom part/lid | Cover | Design of housing | Cover for lower part of housing |
| Design of locking system | Side-locking clamp on upper side | Design | Standard |
| Installation size | 8 | Cable entry | For bases |
| Type | Cover | Clamp version | Side-locking clamp |
| Colour (RAL) | RAL 7035 | BG | 8 |
| Suitable for ModuPlug® | Yes | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000437 | ETIM 7.0 | EC000437 |
| ETIM 8.0 | EC000437 | ETIM 9.0 | EC000437 |
| ETIM 10.0 | EC000437 | ECLASS 9.0 | 27-44-02-02 |
| ECLASS 9.1 | 27-44-02-02 | ECLASS 10.0 | 27-44-02-02 |
| ECLASS 11.0 | 27-44-02-02 | ECLASS 12.0 | 27-44-02-02 |
| ECLASS 13.0 | 27-44-02-02 | ECLASS 14.0 | 27-44-02-02 |
| ECLASS 15.0 | 27-44-02-02 | | |

Drawings

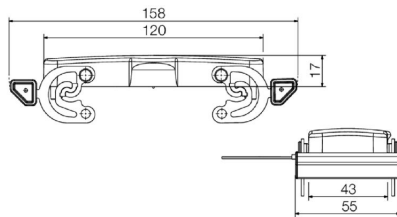

HDC 24B DODQ 2QB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Hood, Cable Entry at top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | HDC 64D TOBU 2M32G | Version |
| Order No. | 1009710000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248771394 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 32 |
| Type | HDC 64D TOBU 1M40G | Version |
| Order No. | 1045560000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248780532 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 40 |

XXL plug housing, cable entry on top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | HDC 64D TOBU 1M50G | Version |
| Order No. | 1111140000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248964413 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 50 |

HDC 24B DODQ 2QB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Hood, Cable Entry at top

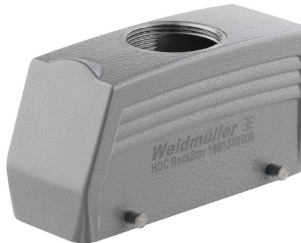

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | HDC 24B TOBU 1PG21G | Version |
| Order No. | 1661370000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417925 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: PG 21 |
| Type | HDC 24B TOBU 1PG29G | Version |
| Order No. | 1661380000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417932 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: PG 29 |
| Type | HDC 64D TOBU 1PG21G | Version |
| Order No. | 1661440000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417994 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: PG 21 |
| Type | HDC 64D TOBU 1PG29G | Version |
| Order No. | 1661460000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190418014 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: PG 29 |
| Type | HDC 64D TOBU 1M32G | Version |
| Order No. | 1786830000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248204076 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 32 |
| Type | HDC 24B TOBU 1M32G | Version |
| Order No. | 1787810000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248205257 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: M 32 |
| Type | HDC 24B TOBU 1M25G | Version |
| Order No. | 1787820000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248205264 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: M 25 |
| Type | HDC 24B TOBU 1M40G | Version |
| Order No. | 1902980000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248585274 | plugged condition, Cable entry from top, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: M 40 |

HDC 24B DODQ 2QB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

XXL plug housing, cable entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | HDC 64D TSBU 1M50G | Version |
| Order No. | 1111130000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248967711 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 50 |

Hood, Cable Entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | HDC 24B TSBU 1PG21G | Version |
| Order No. | 1661230000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417789 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: PG 21 |
| Type | HDC 24B TSBU 1PG29G | Version |
| Order No. | 1661240000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417796 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: PG 29 |

HDC 24B DODQ 2QB

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | HDC 64D TSBU 1PG21G | Version |
| Order No. | 1661300000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417857 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: PG 21 |
| Type | HDC 64D TSBU 1PG29G | Version |
| Order No. | 1661320000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4008190417871 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: PG 29 |
| Type | HDC 64D TSBU 1M32G | Version |
| Order No. | 1786770000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248204014 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 32 |
| Type | HDC 64D TSBU 1M25G | Version |
| Order No. | 1786780000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248204021 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 25 |
| Type | HDC 24B TSBU 1M32G | Version |
| Order No. | 1787750000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248205097 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: M 32 |
| Type | HDC 24B TSBU 1M25G | Version |
| Order No. | 1787760000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248205103 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: M 25 |
| Type | HDC 64D TSBU 1M40G | Version |
| Order No. | 1809630000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248284986 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, high, Size of cable entries: M 40 |
| Type | HDC 24B TSBU 1M40G | Version |
| Order No. | 1902480000 | HDC enclosures, Installation size: 8, Protection degree: IP65, in |
| GTIN (EAN) | 4032248592944 | plugged condition, Cable entry from side, Plug housing, Side-locking |
| Qty. | 1 ST | clamp on lower side, Standard, Size of cable entries: M 40 |