

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Product image



To feed through power, signal, and data is the classical requirement in electrical engineering and panel building. The insulating material, the connection system and the design of the terminal blocks are the differentiating features. A feed-through terminal block is suitable for joining and/or connecting one or more conductors. They could have one or more connection levels that are on the same potential or insulated against one another.

General ordering data

| | |
|------------|---|
| Version | Multi-tier modular terminal, Screw connection, dark beige, 2.5 mm ² , 250 V, Number of connections: 4, Number of levels: 2, TS 35, V-0 |
| Order No. | 1034400000 |
| Type | WDK 2.5/BLZ/5.08/ZA |
| GTIN (EAN) | 4008 190193058 |
| Qty. | 50 items |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



| | |
|-------------------------|----------------------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate No. (cURus) | E60693 |

Dimensions and weights

| | | | |
|--------------------------|-------------|----------------|-------------|
| Depth | 52.5 mm | Depth (inches) | 2.0669 inch |
| Depth including DIN rail | 53 mm | Height | 58 mm |
| Height (inches) | 2.2835 inch | Width | 5.08 mm |
| Width (inches) | 0.2 inch | Net weight | 10.01 g |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|---------------|
| Storage temperature | -25 °C...55 °C | Ambient temperature | -5 °C...40 °C |
| Continuous operating temp., min. | -50 °C | Continuous operating temp., max. | 120 °C |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Material data

| | | | |
|---------------------------|-------|--------|------------|
| Basic material | Wemid | Colour | dark beige |
| UL 94 flammability rating | V-0 | | |

System specifications

| | | | |
|-------------------------------------|---|-------------------------------|-----|
| Version | 2 screw connections - 2 plug-in connections, With assembly peg, One end without connector | End cover plate required | Yes |
| Number of potentials | 2 | Number of levels | 2 |
| Number of clamping points per level | 2 | Number of potentials per tier | 1 |
| Levels cross-connected internally | No | PE connection | No |
| Mounting rail | TS 35 | N-function | No |
| PE function | No | PEN function | No |

2 clampable conductors (H05V/H07V) with equal cross-section (rated connection)

| | | | |
|--|---------------------|--|---------------------|
| Cross-section for connected wire, solid, two clampable wires, max. | 2.5 mm ² | Cross-section for connected wire, solid, two clampable wires, min. | 0.5 mm ² |
| Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, 2 clampable wires, max. | 1.5 mm ² | Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, 2 clampable wires, min. | 0.5 mm ² |
| Wire cross-section, finely stranded, two clampable wires, max. | 1.5 mm ² | Wire connection cross section, finely stranded, two clampable wires, min. | 0.5 mm ² |

Additional technical data

| | | | |
|--------------------------|-------|-----------------------------|---------|
| Open sides | right | Number of similar terminals | 1 |
| Explosion-tested version | No | Type of mounting | Snap-on |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

CSA rating data

| | | | |
|-------------------------------|--------|-----------------------|----------------|
| Wire cross section max. (CSA) | 12 AWG | Certificate No. (CSA) | 200039-1057876 |
| Voltage size B (CSA) | 300 V | Current size B (CSA) | 20 A |
| Voltage size D (CSA) | 300 V | Current size D (CSA) | 10 A |
| Wire cross section min. (CSA) | 26 AWG | | |

Conductors for clamping (additional connection)

Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max. 2.5 mm²

Conductors for clamping (rated connection)

| | | | |
|---|----------------------|---|----------------------|
| Gauge to IEC 60947-1 | A3 | Wire connection cross section AWG, max. | AWG 12 |
| Connection direction | on side | Stripping length | 10 mm |
| Type of connection 2 | Plug-in connection | Type of connection | Screw connection |
| Number of connections | 4 | Clamping range, max. | 4 mm ² |
| Clamping range, min. | 0.13 mm ² | Clamping screw | M 2.5 |
| Blade size | 0.6 x 3.5 mm | Wire connection cross section AWG, min. | AWG 20 |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 2.5 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.13 mm ² |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 2.5 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 0.13 mm ² |
| Wire connection cross section, finely stranded, max. | 4 mm ² | Wire connection cross section, finely stranded, min. | 0.13 mm ² |
| Connection cross-section, stranded, max. | 2.5 mm ² | Connection cross-section, stranded, min. | 0.13 mm ² |
| Torque level with DMS electric screwdriver | 1 | Wire connection cross-section, solid core, max. | 4 mm ² |
| Wire connection cross-section, solid core, min. | 0.13 mm ² | Connection cross-section, finely stranded, min. | 0.13 mm ² |

General

| | | | |
|---|---|---|--------|
| Wire connection cross section AWG, max. | AWG 12 | Wire connection cross section AWG, min. | AWG 20 |
| Standards | IEC 61984, In accordance with IEC 60947-7-1 | Mounting rail | TS 35 |

Rating data


| | | | |
|--|---------------------|---------------------------------|---|
| Rated cross-section | 2.5 mm ² | Rated voltage | 250 V |
| Rated DC voltage | 250 V | Nominal current | 16.5 A |
| Current at maximum wires | 18 A | Standards | IEC 61984, In accordance with IEC 60947-7-1 |
| Volume resistance according to IEC 60947-7-x | 1.33 mΩ | Rated impulse withstand voltage | 4 kV |
| Power loss in accordance with IEC 60947-7-x | 0.77 W | Pollution severity | 3 |

Technical data**UL rating data**

| | | | |
|--|--------|--|--------|
| Conductor size Factory wiring max. (cURus) | 12 AWG | Voltage size B (cURus) | 300 V |
| Voltage size D (cURus) | 300 V | Certificate No. (cURus) | E60693 |
| Conductor size Field wiring min. (cURus) | 22 AWG | Conductor size Factory wiring min. (cURus) | 26 AWG |
| Current size B (cURus) | 20 A | Current size D (cURus) | 10 A |
| Conductor size Field wiring max. (cURus) | 12 AWG | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000897 | ETIM 9.0 | EC000897 |
| ETIM 10.0 | EC000897 | ECLASS 14.0 | 27-25-01-02 |
| ECLASS 15.0 | 27-25-01-02 | | |

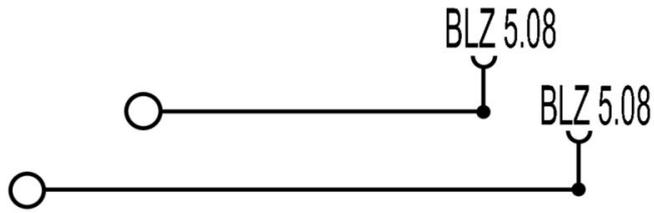

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

End plates and partition plates




Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | WAP WDK2.5/BLZ/O.ZA | Version | |
| Order No. | 1070000000 | End plate for terminals, dark beige, Height: 45.4 mm, Width: 5.08 mm, V-O, Wemid, Snap-on: No | |
| GTIN (EAN) | 4008190191221 | | |
| Qty. | 20 ST | | |
| Type | WAP WDK2.5/BLZ/M.ZA | Version | |
| Order No. | 1070100000 | End plate for terminals, dark beige, Height: 45.4 mm, Width: 5.08 mm, V-O, Wemid, Snap-on: No | |
| GTIN (EAN) | 4008190191214 | | |
| Qty. | 20 ST | | |

End bracket

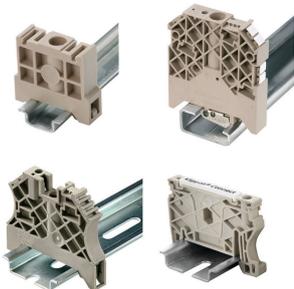

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

General ordering data

| | | | |
|------------|----------------------------|--|--|
| Type | WEW 35/1 | Version | |
| Order No. | 1059000000 | End bracket, dark beige, TS 35, V-2, Wemid, Width: 12 mm, 100 °C | |
| GTIN (EAN) | 4008190172282 | | |
| Qty. | 50 ST | | |

Mounting support



We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|--|
| Type | WBB WDK2.5/BL5.08 | Version |
| Order No. | 1072660000 | Partition plate (terminal), orange, Height: 58 mm, Width: 5 mm, V-2, |
| GTIN (EAN) | 4008190470555 | PA 66 |
| Qty. | 10 ST | |
| Type | WBB ZA WDK2.5/BL5.08 | Version |
| Order No. | 1072760000 | Partition plate (terminal), orange, Height: 58 mm, Width: 5 mm, V-2, |
| GTIN (EAN) | 4008190470548 | PA 66 |
| Qty. | 10 ST | |

BLZP 5.08HC/180 SN



Female plug with clamping-yoke screw system for connecting wires with straight (180°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BLZP 5.08HC/04/180 SN O... | Version |
| Order No. | 1943600000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248617593 | 180°, Clamping yoke connection, Clamping range, max. : 4 mm², Box |
| Qty. | 90 ST | |
| Type | BLZP 5.08HC/06/180 SN O... | Version |
| Order No. | 1943620000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248617616 | 180°, Clamping yoke connection, Clamping range, max. : 4 mm², Box |
| Qty. | 60 ST | |
| Type | BLZP 5.08HC/08/180 SN O... | Version |
| Order No. | 1943640000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248617647 | 180°, Clamping yoke connection, Clamping range, max. : 4 mm², Box |
| Qty. | 42 ST | |

BLZP 5.08HC/180F SN



Female plug with clamping-yoke screw system for connecting wires with straight (180°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BLZP 5.08HC/04/180F SN ... | Version |
| Order No. | 1944110000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248617494 | 180°, Clamping yoke connection, Clamping range, max. : 4 mm², Box |
| Qty. | 60 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLZP 5.08HC/06/180F SN ... | Version |
| Order No. | 1944130000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248618712 | 180°, Clamping yoke connection, Clamping range, max. : 4 mm², Box |
| Qty. | 42 ST | |
| Type | BLZP 5.08HC/08/180F SN ... | Version |
| Order No. | 1944150000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248618736 | 180°, Clamping yoke connection, Clamping range, max. : 4 mm², Box |
| Qty. | 36 ST | |

Coding elements




Only connects what is supposed to be connected: the right connection at the right place.
 Coding elements and locking devices clearly assign connecting elements during the manufacturing process and operation
 The coding elements and locking devices are inserted prior to assembly or during the cable assembly phase.
 The Weidmüller alternative: configure online using the variant configurator to precode prior to delivery.
 Incorrect assembly on the circuit board and incorrect plugging of connecting elements is no longer possible.
 The advantage: no troubleshooting during manufacture and no operational errors by the user.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BLZ/SL KO BK BX | Version |
| Order No. | 1545710000 | PCB plug-in connector, Accessories, Coding element, black, Number |
| GTIN (EAN) | 4008190087142 | of poles: 1 |
| Qty. | 50 ST | |

Warning cover

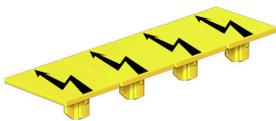

Warning covers with a flash symbol provide more safety for man and machine. They are used where external voltage must be indicated within the application.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | WAD WDU1.5/BLZ/BLA | Version |
| Order No. | 1577400000 | Terminal cover, dark beige, Wemid, Height: 12.75 mm, Width: 9.48 |
| GTIN (EAN) | 4008190112165 | mm, Depth: 8.85 mm, V-0 |
| Qty. | 20 ST | |


WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Blank

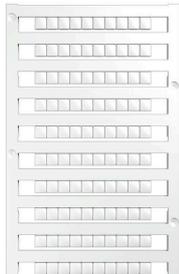

The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | DEK 5/5 MC NE WS | Version |
| Order No. | 1609801044 | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190397111 | Weidmueller, white |
| Qty. | 1000 ST | |
| Type | WS 8/5 MC NE WS | Version |
| Order No. | 1640740000 | WS, Terminal marker, 8 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4008190279103 | Allen-Bradley, white |
| Qty. | 720 ST | |

Marker holder



The marker holder offer the possibility of additional mounting of standard markers with a pitch of 5 or 5.1 mm. The angled holders can be optionally snapped together and could be mounted in all standard marking channels of the Klippon® Connect modular terminal blocks. Fitting marker types could be found under the respective accessories of the designation marking holder.

General ordering data

| | | |
|------------|----------------------------|----------------------------|
| Type | BZT 1 WS 10/5 | Version |
| Order No. | 1805490000 | Accessories, Marker holder |
| GTIN (EAN) | 4032248270231 | |
| Qty. | 100 ST | |
| Type | BZT 1 ZA WS 10/5 | Version |
| Order No. | 1805520000 | Accessories, Marker holder |
| GTIN (EAN) | 4032248270248 | |
| Qty. | 100 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

WS 8/5



WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | WS 8/5 MM WS | Version | |
| Order No. | 2007150000 | WS, Terminal marker, 8 x 5 mm, Weidmueller, white | |
| GTIN (EAN) | 4050118392029 | | |
| Qty. | 800 ST | | |

End plates and partition plates



Partition plates and end plates are essential accessories for terminal blocks. Partition plates provide optical and electrical separation of different potentials and functional groups, increasing safety and ensuring a clear structure inside the control cabinet. End plates close the terminal block row on the sides, protect against contact with live parts, and ensure a clean, stable finish. Both components are precisely matched to the respective Weidmüller terminal block series, contributing to safe, compliant, and professional wiring.

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | WAP WDK2.5/BLZ/O.ZA LG | Version | |
| Order No. | 1112130000 | End plate for terminals, Light Grey, Height: 45.4 mm, Width: 5.08 mm, V-O, Wemid, Snap-on: No | |
| GTIN (EAN) | 4032248891313 | | |
| Qty. | 20 ST | | |


WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

BLDF 5.08/180F SN

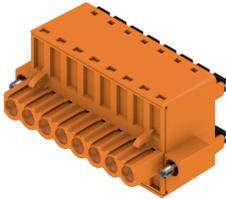

The powerful daisy-chain solution for high-performance signal bus applications is also suitable for 400V auxiliary power chains with 18.5A current-carrying capacity. The large clamping capacity (up to 2.5mm² wire cross-sections) is particularly beneficial for long bus cables or high currents because of the low voltage drop. Four flange variations, including the patented release latch, allow for user-friendly unplugging designs.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | BLDF 5.08/08/180F SN OR... | Version |
| Order No. | 1065120000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248817658 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 24 ST | |
| Type | BLDF 5.08/08/180F SN BK... | Version |
| Order No. | 1001000000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248817559 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 24 ST | |
| Type | BLDF 5.08/07/180F SN OR... | Version |
| Order No. | 1065110000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 7, |
| GTIN (EAN) | 4032248817832 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 24 ST | |
| Type | BLDF 5.08/07/180F SN BK... | Version |
| Order No. | 1000990000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 7, |
| GTIN (EAN) | 4032248817474 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 24 ST | |
| Type | BLDF 5.08/06/180F SN OR... | Version |
| Order No. | 1065090000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248817801 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 28 ST | |
| Type | BLDF 5.08/06/180F SN BK... | Version |
| Order No. | 1000980000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248817375 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 28 ST | |
| Type | BLDF 5.08/05/180F SN OR... | Version |
| Order No. | 1065080000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248817856 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 32 ST | |
| Type | BLDF 5.08/05/180F SN BK... | Version |
| Order No. | 1000970000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248817337 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 32 ST | |
| Type | BLDF 5.08/04/180F SN OR... | Version |
| Order No. | 1059420000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248817894 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 40 ST | |
| Type | BLDF 5.08/04/180F SN BK... | Version |
| Order No. | 1000960000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248817344 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm ² , Box |
| Qty. | 40 ST | |

WDK 2.5/BLZ/5.08/ZA


Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLDF 5.08/03/180F SN OR... | Version |
| Order No. | 1012060000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248818037 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 48 ST | |
| Type | BLDF 5.08/03/180F SN BK... | Version |
| Order No. | 1000950000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248817085 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 48 ST | |
| Type | BLDF 5.08/02/180F SN OR... | Version |
| Order No. | 1001220000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248817955 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLDF 5.08/02/180F SN BK... | Version |
| Order No. | 1000930000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248817252 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |

BLDF 5.08/180 SN

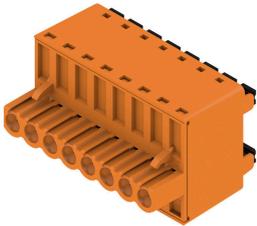

The powerful daisy-chain solution for high-performance signal bus applications is also suitable for 400V auxiliary power chains with 18.5A current-carrying capacity. The large clamping capacity (up to 2.5mm² wire cross-sections) is particularly beneficial for long bus cables or high currents because of the low voltage drop. Four flange variations, including the patented release latch, allow for user-friendly unplugging designs.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BLDF 5.08/08/180 SN OR ... | Version |
| Order No. | 1001210000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248817573 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 28 ST | |
| Type | BLDF 5.08/08/180 SN BK ... | Version |
| Order No. | 1000920000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248817092 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 28 ST | |
| Type | BLDF 5.08/07/180 SN OR ... | Version |
| Order No. | 1001200000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 7, |
| GTIN (EAN) | 4032248817535 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 32 ST | |
| Type | BLDF 5.08/07/180 SN BK ... | Version |
| Order No. | 1000910000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 7, |
| GTIN (EAN) | 4032248817450 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 32 ST | |
| Type | BLDF 5.08/06/180 SN OR ... | Version |
| Order No. | 1001190000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248818174 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 40 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLDF 5.08/06/180 SN BK ... | Version |
| Order No. | 1000900000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248817412 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 40 ST | |
| Type | BLDF 5.08/05/180 SN OR ... | Version |
| Order No. | 1001180000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248818228 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 48 ST | |
| Type | BLDF 5.08/05/180 SN BK ... | Version |
| Order No. | 1000890000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248817078 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 48 ST | |
| Type | BLDF 5.08/04/180 SN OR ... | Version |
| Order No. | 1001170000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248818075 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLDF 5.08/04/180 SN BK ... | Version |
| Order No. | 1000880000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248817269 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLDF 5.08/03/180 SN OR ... | Version |
| Order No. | 2759190000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4064675007289 | 180°, PUSH IN with actuator, Tension-clamp connection, Clamping range, max. : 3.31 mm², Box |
| Qty. | 80 ST | |
| Type | BLDF 5.08/03/180 SN OR ... | Version |
| Order No. | 1001160000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248817726 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 80 ST | |
| Type | BLDF 5.08/03/180 SN BK ... | Version |
| Order No. | 1000870000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248817276 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 80 ST | |
| Type | BLDF 5.08/02/180 SN OR ... | Version |
| Order No. | 1001150000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248818020 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 120 ST | |
| Type | BLDF 5.08/02/180 SN BK ... | Version |
| Order No. | 1000860000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248817030 | 180°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 120 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

BLF 5.08HC/90 SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

| | | |
|------------|----------------------------|--|
| Type | BLF 5.08HC/02/90 SN BK ... | Version |
| Order No. | 1000030001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248689965 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 180 ST | |
| Type | BLF 5.08HC/02/90 SN OR ... | Version |
| Order No. | 1001530000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248693337 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 180 ST | |
| Type | BLF 5.08HC/03/90 SN BK ... | Version |
| Order No. | 1000040001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248689972 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 120 ST | |
| Type | BLF 5.08HC/03/90 SN OR ... | Version |
| Order No. | 1001540000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248693344 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 120 ST | |
| Type | BLF 5.08HC/03/90 SN OR ... | Version |
| Order No. | 2766910000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4064675022527 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 120 ST | |
| Type | BLF 5.08HC/03/90 SN OR ... | Version |
| Order No. | 2764380000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4064675017332 | 90°, PUSH IN with actuator, Tension-clamp connection, Clamping range, max. : 3.31 mm², Box |
| Qty. | 120 ST | |
| Type | BLF 5.08HC/04/90 SN BK ... | Version |
| Order No. | 1000050001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248689989 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 90 ST | |
| Type | BLF 5.08HC/04/90 SN OR ... | Version |
| Order No. | 1001550000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248693351 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 90 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLF 5.08HC/05/90 SN BK ... | Version |
| Order No. | 1000060001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248689996 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 72 ST | |
| Type | BLF 5.08HC/05/90 SN OR ... | Version |
| Order No. | 1001560000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248693368 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 72 ST | |
| Type | BLF 5.08HC/06/90 SN BK ... | Version |
| Order No. | 1000070001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248690008 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLF 5.08HC/06/90 SN OR ... | Version |
| Order No. | 1001570000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248693375 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLF 5.08HC/07/90 SN OR ... | Version |
| Order No. | 1001580000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 7, |
| GTIN (EAN) | 4032248693382 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 48 ST | |
| Type | BLF 5.08HC/08/90 SN BK ... | Version |
| Order No. | 1000090001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248690022 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 42 ST | |
| Type | BLF 5.08HC/08/90 SN OR ... | Version |
| Order No. | 1001590000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248693399 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 42 ST | |
| Type | BLF 5.08HC/09/90 SN OR ... | Version |
| Order No. | 1001600000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 9, |
| GTIN (EAN) | 4032248693405 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 36 ST | |
| Type | BLF 5.08HC/10/90 SN BK ... | Version |
| Order No. | 1000110001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 10, |
| GTIN (EAN) | 4032248690046 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 36 ST | |
| Type | BLF 5.08HC/10/90 SN OR ... | Version |
| Order No. | 1001610000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 10, |
| GTIN (EAN) | 4032248693412 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 36 ST | |
| Type | BLF 5.08HC/11/90 SN BK ... | Version |
| Order No. | 1000120001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 11, |
| GTIN (EAN) | 4032248690060 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |
| Type | BLF 5.08HC/11/90 SN OR ... | Version |
| Order No. | 1001620000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 11, |
| GTIN (EAN) | 4032248693429 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |
| Type | BLF 5.08HC/12/90 SN BK ... | Version |
| Order No. | 1000130001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 12, |
| GTIN (EAN) | 4032248690084 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLF 5.08HC/12/90 SN OR ... | Version |
| Order No. | 1001630000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 12, |
| GTIN (EAN) | 4032248693436 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |
| Type | BLF 5.08HC/13/90 SN BK ... | Version |
| Order No. | 1000140001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 13, |
| GTIN (EAN) | 4032248690091 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/13/90 SN OR ... | Version |
| Order No. | 1001640000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 13, |
| GTIN (EAN) | 4032248693443 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/14/90 SN BK ... | Version |
| Order No. | 1000150001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 14, |
| GTIN (EAN) | 4032248690107 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/14/90 SN OR ... | Version |
| Order No. | 1001650000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 14, |
| GTIN (EAN) | 4032248693450 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/15/90 SN OR ... | Version |
| Order No. | 1001660000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 15, |
| GTIN (EAN) | 4032248693467 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/16/90 SN BK ... | Version |
| Order No. | 1000170001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 16, |
| GTIN (EAN) | 4032248690121 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/16/90 SN OR ... | Version |
| Order No. | 1001670000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 16, |
| GTIN (EAN) | 4032248693474 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/17/90 SN BK ... | Version |
| Order No. | 1000180001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 17, |
| GTIN (EAN) | 4032248690138 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/17/90 SN OR ... | Version |
| Order No. | 1001680000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 17, |
| GTIN (EAN) | 4032248693481 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/18/90 SN BK ... | Version |
| Order No. | 1000190001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 18, |
| GTIN (EAN) | 4032248690145 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/18/90 SN OR ... | Version |
| Order No. | 1001690000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 18, |
| GTIN (EAN) | 4032248693498 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/19/90 SN BK ... | Version |
| Order No. | 1000200001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 19, |
| GTIN (EAN) | 4032248690152 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLF 5.08HC/19/90 SN OR ... | Version |
| Order No. | 1001700000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 19, |
| GTIN (EAN) | 4032248693504 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/20/90 SN OR ... | Version |
| Order No. | 1001710000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 20, |
| GTIN (EAN) | 4032248693511 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |

BLF 5.08HC/90F SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BLF 5.08HC/21/90F SN OR... | Version |
| Order No. | 1477230000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 21, |
| GTIN (EAN) | 4050118284546 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 12 ST | |
| Type | BLF 5.08HC/20/90F SN OR... | Version |
| Order No. | 1002270000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 20, |
| GTIN (EAN) | 4032248694433 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 12 ST | |
| Type | BLF 5.08HC/19/90F SN OR... | Version |
| Order No. | 1002260000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 19, |
| GTIN (EAN) | 4032248694419 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 12 ST | |
| Type | BLF 5.08HC/18/90F SN OR... | Version |
| Order No. | 1002250000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 18, |
| GTIN (EAN) | 4032248694402 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/17/90F SN OR... | Version |
| Order No. | 1002240000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 17, |
| GTIN (EAN) | 4032248694396 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/16/90F SN OR... | Version |
| Order No. | 1002230000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 16, |
| GTIN (EAN) | 4032248694389 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | BLF 5.08HC/16/90F SN BK... | Version |
| Order No. | 1000360001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 16, |
| GTIN (EAN) | 4032248690329 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/15/90F SN OR... | Version |
| Order No. | 1002220000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 16, |
| GTIN (EAN) | 4032248694372 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/14/90F SN OR... | Version |
| Order No. | 1002210000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 14, |
| GTIN (EAN) | 4032248694365 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 18 ST | |
| Type | BLF 5.08HC/13/90F SN OR... | Version |
| Order No. | 1002200000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 13, |
| GTIN (EAN) | 4032248694358 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/12/90F SN OR... | Version |
| Order No. | 1002190000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 12, |
| GTIN (EAN) | 4032248694341 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/12/90F SN BK... | Version |
| Order No. | 1000320001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 12, |
| GTIN (EAN) | 4032248690282 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/11/90F SN OR... | Version |
| Order No. | 1002180000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 11, |
| GTIN (EAN) | 4032248694334 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 24 ST | |
| Type | BLF 5.08HC/10/90F SN OR... | Version |
| Order No. | 1002170000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 10, |
| GTIN (EAN) | 4032248694327 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |
| Type | BLF 5.08HC/10/90F SN BK... | Version |
| Order No. | 1000300001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 10, |
| GTIN (EAN) | 4032248690268 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |
| Type | BLF 5.08HC/09/90F SN OR... | Version |
| Order No. | 1002160000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 9, |
| GTIN (EAN) | 4032248694310 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 30 ST | |
| Type | BLF 5.08HC/08/90F SN OR... | Version |
| Order No. | 1002150000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248694105 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 36 ST | |
| Type | BLF 5.08HC/08/90F SN BK... | Version |
| Order No. | 1000280001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 8, |
| GTIN (EAN) | 4032248690244 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 36 ST | |
| Type | BLF 5.08HC/07/90F SN OR... | Version |
| Order No. | 1002140000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 7, |
| GTIN (EAN) | 4032248694099 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 36 ST | |

WDK 2.5/BLZ/5.08/ZA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|--|
| Type | BLF 5.08HC/06/90F SN OR... | Version |
| Order No. | 1002130000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248694082 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 42 ST | |
| Type | BLF 5.08HC/06/90F SN BK... | Version |
| Order No. | 1000260001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 6, |
| GTIN (EAN) | 4032248690220 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 42 ST | |
| Type | BLF 5.08HC/05/90F SN OR... | Version |
| Order No. | 1002120000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 5, |
| GTIN (EAN) | 4032248694075 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 48 ST | |
| Type | BLF 5.08HC/04/90F SN OR... | Version |
| Order No. | 1002110000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248694068 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLF 5.08HC/04/90F SN BK... | Version |
| Order No. | 1000240001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 4, |
| GTIN (EAN) | 4032248690206 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 60 ST | |
| Type | BLF 5.08HC/03/90F SN OR... | Version |
| Order No. | 1002100000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248694051 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 72 ST | |
| Type | BLF 5.08HC/03/90F SN BK... | Version |
| Order No. | 1000230001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 3, |
| GTIN (EAN) | 4032248690190 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 72 ST | |
| Type | BLF 5.08HC/02/90F SN OR... | Version |
| Order No. | 1002090000 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248694044 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 90 ST | |
| Type | BLF 5.08HC/02/90F SN BK... | Version |
| Order No. | 1000220001 | PCB plug-in connector, female plug, 5.08 mm, Number of poles: 2, |
| GTIN (EAN) | 4032248690183 | 90°, PUSH IN with actuator, Clamping range, max. : 3.31 mm², Box |
| Qty. | 90 ST | |