


TNHE WSI6 60-150V DC/AC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

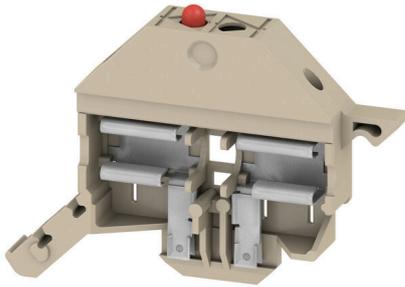

The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

General ordering data

Version	W-Series, Isolating lever
Order No.	1035500000
Type	TNHE WSI6 60-150V DC/AC
GTIN (EAN)	4008 190205539
Qty.	50 items
Delivery status	This article will no longer be available in the future.
Last order date	2025-12-31T00:00:00+01:00

TNHE WSI6 60-150V DC/AC

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Depth	28.8 mm	Depth (inches)	1.1339 inch
Height	50.15 mm	Height (inches)	1.9744 inch
Width	6.95 mm	Width (inches)	0.2736 inch
Net weight	5.66 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...75 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	7cl
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	Wemid	Colour	dark beige
UL 94 flammability rating	V-0		

Additional technical data

Type of fixing	Snap-on	Installation advice	Direct mounting
Explosion-tested version	No		

Dimensions

Pitch in mm (P)	7.80 mm
-----------------	---------

General

Installation advice	Direct mounting
---------------------	-----------------

Rating data

Nominal current	0 A
-----------------	-----

Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		

TNHE WSI6 60-150V DC/AC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

