


**TNHE WSI6 60-150V DC/AC**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

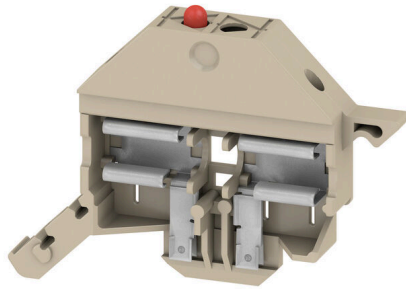

The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

**General ordering data**

Version	W-Series, Isolating lever
Order No.	<a href="#">1035500000</a>
Type	TNHE WSI6 60-150V DC/AC
GTIN (EAN)	4008 190205539
Qty.	50 items
Delivery status	This article will no longer be available in the future.
Available until	2025-12-31T00:00:00+01:00

## TNHE WSI6 60-150V DC/AC

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

### Dimensions and weights

Depth	28.8 mm	Depth (inches)	1.1339 inch
Height	50.15 mm	Height (inches)	1.9744 inch
Width	6.95 mm	Width (inches)	0.2736 inch
Net weight	5.66 g		

### Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...75 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	120 °C

### Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	7cl
REACH SVHC	No SVHC above 0.1 wt%

### Material data

Basic material	Wemid	Colour	dark beige
UL 94 flammability rating	V-0		

### Additional technical data

Type of fixing	Snap-on	Installation advice	Direct mounting
Explosion-tested version	No		

### Dimensions

Pitch in mm (P)	7.80 mm
-----------------	---------

### General

Installation advice	Direct mounting
---------------------	-----------------

### Rating data

Nominal current	0 A
-----------------	-----

### Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		

**TNHE WSI6 60-150V DC/AC**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

