


ELS 6/30 MC SDR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

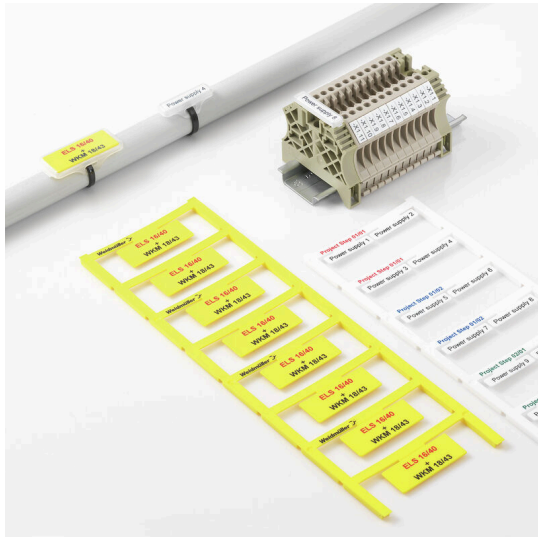

Similar to illustration



ELS MultiCard markers can be printed with a PrintJet, plotter or SMark printer. In particular, colour printing with PrintJet AVANCED allows the eye-catching identification marking of cables and terminal strips in many ways.

ELS 6/30 for use in the WKM 8/30 cable markers or in the EM8/30 group-tag carriers

ELS 7/40 for use in the SchT5S group-tag carriers

ELS 16/40 for use in the WKM 18/43 cable markers or the SchT5 group-tag carriers

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | |
|------------|---|
| Version | ELS, Insert markers, 7 - 115 mm, 30 x 6 mm, To customer specification |
| Order No. | 1045660000 |
| Type | ELS 6/30 MC SDR |
| GTIN (EAN) | 4032248779642 |
| Qty. | 16 items |

ELS 6/30 MC SDR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 0.8 mm | Depth (inches) | 0.0315 inch |
| Height | 30 mm | Height (inches) | 1.1811 inch |
| Width | 6 mm | Width (inches) | 0.2362 inch |
| Net weight | 0.69 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...100 °C |
|-----------------------------|--------------|

Environmental Product Compliance

| | | | |
|--------------------------|-----------------------------|------------------|--|
| RoHS Compliance Status | Compliant without exemption | | |
| REACH SVHC | No SVHC above 0.1 wt% | | |
| Product Carbon Footprint | Cradle to gate | 0.011 kg CO2 eq. | |

General data

| | | | |
|--------------------------------------|---|-----------|--|
| Number per sheet | 16 | | |
| Type of printing | To customer specification | | |
| Printing method | MC Laser | | |
| Version | halogen-free | | |
| Width | 6 mm | | |
| UL 94 flammability rating | V-2 | | |
| Operating temperature range, max. | 100 °C | | |
| Operating temperature range, min. | -40 °C | | |
| Colour | To customer specification | | |
| Halogen | No | | |
| Basic material | Polyamide 66 | | |
| Colour of printing | black | | |
| Printed characters | Requires M-Print PRO File | | |
| Number of markers per packaging unit | Form of supply | MultiCard | |
| compatible printer | PRINTJET CONNECT , MCP BASIC 2 , MCP PLUS 2 | | |
| Number of markers per combination | 1 MultiCard = Insert markers | | |
| Operating temperature range | -40...100 °C | | |

Conductor and cable markers

| | | | |
|----------------------|------|----------------------|------------|
| Halogen | No | Conductor O.D., max. | 115 mm |
| Conductor O.D., min. | 7 mm | Conductor O.D. | 7 - 115 mm |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ETIM 10.0 | EC001530 | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 | | |