

## IE-BHD-V14M



PushPull plug-in connector according to IEC  
61076-3-117 ver.14 (PROFINET), metal, empty housing

### General ordering data

Version	Empty enclosure, Device flange
Order No.	<a href="#">1047940000</a>
Type	IE-BHD-V14M
GTIN (EAN)	4032248784486
Qty.	10 items

## Technical data

### Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E316369

### Dimensions and weights

Depth	13.2 mm	Depth (inches)	0.5197 inch
Height	42 mm	Height (inches)	1.6535 inch
Width	22.2 mm	Width (inches)	0.874 inch
Net weight	14.9 g		

### Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Protection degree	IP67	Plugging cycles	750
Composition	Plug housing with labelling tag holder: 9*11 mm; suitable for holding RJ45 and fibre-optic inserts		

### General standards


Connector standard	IEC 61076-3-117 Var. 14	Certificate no. (cULus)	E316369
--------------------	-------------------------	-------------------------	---------

### Classifications

ETIM 8.0	EC001031	ETIM 9.0	EC001031
ETIM 10.0	EC001031	ECLASS 14.0	27-19-01-04
ECLASS 15.0	27-19-01-04		

**Drawings**

**Dimensioned drawing**

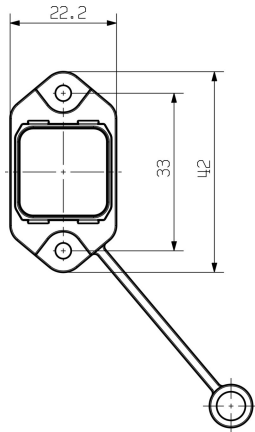

**Dimensioned drawing**

