

## IE-BHC-V14M-RJA

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



PushPull plug-in connector according to IEC  
61076-3-117 ver.14 (PROFINET), metal, RJ45 empty  
housing

### General ordering data

Version	Empty enclosure
Order No.	<a href="#">1047950000</a>
Type	IE-BHC-V14M-RJA
GTIN (EAN)	4032248784493
Qty.	10 items

## IE-BHC-V14M-RJA

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E316369

## Dimensions and weights

Depth	34.7 mm	Depth (inches)	1.3661 inch
Height	39.6 mm	Height (inches)	1.5591 inch
Width	39.6 mm	Width (inches)	1.5591 inch
Net weight	4.95 g		

## Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

## Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

## General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Protection degree	IP67	Plugging cycles	750
Composition	Plug housing with labelling tag holder: 9*11 mm; suitable for holding RJ45 and fibre-optic inserts		


## General standards

Connector standard	IEC 61076-3-117 Var. 14	Certificate no. (cULus)	E316369
--------------------	-------------------------	-------------------------	---------

## Classifications

ETIM 8.0	EC001031	ETIM 9.0	EC001031
ETIM 10.0	EC001031	ECLASS 14.0	27-19-01-04
ECLASS 15.0	27-19-01-04		

Installation cut-out

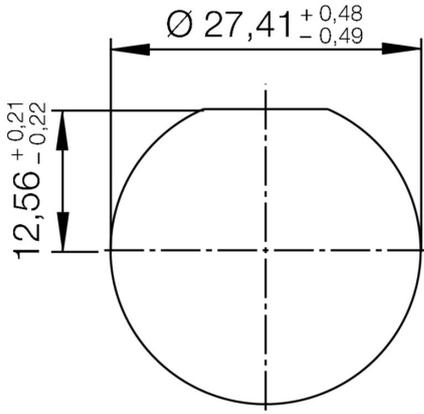

## IE-BHC-V14M-RJA

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## RJ45



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

## General ordering data

Type	IE-BI-RJ45-FJ-B	Version
Order No.	<a href="#">1963840000</a>	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 ST	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	<a href="#">1963830000</a>	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 ST	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	<a href="#">1962850000</a>	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 ST	
Type	IE-BI-RJ45-C	Version
Order No.	<a href="#">1962840000</a>	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	10 ST	

## USB



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

## General ordering data

Type	IE-BI-USB-A	Version
Order No.	<a href="#">1019570000</a>	USB insert, Flange insert, type A
GTIN (EAN)	4032248731602	
Qty.	1 ST	

## IE-BHC-V14M-RJA

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14



## General ordering data

Type	IE-BI-HYB-10P	Version	
Order No.	<a href="#">1069010000</a>	Flange insert, for flange insert, Hybrid	
GTIN (EAN)	4032248823970		
Qty.	10 ST		
Type	IE-BIC-HYB-P-0,5-300	Version	
Order No.	<a href="#">1096150000</a>	Crimp contact, for flange insert, Hybrid	
GTIN (EAN)	4032248869114		
Qty.	300 ST		

## IE fastening tool



The mounting tool helps you to tighten the locknut when mounting the flange of version 04.

Comments:

- Standard tool
- made from tough plastic

## General ordering data

Type	IE-FISP-V4	Version	
Order No.	<a href="#">9204370000</a>	Mounting tool	
GTIN (EAN)	4032248660780		
Qty.	2 ST		