 



AP 100 BK**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

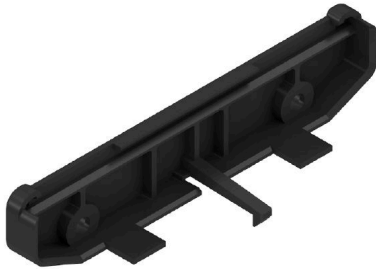

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

General ordering data

Version	End plate, RS 100 black, End plate both sides, Width: 27.2 mm
Order No.	1057540000
Type	AP 100 BK
GTIN (EAN)	4032248799688
Qty.	20 items

AP 100 BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	23.8 mm	Depth (inches)	0.937 inch
Height	108.2 mm	Height (inches)	4.2598 inch
Width	27.2 mm	Width (inches)	1.0709 inch
Net weight	7.4 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

UL 94 flammability rating	V-2	Insulating material	PA 66
Insulating material group	I	Surface finish	untreated
Basic material	PA 66	Comparative Tracking Index (CTI)	600 ≤ CTI

General data



Colour	black	Protection degree	IP20 in installed state
Mounting rail	TS 32, TS 35	Colour chart (similar)	RAL 9011
Encapsulation option	No		

Classifications

ETIM 7.0	EC001031	ETIM 8.0	EC001031
ETIM 9.0	EC002779	ETIM 10.0	EC002779
ECLASS 11.0	27-18-27-92	ECLASS 12.0	27-18-27-92
ECLASS 13.0	27-19-06-02	ECLASS 14.0	27-19-06-02
ECLASS 15.0	27-19-06-02		

Drawings

RAIL MOUNTING
FOR BOTH SIDES (RIGHT AND LEFT)

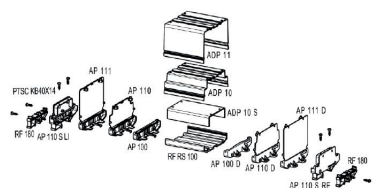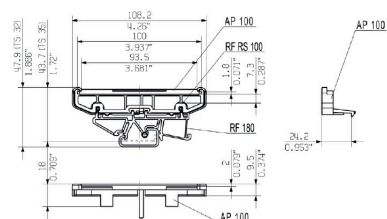


AP 100 BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

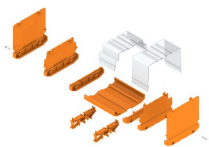www.weidmueller.com**Accessories****RS 100 - Profile housing**

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

General ordering data

Type	PTSC KB40X14	Version
Order No.	4019420000	Mounting screw (Terminal), 0.00 mm, Steel, Depth: 7 mm, Width:
GTIN (EAN)	4008190243029	16.9 mm, Height: 7 mm
Qty.	100 ST	