

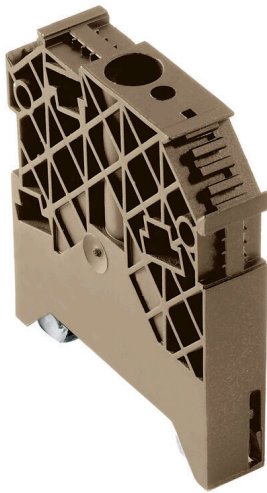
**WEW 35/1****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

**General ordering data**

Version	End bracket, dark beige, TS 35, V-2, Wemid, Width: 12 mm, 100 °C
Order No.	<a href="#">1059000000</a>
Type	WEW 35/1
GTIN (EAN)	4008190172282
Qty.	50 items

## WEW 35/1

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	62.5 mm	Depth (inches)	2.4606 inch
Height	56 mm	Height (inches)	2.2047 inch
Width	12 mm	Width (inches)	0.4724 inch
Net weight	36.3 g		

### Temperatures

Ambient temperature	-5 °C...40 °C	Continuous operating temp., min.	-50 °C
Continuous operating temp., max.	100 °C		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate		0.343 kg CO2eq.

### Material data

Basic material	Wemid	Colour	dark beige
UL 94 flammability rating	V-2		

### System specifications

Version	For the terminals	Mounting rail	TS 35
---------	-------------------	---------------	-------

### Additional technical data

Installation advice	Direct mounting	Type of mounting	when screwed in
Locking	for screw fixing		

### Conductors for clamping (rated connection)

Tightening torque, max.	2.4 Nm	Tightening torque, min.	1.2 Nm
-------------------------	--------	-------------------------	--------

### Dimensions

TS 35 offset	28 mm
--------------	-------

### General

Installation advice	Direct mounting	Mounting rail	TS 35
---------------------	-----------------	---------------	-------

### Classifications

ETIM 8.0	EC001041	ETIM 9.0	EC001041
ETIM 10.0	EC001041	ECLASS 14.0	27-25-03-02
ECLASS 15.0	27-25-03-02		