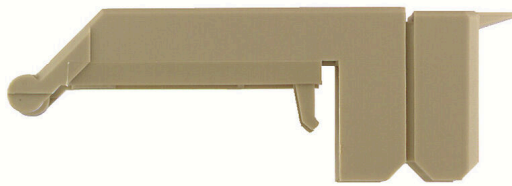


**WAH 70 BE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

**General ordering data**

Version	Bolt-type screw terminals, Hood, beige, 31 mm
Order No.	<a href="#">1064560000</a>
Type	WAH 70 BE
GTIN (EAN)	4008190174736
Qty.	20 items

## WAH 70 BE

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	29.9 mm	Depth (inches)	1.1772 inch
Height	85 mm	Height (inches)	3.3464 inch
Width	31 mm	Width (inches)	1.2205 inch
Net weight	8.47 g		

### Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...55 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate	0.12 kg CO2 eq.	

### Material data

Basic material	Polyamide 66	Colour	beige
UL 94 flammability rating	V-2		

### Additional technical data

Type of fixing	Snap-on	Installation advice	Direct mounting
Explosion-tested version	No		

### Dimensions

Pitch in mm (P)	32.00 mm	TS 35 offset	19 mm
-----------------	----------	--------------	-------

### General

Installation advice	Direct mounting
---------------------	-----------------

### Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		