


WAH 120

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image

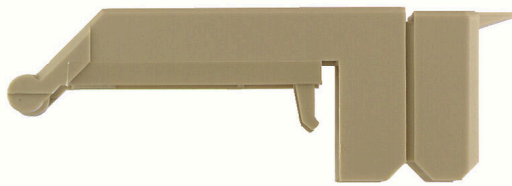

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

Version	Bolt-type screw terminals, Hood, beige, 41 mm
Order No.	1064660000
Type	WAH 120
GTIN (EAN)	4008190100797
Qty.	20 items

WAH 120

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	34.5 mm	Depth (inches)	1.3583 inch
Height	110.25 mm	Height (inches)	4.3405 inch
Width	41 mm	Width (inches)	1.6142 inch
Net weight	16.14 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	Polyamide 66	Colour	beige
UL 94 flammability rating	V-2		

Additional technical data

Type of fixing	Snap-on	Installation advice	Direct mounting
Explosion-tested version	No		

Dimensions

Pitch in mm (P)	42.00 mm
-----------------	----------

General

Installation advice	Direct mounting
---------------------	-----------------

Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		

WAH 120

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Protection against contact



Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

Type	WAP WFF120	Version	
Order No.	1073000000		
GTIN (EAN)	4008190475260		
Qty.	20 ST		
			Bolt-type screw terminals, Cover plate, dark beige, 2 mm