

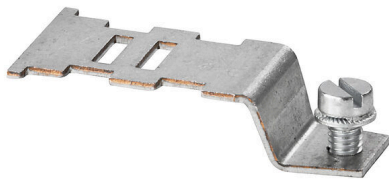
WZAD 70/95**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image

The additional connection enables a separate voltage tap. This can be used, for example, for the emergency power supply before the main switch or simply as an additional connection within the application.

General ordering data

Version	Auxiliary connection (terminal), Number of connections: 1
Order No.	1066000000
Type	WZAD 70/95
GTIN (EAN)	4008190017064
Qty.	10 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	10 mm	Depth (inches)	0.3937 inch
Height	39.61 mm	Height (inches)	1.5594 inch
Width	19.7 mm	Width (inches)	0.7756 inch
Net weight	6.05 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
---------------------	----------------	---------------------	---------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	tinned copper	Colour	Silver grey
----------------	---------------	--------	-------------

System specifications

Version	Additional connection	Number of levels	1
Number of clamping points per level	1		

Additional technical data

Type of fixing	Snap-on	Installation advice	Feed-through (bushing), Direct mounting
Explosion-tested version	No		

Conductors for clamping (rated connection)

Number of connections	1	Clamping range, max.	6 mm ²
Clamping range, min.	0.5 mm ²		

Dimensions

Pitch in mm (P)	20.00 mm
-----------------	----------

General

Installation advice	Feed-through (bushing), Direct mounting
---------------------	--

Rating data

Rated voltage	800 V	Rated DC voltage	800 V
Nominal current	32 A		

Technical data

Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-08
ECLASS 15.0	27-25-03-08		