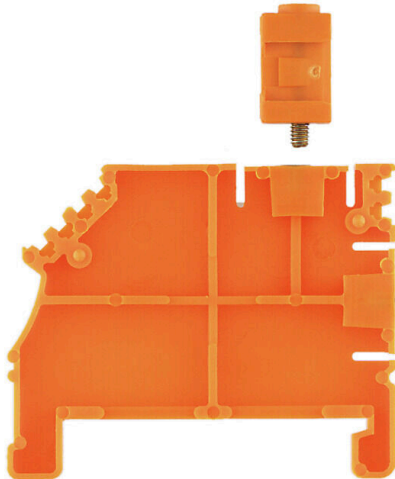


WBB ZA WDU1.5/BL 10/10

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | |
|------------|--|
| Version | Partition plate (terminal), orange, Height: 45.4 mm, Width: 5 mm, V-2, PA 66 |
| Order No. | 1068260000 |
| Type | WBB ZA WDU1.5/BL 10/10 |
| GTIN (EAN) | 4008190015657 |
| Qty. | 10 items |

WBB ZA WDU1.5/BL 10/10

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 36.7 mm | Depth (inches) | 1.4449 inch |
| Height | 45.4 mm | Height (inches) | 1.7874 inch |
| Width | 5 mm | Width (inches) | 0.1968 inch |
| Net weight | 4.31 g | | |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|----------------|
| Storage temperature | -25 °C...55 °C | Ambient temperature | -50 °C...55 °C |
| Continuous operating temp., min. | -50 °C | Continuous operating temp., max. | 100 °C |

Environmental Product Compliance

| | |
|--------------------------------------|--------------------------------------|
| RoHS Compliance Status | Compliant with exemption |
| RoHS Exemption (if applicable/known) | 6c |
| REACH SVHC | Lead 7439-92-1 |
| SCIP | 936a8f21-8ce1-4838-a60e-9ad69268c052 |

Material data

| | | | |
|---------------------------|-------|--------|--------|
| Basic material | PA 66 | Colour | orange |
| UL 94 flammability rating | V-2 | | |

System specifications

| | |
|---------|----------------------------|
| Version | End and intermediate plate |
|---------|----------------------------|

Additional technical data

| | | | |
|---------|----|---------------------|-----------------|
| Snap-on | No | Installation advice | Direct mounting |
|---------|----|---------------------|-----------------|

General

| | |
|---------------------|-----------------|
| Installation advice | Direct mounting |
|---------------------|-----------------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000886 | ETIM 9.0 | EC000886 |
| ETIM 10.0 | EC000886 | ECLASS 14.0 | 27-25-03-01 |
| ECLASS 15.0 | 27-25-03-01 | | |