

RKDG D24 WG PT6


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

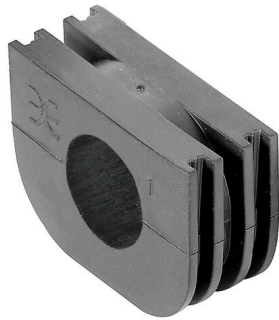

Intelligent cabling solutions can save you valuable time and money.

The FieldPower® modular system contains the right solution for every cabling task.

Foldable seals for the use of pre-assembled cables

Seals available with M16 and M20 connection thread

Integration of operating and signalling devices into the seal possible

General ordering data

| | |
|------------|---|
| Version | Field Power® sealing insert, Seal, IP54, with corresponding enclosure, EPDM |
| Order No. | 1069060000 |
| Type | RKDG D24 WG PT6 |
| GTIN (EAN) | 4032248827053 |
| Qty. | 10 items |

RKDG D24 WG PT6

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|---------|-----------------|---------------|
| Depth | 18 mm | Depth (inches) | 0.7087 inch |
| Height | 33.8 mm | Height (inches) | 1.3307 inch |
| Width | 46.7 mm | Width (inches) | 1.8386 inch |
| Length | 5 m | Length (inches) | 196.8504 inch |
| Net weight | 16.5 g | | |

Temperatures

| | | | |
|---------------------|----------------|-----------------------|----------------|
| Storage temperature | -40 °C...85 °C | Operating temperature | -40 °C...85 °C |
|---------------------|----------------|-----------------------|----------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | | |
|--|------------------------------------|---------------------------|-------|
| Basic material | EPDM | Silicone | No |
| Colour | black | Design | Seal |
| Protection degree | IP54, with corresponding enclosure | UL 94 flammability rating | HB |
| Mounting position, installation notice | in FieldPower® sealing slot | Line type | round |
| Outer cable diameter, max. | 24 mm | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC002624 | ETIM 9.0 | EC002624 |
| ETIM 10.0 | EC002624 | ECLASS 14.0 | 27-18-28-15 |
| ECLASS 15.0 | 27-18-28-15 | | |