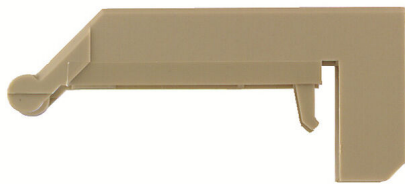


WAH 70/KU**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

General ordering data

Version	Bolt-type screw terminals, Hood, beige, 30.5 mm
Order No.	1070360000
Type	WAH 70/KU
GTIN (EAN)	4008190191054
Qty.	20 items
Delivery status	Discontinued
Last order date	2025-12-31T00:00:00+01:00

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	30 mm	Depth (inches)	1.1811 inch
Height	64 mm	Height (inches)	2.5197 inch
Width	30.5 mm	Width (inches)	1.2008 inch
Net weight	7.15 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Basic material	Polyamide 66	Colour	beige
UL 94 flammability rating	V-2		

Additional technical data

Type of fixing	Snap-on	Installation advice	Direct mounting
Explosion-tested version	No		

Dimensions

Pitch in mm (P)	32.00 mm
-----------------	----------

General

Installation advice	Direct mounting
---------------------	-----------------

Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		