

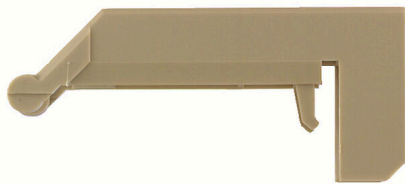
**WAH 70/KU****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

Our systems for touch protection ensure greater safety in your cabinet. They provide protection against electric shock caused by accidental contact with live parts due to operation or faults.

**General ordering data**

|                 |   |
|-----------------|---|
| Version         | Bolt-type screw terminals, Hood, beige, 30.5 mm         |
| Order No.       | <a href="#">1070360000</a>                              |
| Type            | WAH 70/KU   |
| GTIN (EAN)      | 4008 19019 1054   |
| Qty.            | 20 items  |
| Delivery status | This article will no longer be available in the future. |
| Available until | 2025-12-31T00:00:00+01:00                               |

## WAH 70/KU

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 30 mm   | Depth (inches)  | 1.1811 inch |
| Height     | 64 mm   | Height (inches) | 2.5197 inch |
| Width      | 30.5 mm | Width (inches)  | 1.2008 inch |
| Net weight | 7.15 g  |                 |             |

### Temperatures

|                                  |                |                                  |               |
|----------------------------------|----------------|----------------------------------|---------------|
| Storage temperature              | -25 °C...55 °C | Ambient temperature              | -5 °C...40 °C |
| Continuous operating temp., min. | -50 °C         | Continuous operating temp., max. | 100 °C        |

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### Material data

|                           |              |        |       |
|---------------------------|--------------|--------|-------|
| Basic material            | Polyamide 66 | Colour | beige |
| UL 94 flammability rating | V-2          |        |       |

### Additional technical data

|                          |         |                     |                 |
|--------------------------|---------|---------------------|-----------------|
| Type of fixing           | Snap-on | Installation advice | Direct mounting |
| Explosion-tested version | No      |                     |                 |

### Dimensions

|                 |          |
|-----------------|----------|
| Pitch in mm (P) | 32.00 mm |
|-----------------|----------|

### General

|                     |                 |
|---------------------|-----------------|
| Installation advice | Direct mounting |
|---------------------|-----------------|

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC002848    | ETIM 9.0    | EC002848    |
| ETIM 10.0   | EC002848    | ECLASS 14.0 | 27-25-03-90 |
| ECLASS 15.0 | 27-25-03-90 |             |             |