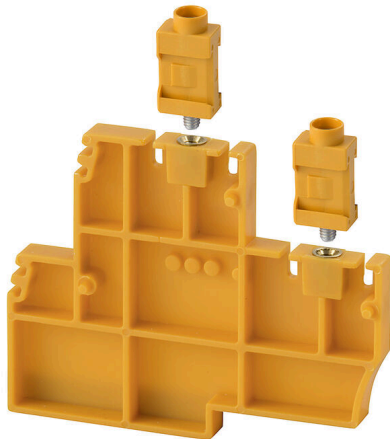


**WBB ZA WDK2.5/BL5.08**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Product image**

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

**General ordering data**

Version	Partition plate (terminal), orange, Height: 58 mm, Width: 5 mm, V-2, PA 66
Order No.	<a href="#">1072760000</a>
Type	WBB ZA WDK2.5/BL5.08
GTIN (EAN)	4008190470548
Qty.	10 items

## WBB ZA WDK2.5/BL5.08

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	45.2 mm	Depth (inches)	1.7795 inch
Height	58 mm	Height (inches)	2.2835 inch
Width	5 mm	Width (inches)	0.1968 inch
Net weight	7.48 g		

## Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...55 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

## Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	936a8f21-8ce1-4838-a60e-9ad69268c052

## Material data

Basic material	PA 66	Colour	orange
UL 94 flammability rating	V-2		

## System specifications

Version	End and intermediate plate
---------	----------------------------

## Additional technical data

Snap-on	No	Installation advice	Direct mounting
---------	----	---------------------	-----------------

## General

Installation advice	Direct mounting
---------------------	-----------------

## Classifications

ETIM 8.0	EC000886	ETIM 9.0	EC000886
ETIM 10.0	EC000886	ECLASS 14.0	27-25-03-01
ECLASS 15.0	27-25-03-01		