


**IE-PS-V14M-HYB-10P**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

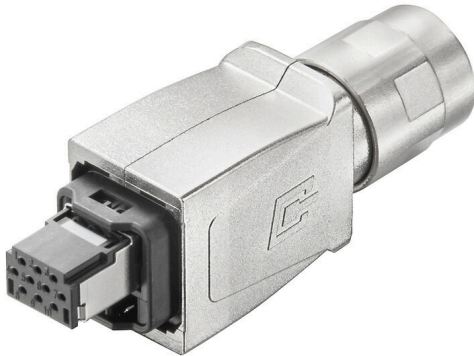

PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. hybrid insert

**General ordering data**

Version	Hybrid plug, Cat.5 (ISO/IEC 11801)
Order No.	<a href="#">1072910000</a>
Type	IE-PS-V14M-HYB-10P
GTIN (EAN)	4032248831128
Qty.	10 items

## IE-PS-V14M-HYB-10P

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E316369

## Dimensions and weights

Net weight 61.81 g

## Temperatures

Storage temperature Operating temperature -40 °C...70 °C

Installation temperature

## Environmental Product Compliance

RoHS Compliance Status Compliant with exemption

RoHS Exemption (if applicable/known) 6c

REACH SVHC Lead 7439-92-1

SCIP 4f3aae94-c2bc-4010-b63b-5b114ba6bd55

## General data

Wire cross-section, finely stranded, max. AWG 20 (AWG)

Shielding 360°; all-round enclosure

Insulation cross-section, max. 1.05 mm

Category Cat.5 (ISO/IEC 11801)

Wire connection cross section, finely stranded, min. 0.08 mm<sup>2</sup>

Sheath diameter, min. 5 mm

Plugging cycles 500

Connection 2 Crimp

Wire cross-section, finely stranded, min. AWG 27 (AWG)

Housing main material Zinc diecast

Insulation cross-section, min. 0.85 mm

Wire connection cross section, finely stranded, max. 0.75 mm<sup>2</sup>

Sheath diameter, max. 10 mm

Protection degree IP67

Connection 1 Hybrid (Q10)

## Electrical properties

Volume resistance &lt;10 mΩ

Rated current 3 A per contact

## General standards

Connector standard IEC 61076-3-119 CDV, IEC 61076-3-117 Var. 14

Certificate no. (cULus) E316369

## Classifications

ETIM 8.0 EC001121

ETIM 9.0 EC001121

ETIM 10.0 EC001121

ECLASS 14.0 27-44-03-90

ECLASS 15.0 27-44-03-90

**IE-PS-V14M-HYB-10P**


**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

**Dimensioned drawing**

---

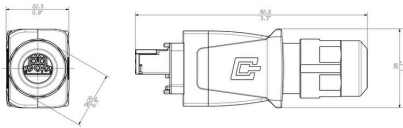

## IE-PS-V14M-HYB-10P


**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

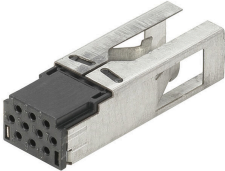

## General ordering data

Type	IE-PIC-HYB-S-0,2-300	Version	
Order No.	<a href="#">1135150000</a>	Crimp contact, for plug insert, Hybrid	
GTIN (EAN)	4032248915347		
Qty.	300 ST		
Type	IE-PIC-HYB-S-0,5-300	Version	
Order No.	<a href="#">1096180000</a>	Crimp contact, for plug insert, Hybrid	
GTIN (EAN)	4032248869152		
Qty.	300 ST		
Type	IE-PIC-HYB-S-0,75-300	Version	
Order No.	<a href="#">1068950000</a>	Crimp contact, for plug insert, Hybrid	
GTIN (EAN)	4032248823109		
Qty.	300 ST		

## Crimping tools



Crimping tools for Weidmüller contacts for RSV and DSTV-HD systems

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With end stop for exact positioning of the contacts

## General ordering data

Type	HTF HYB	Version	
Order No.	<a href="#">1119580000</a>	Pressing tool, Crimping tool for contacts, 0.08mm <sup>2</sup> , 1mm <sup>2</sup> ,	
GTIN (EAN)	4032248900626	FoderBcrimp	
Qty.	1 ST		

## IE-PS-V14M-HYB-10P

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Hybrid cable



Bulk stock, copper cable, hybrid, flexible, 6 x 0.5 mm<sup>2</sup> + 4 x AWG 22/7

## General ordering data

Type	IE-C5DHAG-MW	Version	
Order No.	<a href="#">1172250000</a>	Connecting line, Cat.5 (ISO/IEC 11801) / Cat.5e (TIA T568-B), PVC,	
GTIN (EAN)	4032248964543	Products sold by meter, from 110 m	
Qty.	110 M		

## Dust caps




For protecting your devices against dust and dirt.

## General ordering data

Type	IE-PP-V14P	Version	
Order No.	<a href="#">1058280000</a>	Plug housing protective cap	
GTIN (EAN)	4032248799374		
Qty.	10 ST		

## Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

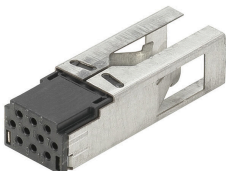

## General ordering data

Type	IE-PI-HYB-10P	Version	
Order No.	<a href="#">1068990000</a>	Insert, for plug insert, Hybrid	
GTIN (EAN)	4032248823963		
Qty.	1 ST		


**IE-PS-V14M-HYB-10P**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**Blank**

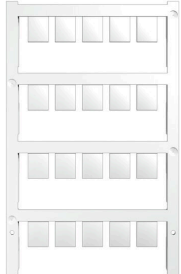

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

**General ordering data**

Type	ESG 9/11 K MC NE WS	Version	
Order No.	<a href="#">1857440000</a>		ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731		
Qty.	200 ST		


## IE-PS-V14M-HYB-10P

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Counterpart

### Sets - hybrid

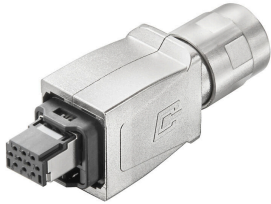

PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. hybrid insert

### General ordering data

Type	IE-BSS-V14M-HYB-10P-FJ	Version	
Order No.	<a href="#">1072900000</a>	Hybrid flange, IP67, Cat.5 (ISO/IEC 11801)	
GTIN (EAN)	4032248831111		
Qty.	10 ST		