


**IE-PS-V14M-HYB-10P**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

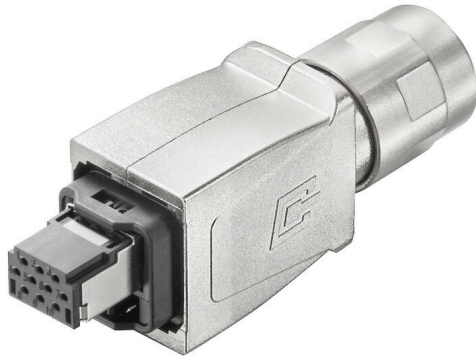

PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. hybrid insert

**General ordering data**

Version	Hybrid plug, Cat.5 (ISO/IEC 11801)
Order No.	<a href="#">1072910000</a>
Type	IE-PS-V14M-HYB-10P
GTIN (EAN)	4032248831128
Qty.	10 items

## IE-PS-V14M-HYB-10P

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E316369

## Dimensions and weights

Net weight 61.81 g

## Temperatures

Storage temperature Operating temperature -40 °C...70 °C

Installation temperature

## Environmental Product Compliance

RoHS Compliance Status Compliant with exemption

RoHS Exemption (if applicable/known) 6c

REACH SVHC Lead 7439-92-1

SCIP 4f3aae94-c2bc-4010-b63b-5b114ba6bd55

## General data

Wire cross-section, finely stranded, max. AWG 20 (AWG)

Shielding 360°; all-round enclosure

Insulation cross-section, max. 1.05 mm

Category Cat.5 (ISO/IEC 11801)

Wire connection cross section, finely stranded, min. 0.08 mm<sup>2</sup>

Sheath diameter, min. 5 mm

Plugging cycles 500

Connection 2 Crimp

Wire cross-section, finely stranded, min. AWG 27 (AWG)

Housing main material Zinc diecast

Insulation cross-section, min. 0.85 mm

Wire connection cross section, finely stranded, max. 0.75 mm<sup>2</sup>

Sheath diameter, max. 10 mm

Protection degree IP67

Connection 1 Hybrid (Q10)

## Electrical properties

Volume resistance &lt;10 mΩ

Rated current 3 A per contact

## General standards

Connector standard IEC 61076-3-119 CDV, IEC 61076-3-117 Var. 14

Certificate no. (cULus) E316369

## Classifications

ETIM 8.0 EC001121

ETIM 9.0 EC001121

ETIM 10.0 EC001121

ECLASS 14.0 27-44-03-90

ECLASS 15.0 27-44-03-90

**IE-PS-V14M-HYB-10P**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

**Dimensioned drawing**

