

**HDC IP68 HP 24B TO****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The RockStar® HighPower housings are manufactured from high-strength die-cast aluminium and offer perfect protection against harsh environmental conditions thanks to continual optimisation. The multi-part housing gives users the opportunity to examine work processes down to the last step in the workflow.

**General ordering data**

Version	HDC enclosures, Installation size: 8, Protection degree: IP68, IP69, in plugged condition, Plug housing, Clamping yoke connection, Standard
Order No.	<a href="#">1079930000</a>
Type	HDC IP68 HP 24B TO
GTIN (EAN)	4032248842032
Qty.	1 items

**HDC IP68 HP 24B TO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	192 mm	Depth (inches)	7.559 inch
Height	120 mm	Height (inches)	4.7244 inch
Width	64 mm	Width (inches)	2.5197 inch
Net weight	822.72 g		

**Temperatures**

Limit temperature	-50 °C ... 120 °C
-------------------	-------------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption	
REACH SVHC	No SVHC above 0.1 wt%	
Chemical resistance	Substance	Acetone
	Chemical resistance	Resistant
	Substance	Diesel oil
	Chemical resistance	Unstable
	Substance	Ethyl alcohol
	Chemical resistance	Resistant
	Substance	Transmission oil
	Chemical resistance	Conditionally resistant
	Substance	Hydraulic oil
	Chemical resistance	Conditionally resistant
	Substance	Petroleum benzine
	Chemical resistance	Unstable
	Substance	Sweat
	Chemical resistance	Conditionally resistant
	Substance	Premium gasoline
	Chemical resistance	Unstable
Substance	Water	
Chemical resistance	Resistant	
Substance	UV	
Chemical resistance	Resistant	
Substance	Ozone	
Chemical resistance	Resistant	

**General data**

Number of poles	0	Design of housing	Plug housing
Installation size	8	Colour	black, black (similar to RAL 9005)
Surface finish	Powder coating	Type	Plug
Series	HighPower	Free from halogens	false
BG	8	Protection degree	IP68, IP69, in plugged condition

**General data**

Tightening torque	11 Nm	Housing main material	diecast aluminium
Surface finish	Powder coating	Protection degree	IP68, IP69, in plugged condition

## HDC IP68 HP 24B TO

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

Series	HighPower	EMC housings	Yes
Material of locking element	Stainless steel, rust-proof		

### Version

Top part/bottom part/lid	upper part	Cover	without cover
Tightening torque	11 Nm	Number of cable entry sideways	0
Design of housing	Plug housing	Design of locking system	Clamping yoke connection
Design	Standard	Installation size	8
Cable entry	No	Type	Plug
Clamp version	Clamping yoke connection	Sealing	Silicone rubber
Colour (RAL)	RAL 9011, RAL 9005	BG	8

### Important note

Product information	Depending on the intended operation, internally generated voltages can superimpose the working voltage and contain corresponding peaks. It is imperative to ensure that these peak voltages do not exceed the rated voltage. For applications outside of this specification, please contact us.
---------------------	---

### Classifications



ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

**HDC IP68 HP 24B TO**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

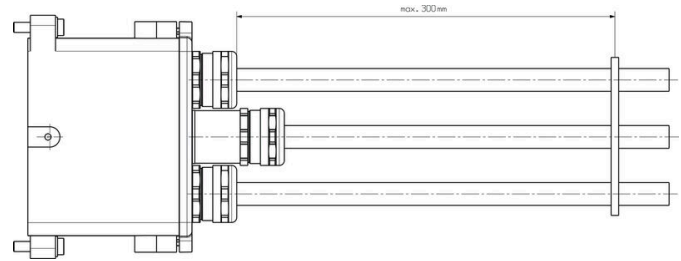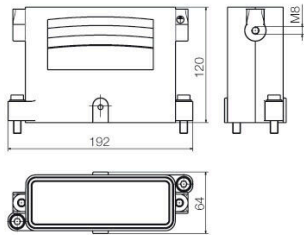

To avoid damage to the contacts and insulating sleeves, we recommend fixing the cable. The corresponding distances are shown in the following drawing. The cable fixation is not included in the scope of delivery.



**HDC IP68 HP 24B TO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**Socket wrench sets**



Allen key made from fully hardened, high-alloy chromium-vanadium- steel, acc. to DIN ISO 2936 L (DIN 911), high-quality refined surface.

**General ordering data**

Type	SK WSD-S 1,5-10,0	Version	
Order No.	<a href="#">9008850000</a>	Mounting tool	
GTIN (EAN)	4032248266609		
Qty.	1 ST		

**HighPower spare parts**



**General ordering data**

Type	HDC HP TO SCREW SET	Version	
Order No.	<a href="#">2447770000</a>	HDC-HighPower	
GTIN (EAN)	4050118461688		
Qty.	10 ST		
Type	HDC HP TO SCREW SET	Version	
Order No.	<a href="#">2447770000</a>	HDC-HighPower	
GTIN (EAN)	4050118461688		
Qty.	10 ST		