

**HDC 64D TOLU 1M50G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Installation size: 8, Protection degree: IP65, in plugged condition, Cable entry from top, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 50
Order No.	<a href="#">1111170000</a>
Type	HDC 64D TOLU 1M50G
GTIN (EAN)	4032248100125
Qty.	1 items

## HDC 64D TOLU 1M50G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E92202

## Dimensions and weights

Height	94 mm	Height (inches)	3.7008 inch
Width	65.5 mm	Width (inches)	2.5787 inch
Net weight	411 g		

## Temperatures

Limit temperature -40 °C ... 125 °C

## Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Chemical resistance

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant
Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

## Dimensions

Cable entry	w. thread	Width housing C	43 mm
Total length housing	120 mm	Height of housing B	76 mm

## HDC 64D TOLU 1M50G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## General data

Housing main material	diecast aluminium	Surface finish	Powder coating
Protection degree	IP65, in plugged condition	EMC housings	No

## Version

Size of cable entries	M 50	Top part/bottom part/lid	upper part
Number of cable entry on top	1	Number of cable entry sideways	0
Design of housing	Cable entry from top, Plug housing	Design of locking system	End-locking clamp, lower side
Design	Standard	Installation size	8
Cable entry	w. thread	Type	Plug
Internal thread	M 50	Colour (RAL)	RAL 7035
BG	8	Suitable for ModuPlug®	Yes

## Classifications


ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 9.0	27-44-02-02
ECLASS 9.1	27-44-02-02	ECLASS 10.0	27-44-02-02
ECLASS 11.0	27-44-02-02	ECLASS 12.0	27-44-02-02
ECLASS 13.0	27-44-02-02	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

## HDC 64D TOLU 1M50G

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

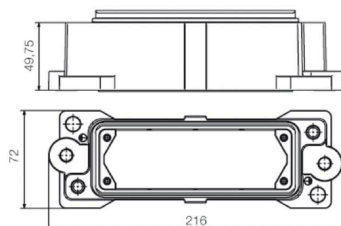

## HDC 64D TOLU 1M50G

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B SDLU 2PG21G	Version
Order No.	<a href="#">1214500000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190153021	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: PG 21
Type	HDC 24B SLU 2PG21G	Version
Order No.	<a href="#">1662720000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190419240	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: PG 21
Type	HDC 64D SDLU 2PG29G	Version
Order No.	<a href="#">1663040000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190419561	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: PG 29
Type	HDC 64D SLU 2M32G	Version
Order No.	<a href="#">1786900000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204144	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 32
Type	HDC 64D SLU 2M25G	Version
Order No.	<a href="#">1786910000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204151	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 25
Type	HDC 64D SDLU 2M32G	Version
Order No.	<a href="#">1786940000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204182	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 32
Type	HDC 64D SDLU 2M25G	Version
Order No.	<a href="#">1786950000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204199	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 25
Type	HDC 24B SLU 2M25G	Version
Order No.	<a href="#">1787880000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248205325	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: M 25

## HDC 64D TOLU 1M50G

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

Type	HDC 24B SDLU 2M25G	Version
Order No.	<a href="#">1787900000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248205349	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: M 25
Type	HDC 24B SDLU 1M25G	Version
Order No.	<a href="#">1901480000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248521364	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: M 25
Type	HDC 24B SLU 1M25G	Version
Order No.	<a href="#">1901560000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248521395	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: M 25
Type	HDC 64D SDLU 1M25G	Version
Order No.	<a href="#">1904430000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585106	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 25
Type	HDC 64D SDLU 1M32G	Version
Order No.	<a href="#">1904440000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585212	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 32
Type	HDC 64D SLU 1M25G	Version
Order No.	<a href="#">1904480000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585090	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 25
Type	HDC 64D SLU 1M32G	Version
Order No.	<a href="#">1904490000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585618	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 32

## Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B ALU	Version
Order No.	<a href="#">1213900000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190176303	plugged condition, Bulkhead housing, End-locking clamp, lower side,
Qty.	1 ST	Standard

## HDC 64D TOLU 1M50G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 24B ADLU	Version
Order No.	<a href="#">1214300000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190083090	plugged condition, Bulkhead housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover

## Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B KLU 1M25G	Version
Order No.	<a href="#">1968340000</a>	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248689378	plugged condition, Coupling housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: M 25