


WAD 8 MC SDR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

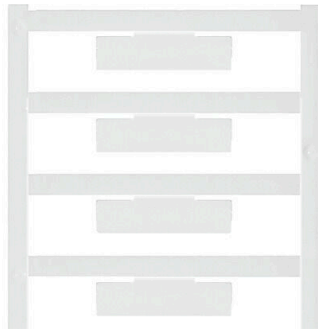

Similar to illustration

The WAD connector marker is suitable for W-series terminals and for the WEW 35/2 and ZEW 35/2 end brackets. The markers are available as blank markers, with custom printing or standard print with lightning symbol. The WAD MultiCard markers are suitable for labelling with PrintJet CONNECT printers. For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | |
|------------|---|
| Version | Group markers, Cover, 33.3 x 8 mm, Pitch in mm (P): 8.00 WDU 4, WEW 35/2, ZEW 35/2, To customer specification |
| Order No. | 1112970000 |
| Type | WAD 8 MC SDR |
| GTIN (EAN) | 4032248891788 |
| Qty. | 12 items |

WAD 8 MC SDR

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Depth | 11.74 mm | Depth (inches) | 0.4622 inch |
| Height | 33.3 mm | Height (inches) | 1.311 inch |
| Width | 8 mm | Width (inches) | 0.315 inch |
| Net weight | 1.33 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...100 °C |
|-----------------------------|--------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | |
|--------------------------------------|---|-----------|
| Type of printing | To customer specification | |
| Printing method | Ink jet technology | |
| Width | 8 mm | |
| UL 94 flammability rating | V-2 | |
| Operating temperature range, max. | 100 °C | |
| Operating temperature range, min. | -40 °C | |
| Colour | To customer specification | |
| Halogen | No | |
| Basic material | Polyamide 66 | |
| Printed characters | Based on customer requirements (Please send M-Print PRO file) | |
| Number of markers per packaging unit | Form of supply | MultiCard |
| Number of markers per combination | 1 MultiCard = Cover | |
| Operating temperature range | -40...100 °C | |
| Application/manufacturer | WDU 4, WEW 35/2, ZEW 35/2 | |

Connector markers

| | |
|-----------------|---------|
| Pitch in mm (P) | 8.00 mm |
|-----------------|---------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC002848 | ETIM 9.0 | EC002848 |
| ETIM 10.0 | EC002848 | ECLASS 14.0 | 27-25-03-90 |
| ECLASS 15.0 | 27-25-03-90 | | |

Drawings

Drawing

